


Squeeze Type - Zinc

Images

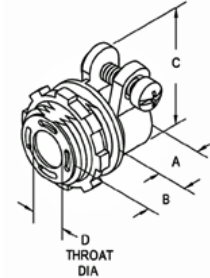

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-1/8

Dimension B in Inches: 1/2

Dimension C in Inches: 1-3/4

Dimension D in Inches: .813

Application

Used to connect steel flexible metal conduit or XRW FMC to box or enclosure.

Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E9391

UL Standard: UL-514B

UNSPSC: 39121419

Catalog ID: 408-DC2

UPC Number: 781747154088

Description: Connector, Squeeze, Zinc Die Cast, Trade Size 3/4 Inch

Application: Used to connect steel flexible metal conduit or XRW FMC to box or enclosure.

Trade Size: 3/4"

Country of Manufacture: USA

Std Pkg Qty: 100

Unit Qty: 25