




## OmniConn™ RG-6 Quad F Compression Connector

Cable specific RG-6 Quad coax F compression connector designed for indoor and outdoor applications. Black adapter sleeve provides a weatherproof back seal once compressed.

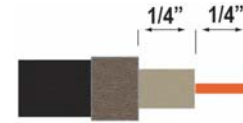

- Nickel plated brass and plastic construction for indoor/outdoor applications
- O-ring and adapter sleeve prevent moisture migration
- 3GHZ, 75Ω rated for use in all video based applications such as cable and satellite television
- >40lbs cable retention
- Fits cables with .270" - .295" jacket diameter
- Fits cables with .175" - .183" dielectric diameter
- Requires industry standard 1/4" x 1/4" cable preparation
- Recommended IDEAL cable prep tool: 45-605
- Requires industry standard 21mm compression stroke
- Recommended compression tools: 30-793, 33-632
- Compatible with non-IDEAL tools
- Not compatible with 35-046 F/BNC Insertion Tool

Weatherproof adapter sleeve

Internal O-ring



Two-piece, preassembled design

Part No.	Qty
89-045	50/Jar
89-1545	1,000/Bulk Box

**Also available:**



89-044 RG-6 OmniConn™



45-605



30-793