


Duplex - Single Screw - Strap Type

Images

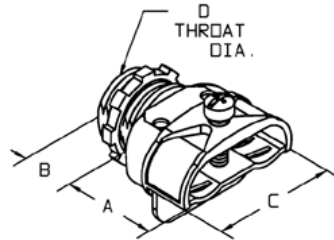

Application

For use with AC/MC/MCI-A 14/2 (.375" 0 min) to 10/3 (.625" 0 max) HCF/HCFMCI-A 3/8" FMC and 14/2 to 10/3 NM Cable

Product Information

Material: Zinc Die Cast
Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E20534
UL Standard:	UL-514B
UNSPSC:	39121419

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-1/8

Dimension B in Inches: 9/16

Dimension C in Inches: 1-11/16

Dimension D in Inches: .618

Catalog ID: 601-DC2

UPC Number: 781747156013

Description: Connector, Duplex, Zinc Die Cast. For AC/MC 3/8" FMC and Non-Metallic Cables.

Application: For use with AC/MC/MCI-A 14/2 (.375" 0 min) to 10/3 (.625" 0 max) HCF/HCFMCI-A 3/8" FMC and 14/2 to 10/3 NM Cable

Trade Size: 1/2"

Country of Manufacture: USA

Std Pkg Qty: 200

Unit Qty: 20