




Pass & Seymour

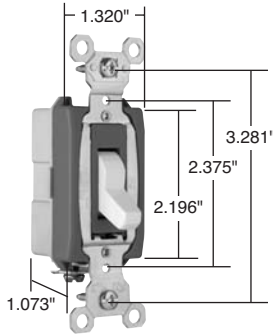

15 & 20 Amp\*

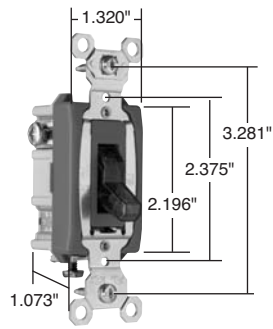

15 & 20 Amp Lighted & Pilot Lighted\*

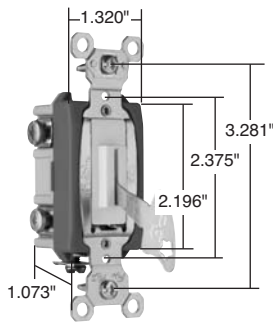


Locking\*

\*30AC series is 1.437" wide

**Lock Switch Replacement Keys**

(One key furnished with each switch)

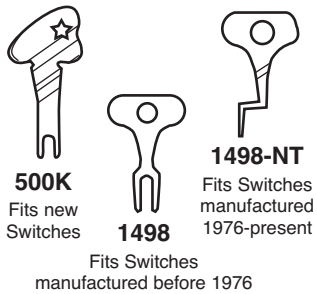

All devices listed on this page conform to NEMA WD-1 and WD-6.

**Switches**  
**Industrial Extra Heavy-Duty**  
**Specification Grade Switches**

15, 20 & 30A, 120, 277 & 120/277VAC

**Features**

- External screw-pressure-plate back and side wired. Accepts #14 – #10 AWG copper or copper-clad conductors.
- Heavy-gauge one-piece copper alloy contact arm virtually eliminates contact bounce.
- Cam controls fast “make” and positive “break” to minimize arcing.
- Heavy-duty bumper pads for quiet operation.
- High strength thermoplastic polycarbonate toggle.
- Back body made of glass-reinforced nylon.
- Locking support provides resistance to face and back body separation.
- Oversized silver alloy contacts for long life and better heat dissipation.
- Grounding terminal is standard.
- Shallow design for ease of installation.
- Strap nickel-plated steel with integral ground.

Catalog Number				Rating A. VAC	Color	3rd Party Compliance		
Single Pole	Double Pole	Three-Way	Four-Way			UL20	FSUL WS896	CS C22.2 111
<b>Toggle Switches Back &amp; Side Wire</b>								
PS15AC1-I PS15AC1-W PS15AC1 PS15AC1-GRY PS15AC1-LA	PS15AC2-I PS15AC2-W PS15AC2 PS15AC2-GRY PS15AC2-LA	PS15AC3-I PS15AC3-W PS15AC3 PS15AC3-GRY PS15AC3-LA	PS15AC4-I PS15AC4-W PS15AC4 PS15AC4-GRY PS15AC4-LA	15 120/277 15 120/277 15 120/277 15 120/277 15 120/277	Ivory White Brown Gray Light Almond	• • • • •	• • • • •	• • • • •
PS20AC1-I PS20AC1-W PS20AC1 PS20AC1-GRY PS20AC1-BK PS20AC1-RED PS20AC1-LA	PS20AC2-I PS20AC2-W PS20AC2 PS20AC2-GRY PS20AC2-BK PS20AC2-RED PS20AC2-LA	PS20AC3-I PS20AC3-W PS20AC3 PS20AC3-GRY PS20AC3-BK PS20AC3-RED PS20AC3-LA	PS20AC4-I PS20AC4-W PS20AC4 PS20AC4-GRY PS20AC4-BK PS20AC4-RED PS20AC4-LA	20 120/277 20 120/277 20 120/277 20 120/277 20 120/277 20 120/277 20 120/277	Ivory White Brown Gray Black Red Light Almond	• • • • • • •	• • • • • • •	• • • • • • •
PS30AC1-I PS30AC1	PS30AC2-I PS30AC2-W PS30AC2	PS30AC3-I PS30AC3		30 120/277 30 120/277 30 120/277	Ivory White Brown	• • •	• • •	• • •
<b>Lighted Toggle Switches (Lighted when OFF) Back &amp; Side Wire</b>								
PS15AC1-CSL PS15AC1-ISL PS15AC1-WSL		PS15AC3-CSL PS15AC3-ISL PS15AC3-WSL		15 120/277 15 120/277 15 120/277	Clear Ivory White	• • •	• • •	• • •
PS20AC1-CSL PS20AC1-ISL PS20AC1-WSL PS20AC1-LASL		PS20AC3-CSL PS20AC3-ISL PS20AC3-WSL PS20AC3-LASL		20 120/277 20 120/277 20 120/277 20 120/277	Clear Ivory White Light Almond	• • • •	• • • •	• • • •
<b>Pilot Lighted Switches (Lighted when ON) Back &amp; Side Wire</b>								
PS15AC1-CPL PS15AC1-RPL		PS15AC3-CPL PS15AC3-RPL		15 120 15 120	Clear Red	• •	• •	• •
PS20AC1-CPL PS20AC1-CPL7 PS20AC1-RPL PS20AC1-RPL7		PS20AC3-CPL7 PS20AC3-RPL PS20AC3-RPL7		20 120 20 277 20 120 20 277	Clear Clear Red Red	• • • •	• • • •	• • • •
	PS20AC2-CPL PS20AC2-RPL			20 120/277 20 120/277	Clear Red	• •	• •	• •
PS30AC1-RPL	PS30AC2-RPL	PS30AC3-RPL		30 120 30 120/277	Red Red	• •	• •	• •
<b>Lock Switches (Key can be removed in both positions) Back &amp; Side Wire</b>								
PS15AC1-L PS20AC1-L PS20AC1-IL PS20AC1-WL PS20AC1-LAL	PS20AC2-L	PS15AC3-L PS20AC3-L PS20AC3-IL PS20AC3-WL PS20AC3-LAL	PS20AC4-L	15 120/277 20 120/277 20 120/277 20 120/277 20 120/277	Gray Gray Ivory White Light Almond	• • • • •	• • • • •	• • • • •