

SNA Terminal Blocks

T&B Catalog Number:

011564622

UPC Number:

66201995743

Status:

Active

Description:

Beige, fuse holder terminal blocks, double-deck for 5 x 20 and 5 x 25 mm fuses with 8 mm spacing, 26 Amp rated UL current that accepts 12 AWG UL wire

Features

Includes IP20 protection

Application

For use with applications ranging from standard distribution and control panels, to specialized applications in key industries such as traction, energy, maritime, explosive atmospheres, material handling, etc.

General

Style	Fuse Holder
Color	Beige
Mounting	DIN 1-3
Series	M4/8.D2.SF.V0
Connection Technology	Screw Clamp
UL Wire Range (AWG)	24-12
Rated IEC Wire Range (Solid) (mm ²)	4

Dimension Information

L x W x H (mm)	85.7 x 71.5
Spacing (mm)	8
L x W x H (in)	3.37 x 2.81
Spacing (inches)	0.315

Specifications

UL Current (Amps)	20
UL Voltage (VAC)	300
Rated UL Wire Size (AWG)	12
IEC Voltage (VAC)	630
IEC Current (Amps)	6.3

Packaging

T&B Order Multiple	50
T&B Inner Pack	50
Package in Units	450
T&B Sold in UOM	Each
T&B Weight Per UOM	6.5 lbs. per 100

Certifications


Approvals	IEC, UL/CSA
-----------	-------------

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com

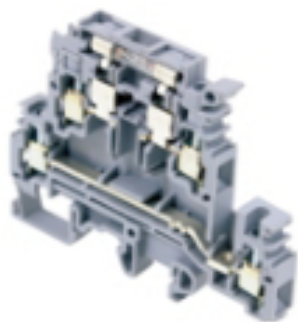

SNA Terminal Blocks

T&B Catalog Number:

011564622

UPC Number:

66201995743

Status:

Active

Description:

Beige, fuse holder terminal blocks, double-deck for 5 x 20 and 5 x 25 mm fuses with 8 mm spacing, 26 Amp rated UL current that accepts 12 AWG UL wire

Features

Includes IP20 protection

Application

For use with applications ranging from standard distribution and control panels, to specialized applications in key industries such as traction, energy, maritime, explosive atmospheres, material handling, etc.

General

Style	Fuse Holder
Color	Beige
Mounting	DIN 1-3
Series	M4/8.D2.SF.V0
Connection Technology	Screw Clamp
UL Wire Range (AWG)	24-12
Rated IEC Wire Range (Solid) (mm ²)	4

Dimension Information

L x W x H (mm)	85.7 x 71.5
Spacing (mm)	8
L x W x H (in)	3.37 x 2.81
Spacing (inches)	0.315

Specifications

UL Current (Amps)	20
UL Voltage (VAC)	300
Rated UL Wire Size (AWG)	12
IEC Voltage (VAC)	630
IEC Current (Amps)	6.3

Packaging

T&B Order Multiple	50
T&B Inner Pack	50
Package in Units	450
T&B Sold in UOM	Each
T&B Weight Per UOM	6.5 lbs. per 100

Certifications

Approvals	IEC, UL/CSA
-----------	-------------

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com