






GE
Lighting

13390 - 15T6

GE appliance 15 watt T6 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Indicator Lights are designed for home appliances and many small fixtures requiring a candelabra base.
- 120 volts
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens
- Lasts 2000 hours
- T6 shape with candelabra base for use in appliances

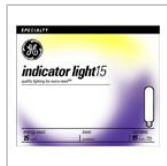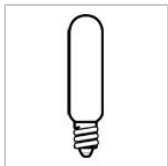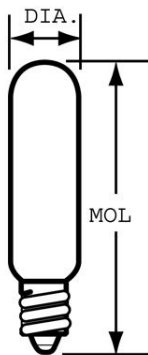

GENERAL CHARACTERISTICS

| | |
|---------------------|-----------------------------|
| Lamp Type | Incandescent - Tubular |
| Bulb | T6 |
| Base | Candelabra Screw (E12) |
| Filament | C-7A |
| Bulb Finish | Clear |
| Rated Life | 2000.0 hrs |
| Bulb Material | Soft glass |
| Primary Application | Appliance;Standard;Standard |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------|-------|
| Initial Lumens | 107.0 |
| Nominal Initial Lumens per Watt | 7 |

ELECTRICAL CHARACTERISTICS

| | |
|---------|-------|
| Wattage | 15.0 |
| Voltage | 120.0 |

DIMENSIONS

| | |
|------------------------------|--------------------|
| Maximum Overall Length (MOL) | 3.0600 in(77.7 mm) |
| Bulb Diameter (DIA) | 0.750 in(19.0 mm) |
| Light Center Length (LCL) | 1.560 in(39.6 mm) |

PRODUCT INFORMATION

| | |
|----------------------------|----------------|
| Product Code | 13390 |
| Description | 15T6 |
| Standard Package | Case |
| Standard Package GTIN | 10043168133903 |
| Standard Package Quantity | 60 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard | 60 |
| Package | |
| UPC | 043168133906 |







GE
Lighting

13390 - 15T6

GE appliance 15 watt T6 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- GE's Indicator Lights are designed for home appliances and many small fixtures requiring a candelabra base.
- 120 volts
- Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens
- Lasts 2000 hours
- T6 shape with candelabra base for use in appliances

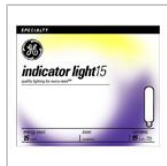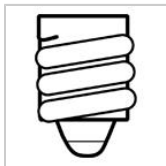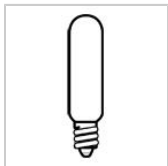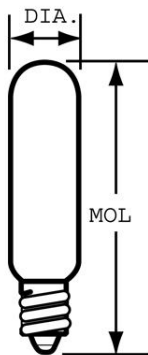

GENERAL CHARACTERISTICS

| | |
|---------------------|-----------------------------|
| Lamp Type | Incandescent - Tubular |
| Bulb | T6 |
| Base | Candelabra Screw (E12) |
| Filament | C-7A |
| Bulb Finish | Clear |
| Rated Life | 2000.0 hrs |
| Bulb Material | Soft glass |
| Primary Application | Appliance;Standard;Standard |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------|-------|
| Initial Lumens | 107.0 |
| Nominal Initial Lumens per Watt | 7 |

ELECTRICAL CHARACTERISTICS

| | |
|---------|-------|
| Wattage | 15.0 |
| Voltage | 120.0 |

DIMENSIONS

| | |
|------------------------------|--------------------|
| Maximum Overall Length (MOL) | 3.0600 in(77.7 mm) |
| Bulb Diameter (DIA) | 0.750 in(19.0 mm) |
| Light Center Length (LCL) | 1.560 in(39.6 mm) |

PRODUCT INFORMATION

| | |
|----------------------------|----------------|
| Product Code | 13390 |
| Description | 15T6 |
| Standard Package | Case |
| Standard Package GTIN | 10043168133903 |
| Standard Package Quantity | 60 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard | 60 |
| Package | |
| UPC | 043168133906 |