




GE  
Lighting

### 47724 - 250R40/1/STG PQ6

GE Heat Lamp Saf-T-Gard® R40 - Shatter-Resistant; Heat Lamp

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- Shatter Resistant Bulb - Protective coating helps contain glass fragments if broken.

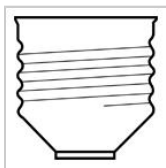

#### GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Reflector
Bulb	R40
Base	Medium Screw (E26)
Filament	C-9
Rated Life	5000.0 hrs
Primary Application	Shatter-Resistant;Heat Lamp10

#### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	2150.0
Nominal Initial Lumens per Watt	8

#### ELECTRICAL CHARACTERISTICS

Wattage	250.0
Voltage	120.0

#### DIMENSIONS

Maximum Overall Length (MOL)	6.5600 in(166.6 mm)
Bulb Diameter (DIA)	2.625 in(66.7 mm)

#### PRODUCT INFORMATION

Product Code	47724
Description	250R40/1/STG PQ6
Standard Package	BUNDLE
Standard Package GTIN	00043168477246
Standard Package Quantity	30
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	30
UPC	043168162579

#### CAUTIONS & WARNINGS

##### Warning

- Risk of Burn
  - Do not touch operating lamp.
- Lamp emits IR radiation which may cause eye injury
  - Do not use on infant, disabled, sleeping, or unconscious person or any person/animal unable to avoid potential injury.
  - Use in fixture approved for this product.
- Risk of Fire
  - Keep combustible materials away from lamp.
  - Use in fixture rated for this product.




GE  
Lighting

### 47724 - 250R40/1/STG PQ6

GE Heat Lamp Saf-T-Gard® R40 - Shatter-Resistant; Heat Lamp

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- Shatter Resistant Bulb - Protective coating helps contain glass fragments if broken.

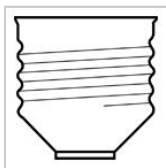

#### GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Reflector
Bulb	R40
Base	Medium Screw (E26)
Filament	C-9
Rated Life	5000.0 hrs
Primary Application	Shatter-Resistant;Heat Lamp10

#### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	2150.0
Nominal Initial Lumens per Watt	8

#### ELECTRICAL CHARACTERISTICS

Wattage	250.0
Voltage	120.0

#### DIMENSIONS

Maximum Overall Length (MOL)	6.5600 in(166.6 mm)
Bulb Diameter (DIA)	2.625 in(66.7 mm)

#### PRODUCT INFORMATION

Product Code	47724
Description	250R40/1/STG PQ6
Standard Package	BUNDLE
Standard Package GTIN	00043168477246
Standard Package Quantity	30
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	30
UPC	043168162579

#### CAUTIONS & WARNINGS

##### Warning

- Risk of Burn
  - Do not touch operating lamp.
- Lamp emits IR radiation which may cause eye injury
  - Do not use on infant, disabled, sleeping, or unconscious person or any person/animal unable to avoid potential injury.
  - Use in fixture approved for this product.
- Risk of Fire
  - Keep combustible materials away from lamp.
  - Use in fixture rated for this product.