






GE  
Lighting

## 14791 - 25T7N

GE appliance 25 watt T7 1-pack

- 120 volts
- Lasts 1000 hours
- T7 shape with intermediate base for use in appliances

• Whether you're cooking it or keeping it fresh GE appliance lights lets you see it. They're specially designed to withstand high or low temperatures and feature a rugged filament that resists vibration, perfect for microwaves, refrigerators and ovens

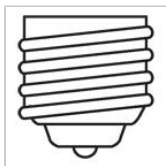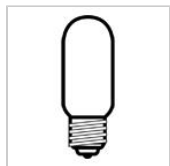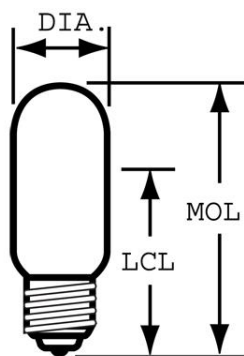

### GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Tubular
Bulb	T7
Base	Intermediate Screw (E17)
Filament	C-7A
Bulb Finish	Clear
Rated Life (Vert)	1000.0 h
Rated Life	1000.0 hrs
Bulb Material	Soft glass
Primary Application	Standard;Standard;Appliance

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens (Vert)	195.0
Initial Lumens	195.0
Initial Lumens (Hor)	7.8
Nominal Initial Lumens per Watt	7

### ELECTRICAL CHARACTERISTICS

Wattage	25.0
Voltage	120.0

### DIMENSIONS

Maximum Overall Length (MOL)	2.2500 in(57.2 mm)
Bulb Diameter (DIA)	0.875 in(22.2 mm)
Light Center Length (LCL)	1.560 in(39.6 mm)

### PRODUCT INFORMATION

Product Code	14791
Description	25T7N
Standard Package	Case
Standard Package GTIN	00043168147910
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard	60
Package	
UPC	043168904667