






GE
Lighting

73788 - 300M/130V-PK6

GE crystal clear 300/266 watt PS25 1-pack

- 2800K soft white light appearance
- Add sparkle to your decorative fixtures with GE crystal clear bulbs. The clear glass and elegant filament design provide a decorative touch in fixtures where the bulb is visible
- Lasts 0.7 years based on 3 hours per day usage
- 4650/6120 lumens providing strong, vibrant™ light
- Estimated yearly energy costs \$36.14/\$32.16 based on 3 hours per day \$0.11 per kWh
- PS25 shape with medium base for use in table lamps and enclosed fixtures

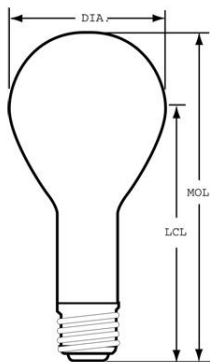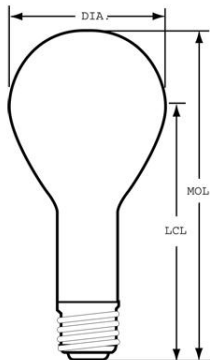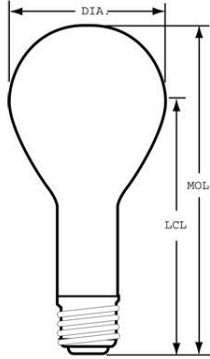

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	PS25
Base	Medium Screw (E26)
Filament	CC-8
Bulb Finish	Clear
Rated Life	750.0 hrs
Bulb Material	Soft glass
Primary Application	Standard

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	6120.0 /4170.0
Nominal Initial Lumens per Watt	23 /15

ELECTRICAL CHARACTERISTICS


Wattage	300.0
Voltage	120.0

DIMENSIONS

Maximum Overall Length (MOL)	6.9300 in(176.0 mm)
Bulb Diameter (DIA)	3.125 in(79.4 mm)
Light Center Length (LCL)	5.180 in(131.6 mm)

PRODUCT INFORMATION

Product Code	73788
Description	300M/130V-PK6
Standard Package	Case
Standard Package GTIN	00043168737883
Standard Package Quantity	6
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168901611

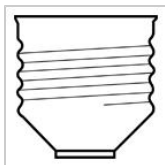









GE
Lighting

73788 - 300M/130V-PK6

GE crystal clear 300/266 watt PS25 1-pack

- 2800K soft white light appearance
- Add sparkle to your decorative fixtures with GE crystal clear bulbs. The clear glass and elegant filament design provide a decorative touch in fixtures where the bulb is visible
- Lasts 0.7 years based on 3 hours per day usage
- 4650/6120 lumens providing strong, vibrant™ light
- Estimated yearly energy costs \$36.14/\$32.16 based on 3 hours per day \$0.11 per kWh
- PS25 shape with medium base for use in table lamps and enclosed fixtures

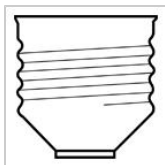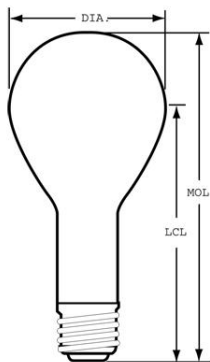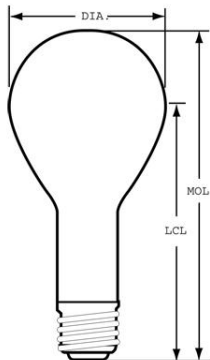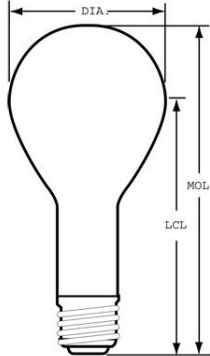

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	PS25
Base	Medium Screw (E26)
Filament	CC-8
Bulb Finish	Clear
Rated Life	750.0 hrs
Bulb Material	Soft glass
Primary Application	Standard

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	6120.0 /4170.0
Nominal Initial Lumens per Watt	23 /15

ELECTRICAL CHARACTERISTICS

Wattage	300.0
Voltage	120.0

DIMENSIONS

Maximum Overall Length (MOL)	6.9300 in(176.0 mm)
Bulb Diameter (DIA)	3.125 in(79.4 mm)
Light Center Length (LCL)	5.180 in(131.6 mm)

PRODUCT INFORMATION

Product Code	73788
Description	300M/130V-PK6
Standard Package	Case
Standard Package GTIN	00043168737883
Standard Package Quantity	6
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168901611

