





GE
Lighting

73790 - 300M/IF/130V-PK3

GE soft white 300/266 watt PS25 1-pack

- GE soft white bulbs provide warm, pleasing everyday light without harsh glares and shadows. Use general purpose GE soft white bulbs in common household fixtures like table lamps, floor lamps, enclosed ceiling fixtures and bare lamp sockets
- Lasts 0.7 years based on 3 hours per day usage
- Estimated yearly energy costs \$36.14/\$32.16 based on 3 hours per day \$0.11 per kWh
- PS25 shape with medium base for use in table lamps and enclosed fixtures
- 2715K soft white light appearance
- 6120/4650 lumens providing strong, vibrant™ light

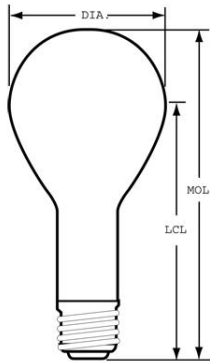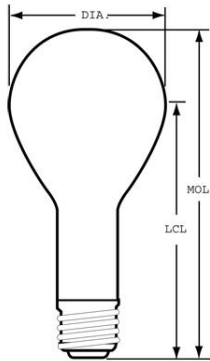

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	PS25
Base	Medium Screw (E26)
Filament	CC-8
Bulb Finish	Inside frost
Rated Life	750.0 hrs
Bulb Material	Soft glass
Primary Application	Standard

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	6120.0 /4170.0
Nominal Initial Lumens per Watt	20 /15

ELECTRICAL CHARACTERISTICS


Wattage	300.0
Voltage	130.0

DIMENSIONS

Maximum Overall Length (MOL)	6.9300 in(176.0 mm)
Bulb Diameter (DIA)	3.125 in(79.4 mm)
Light Center Length (LCL)	5.180 in(131.6 mm)

PRODUCT INFORMATION

Product Code	73790
Description	300M/IF/130V-PK3
Standard Package	Case
Standard Package GTIN	00043168737906
Standard Package Quantity	3
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	3
UPC	043168982627

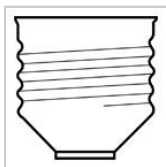





GE
Lighting

73790 - 300M/IF/130V-PK3

GE soft white 300/266 watt PS25 1-pack

- GE soft white bulbs provide warm, pleasing everyday light without harsh glares and shadows. Use general purpose GE soft white bulbs in common household fixtures like table lamps, floor lamps, enclosed ceiling fixtures and bare lamp sockets
- Lasts 0.7 years based on 3 hours per day usage
- Estimated yearly energy costs \$36.14/\$32.16 based on 3 hours per day \$0.11 per kWh
- PS25 shape with medium base for use in table lamps and enclosed fixtures
- 2715K soft white light appearance
- 6120/4650 lumens providing strong, vibrant™ light

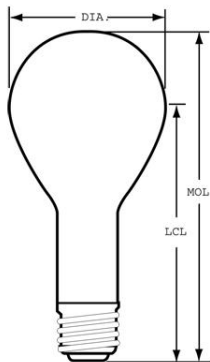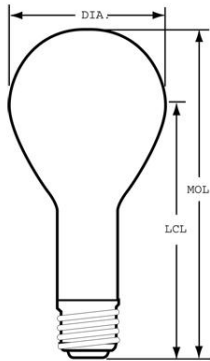

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	PS25
Base	Medium Screw (E26)
Filament	CC-8
Bulb Finish	Inside frost
Rated Life	750.0 hrs
Bulb Material	Soft glass
Primary Application	Standard

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	6120.0 /4170.0
Nominal Initial Lumens per Watt	20 /15

ELECTRICAL CHARACTERISTICS

Wattage	300.0
Voltage	130.0

DIMENSIONS

Maximum Overall Length (MOL)	6.9300 in(176.0 mm)
Bulb Diameter (DIA)	3.125 in(79.4 mm)
Light Center Length (LCL)	5.180 in(131.6 mm)

PRODUCT INFORMATION

Product Code	73790
Description	300M/IF/130V-PK3
Standard Package	Case
Standard Package GTIN	00043168737906
Standard Package Quantity	3
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	3
UPC	043168982627

