


Electrical Construction Supplies

Pipe Mounting Wireholders

Designed especially for service entrance masts. May be used in other applications requiring insulator attachment to pipe. All ferrous metal parts are hot dipped galvanized. Assembly of parts after galvanizing assures all surfaces are protected from rust and corrosion.

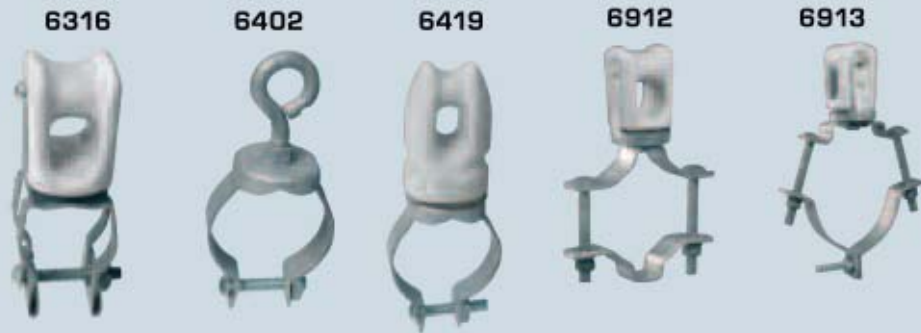

Catalog No.	Style	Pipe Size (inches)	Std. Pkg.	Wt. per 100
6319	1929	1 1/4 - 1 1/2	50	94
6419	1929	2	50	94
6316	1986	1 1/4 - 1 1/2	50	94
6416	1986	2	50	94
6516	1986	2 1/2	50	100
6912	"Universal" Reinforced	1 1/4 - 2 1/2	25	168
6913	"Universal" Reinforced	3" - 4	10	175
6402	Triplex Hanger	2	50	40

Clevises

Clevises are suitable for dead-ending service drops at either end and for general use in commercial and industrial applications. All steel components are hot dipped galvanized in accordance with latest applicable ASTM specifications. Clevis and insulator are completely assembled and packed in convenient standard package quantities.



Catalog No.	Insulators Hole	Extension (inches)	Mounting (inches)	Steel Size (inches)	Std. Pkg.	Wt. per 100
4170	5107	6 1/2	11/16	3/16 x 3/4	25	132
4172	5107	4	11/16	3/16 x 1 1/2	25	152
4111	5101	4	11/16 Sq.	1/8 x 1/2 x 1	10	250
4112	5101	4	11/16 x 7/8	3/16 x 3	10	360
4113	5101	5	3/4	1/8 x 1 3/4	10	260

Wedge Grip Clamps

These clamps can be installed at any point on the conductor, allowing for sag before the conductor is cut. Made with aluminum wedge and shell with stainless steel solid bail or nylon jacketed galvanized steel aircraft strand flexible bail.




Catalog No.	Bail Type	Conductor Size		Bail Length (inches)	Std. Pkg.	Wt. per 100
		Min. ACSR	Max. ACSR			
1061	Solid	6	2	6 1/2	50	15
1062	Solid	4	1/D	6 1/2	25	26
1063	Solid	2/D	4/D	6 1/2	25	33
1061F	Flexible	6	2	12	50	16
1062F	Flexible	4	1/D	14	25	28
1063F	Flexible	2/D	4/D	14	25	36

* Standard insulator glaze "Skyline" ANSI-70, Munsell 5 BG 7.0/D.4.

Electrical Construction Supplies

Pipe Mounting Wireholders

Designed especially for service entrance masts. May be used in other applications requiring insulator attachment to pipe. All ferrous metal parts are hot dipped galvanized. Assembly of parts after galvanizing assures all surfaces are protected from rust and corrosion.

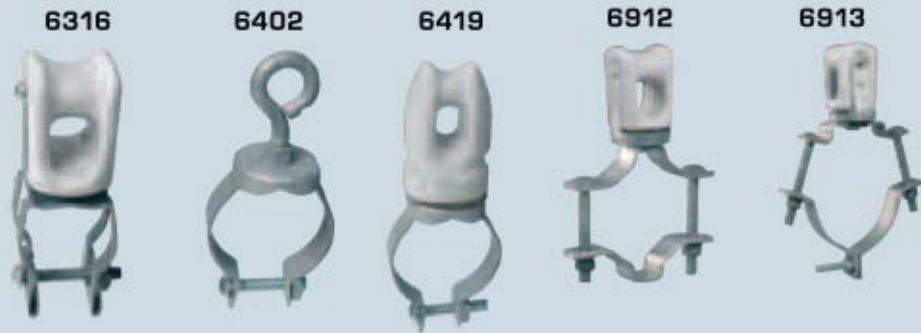

Catalog No.	Style	Pipe Size (inches)	Std. Pkg.	Wt. per 100
6319	1929	1 1/4 - 1 1/2	50	94
6419	1929	2	50	94
6316	1986	1 1/4 - 1 1/2	50	94
6416	1986	2	50	94
6516	1986	2 1/2	50	100
6912	"Universal" Reinforced	1 1/4 - 2 1/2	25	168
6913	"Universal" Reinforced	3" - 4	10	175
6402	Triplex Hanger	2	50	40

Clevises

Clevises are suitable for dead-ending service drops at either end and for general use in commercial and industrial applications. All steel components are hot dipped galvanized in accordance with latest applicable ASTM specifications. Clevis and insulator are completely assembled and packed in convenient standard package quantities.



Catalog No.	Insulators Hole	Extension (inches)	Mounting (inches)	Steel Size (inches)	Std. Pkg.	Wt. per 100
4170	5107	6 1/2	11/16	3/16 x 3/4	25	132
4172	5107	4	11/16	3/16 x 1 1/2	25	152
4111	5101	4	11/16 Sq.	1/8 x 1/2 x 1	10	250
4112	5101	4	11/16 x 7/8	3/16 x 3	10	360
4113	5101	5	3/4	1/8 x 1 3/4	10	260

Wedge Grip Clamps

These clamps can be installed at any point on the conductor, allowing for sag before the conductor is cut. Made with aluminum wedge and shell with stainless steel solid bail or nylon jacketed galvanized steel aircraft strand flexible bail.



Catalog No.	Bail Type	Conductor Size		Bail Length (inches)	Std. Pkg.	Wt. per 100
		Min. ACSR	Max. ACSR			
1061	Solid	6	2	6 1/2	50	15
1062	Solid	4	1/0	6 1/2	25	26
1063	Solid	2/0	4/0	6 1/2	25	33
1061F	Flexible	6	2	12	50	16
1062F	Flexible	4	1/0	14	25	28
1063F	Flexible	2/0	4/0	14	25	36

* Standard insulator glaze "Skyline" ANSI-70, Munsell 5 BG 7.0/0.4.