


## Squeeze Type - Zinc

### Images

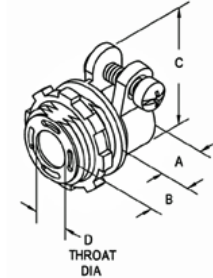

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-5/16  
Dimension B in Inches: 11/16  
Dimension C in Inches: 2-1/4  
Dimension D in Inches: 1.170

### Application

Used to connect steel flexible metal conduit to box or enclosure. Insulator rated 105 degree C.

### Product Information

Material: Zinc Die Cast  
Finish: Ball burnished, mirror smooth

### Certifications & Codes:

Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121419

**Catalog ID:** 412-DC12

**UPC Number:** 781747164124

**Description:** Connector, Squeeze, Zinc Die Cast, Insulated Throat, Trade Size 1 1/4 Inch

**Application:** Used to connect steel flexible metal conduit to box or enclosure. Insulator rated 105 degree C.

**Trade Size:** 1-1/4"

**Country of Manufacture:** USA

**Std Pkg Qty:** 100

**Unit Qty:** 10