


| CAT#     | A    | B    |
|----------|------|------|
| 751/751i | .68  | 1.02 |
| 751A     | 1.00 | 1.02 |
| 752A     | 1.00 | 1.29 |
| 752/752i | .75  | 1.29 |
| 753/753i | .87  | 1.53 |
| 754/754i | .94  | 1.89 |
| 755/755i | .91  | 2.30 |
| 756/756i | 1.07 | 2.88 |
| 757/757i | 1.38 | 3.39 |
| 758/758i | 1.44 | 4.06 |
| 759/759i | 1.47 | 4.61 |
| 760/760i | 1.47 | 5.15 |

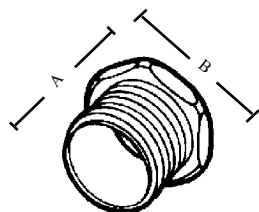

| CAT#       | A     | B    |
|------------|-------|------|
| 751M/751Mi | .68   | 1.02 |
| 752M/752Mi | .75   | 1.29 |
| 753M/753Mi | .87   | 1.53 |
| 754M/754Mi | .94   | 1.89 |
| 755M/755Mi | .91   | 2.30 |
| 756M/756Mi | 1.07  | 2.88 |
| 757M/757Mi | 1.38  | 3.39 |
| 758M/758Mi | 1.44  | 4.06 |
| 759M/759Mi | 1.47  | 4.61 |
| 760M/760Mi | 1.47  | 5.15 |
| 760A       | 2.352 | 6.0  |
| 760B       | 2.180 | 7.0  |

## RIGID CONDUIT NIPPLES

### ZINC DIE CAST

| TOPAZ CAT # | UPC#  | SIZE        | UNIT CTN | SHIP CASE | WT/ CASE |
|-------------|-------|-------------|----------|-----------|----------|
| 751         | 17860 | 1/2"        | 100      | 1000      | 40       |
| 751A        | 17859 | 1/2" x 1" L | —        | 100       | 5        |
| 752         | 17870 | 3/4"        | 50       | 500       | 30       |
| 752A        | 17851 | 3/4" x 1" L | —        | 50        | 25       |
| 753         | 17880 | 1"          | 25       | 250       | 25       |
| 754         | 17890 | 1 1/4"      | 25       | 250       | 35       |
| 755         | 17900 | 1 1/2"      | 25       | 100       | 20       |
| 756         | 17910 | 2"          | 10       | 40        | 13       |
| 757         | 17920 | 2 1/2"      | 10       | 40        | 17       |
| 758         | 17930 | 3"          | 10       | 40        | 22       |
| 759         | 17940 | 3 1/2"      | 10       | 40        | 27       |
| 760         | 17950 | 4"          | 5        | 20        | 14       |

### INSULATED THROAT

|      |       |        |     |      |    |
|------|-------|--------|-----|------|----|
| 751i | 17861 | 1/2"   | 100 | 1000 | 40 |
| 752i | 17871 | 3/4"   | 50  | 500  | 30 |
| 753i | 17881 | 1"     | 25  | 250  | 25 |
| 754i | 17891 | 1 1/4" | 25  | 250  | 35 |
| 755i | 17901 | 1 1/2" | 25  | 100  | 20 |
| 756i | 17911 | 2"     | 10  | 40   | 13 |
| 757i | 17921 | 2 1/2" | 10  | 40   | 17 |
| 758i | 17931 | 3"     | 10  | 40   | 22 |
| 759i | 17941 | 3 1/2" | 10  | 40   | 27 |
| 760i | 17951 | 4"     | 5   | 20   | 14 |

### MALLEABLE IRON

|      |       |        |     |      |     |
|------|-------|--------|-----|------|-----|
| 751M | 17862 | 1/2"   | 100 | 1000 | 5   |
| 752M | 17872 | 3/4"   | 50  | 500  | 7   |
| 753M | 17882 | 1"     | 25  | 250  | 12  |
| 754M | 17892 | 1 1/4" | 25  | 250  | 15  |
| 755M | 17902 | 1 1/2" | 25  | 250  | 22  |
| 756M | 17912 | 2"     | 10  | 40   | 35  |
| 757M | 17922 | 2 1/2" | 10  | 40   | 76  |
| 758M | 17932 | 3"     | 10  | 40   | 101 |
| 759M | 17942 | 3 1/2" | 10  | 40   | 124 |
| 760M | 17943 | 4"     | 5   | 20   | 200 |
| 760A | 17952 | 5"     | —   | 1    | 75  |
| 760B | 17953 | 6"     | —   | 1    | 65  |

### INSULATED THROAT

|       |       |        |     |      |     |
|-------|-------|--------|-----|------|-----|
| 751Mi | 17863 | 1/2"   | 100 | 1000 | 7   |
| 752Mi | 17873 | 3/4"   | 50  | 500  | 7   |
| 753Mi | 17883 | 1"     | 25  | 250  | 12  |
| 754Mi | 17893 | 1 1/4" | 25  | 250  | 15  |
| 755Mi | 17903 | 1 1/2" | 25  | 250  | 22  |
| 756Mi | 17913 | 2"     | 10  | 40   | 35  |
| 757Mi | 17923 | 2 1/2" | 10  | 40   | 76  |
| 758Mi | 17933 | 3"     | 10  | 40   | 101 |
| 759Mi | 17943 | 3 1/2" | 10  | 40   | 124 |
| 760Mi | 17944 | 4"     | 5   | 20   | 200 |



E148716




E148716




E148716



E148716

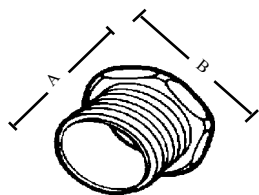

| CAT#     | A    | B    |
|----------|------|------|
| 751/751i | .68  | 1.02 |
| 751A     | 1.00 | 1.02 |
| 752A     | 1.00 | 1.29 |
| 752/752i | .75  | 1.29 |
| 753/753i | .87  | 1.53 |
| 754/754i | .94  | 1.89 |
| 755/755i | .91  | 2.30 |
| 756/756i | 1.07 | 2.88 |
| 757/757i | 1.38 | 3.39 |
| 758/758i | 1.44 | 4.06 |
| 759/759i | 1.47 | 4.61 |
| 760/760i | 1.47 | 5.15 |

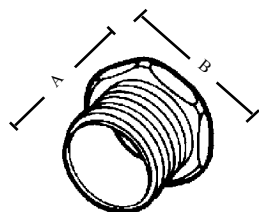

| CAT#       | A     | B    |
|------------|-------|------|
| 751M/751Mi | .68   | 1.02 |
| 752M/752Mi | .75   | 1.29 |
| 753M/753Mi | .87   | 1.53 |
| 754M/754Mi | .94   | 1.89 |
| 755M/755Mi | .91   | 2.30 |
| 756M/756Mi | 1.07  | 2.88 |
| 757M/757Mi | 1.38  | 3.39 |
| 758M/758Mi | 1.44  | 4.06 |
| 759M/759Mi | 1.47  | 4.61 |
| 760M/760Mi | 1.47  | 5.15 |
| 760A       | 2.352 | 6.0  |
| 760B       | 2.180 | 7.0  |

## RIGID CONDUIT NIPPLES

### ZINC DIE CAST

| TOPAZ CAT # | UPC#  | SIZE        | UNIT CTN | SHIP CASE | WT/ CASE |
|-------------|-------|-------------|----------|-----------|----------|
| 751         | 17860 | 1/2"        | 100      | 1000      | 40       |
| 751A        | 17859 | 1/2" x 1" L | —        | 100       | 5        |
| 752         | 17870 | 3/4"        | 50       | 500       | 30       |
| 752A        | 17851 | 3/4" x 1" L | —        | 50        | 25       |
| 753         | 17880 | 1"          | 25       | 250       | 25       |
| 754         | 17890 | 1 1/4"      | 25       | 250       | 35       |
| 755         | 17900 | 1 1/2"      | 25       | 100       | 20       |
| 756         | 17910 | 2"          | 10       | 40        | 13       |
| 757         | 17920 | 2 1/2"      | 10       | 40        | 17       |
| 758         | 17930 | 3"          | 10       | 40        | 22       |
| 759         | 17940 | 3 1/2"      | 10       | 40        | 27       |
| 760         | 17950 | 4"          | 5        | 20        | 14       |

### INSULATED THROAT

|      |       |        |     |      |    |
|------|-------|--------|-----|------|----|
| 751i | 17861 | 1/2"   | 100 | 1000 | 40 |
| 752i | 17871 | 3/4"   | 50  | 500  | 30 |
| 753i | 17881 | 1"     | 25  | 250  | 25 |
| 754i | 17891 | 1 1/4" | 25  | 250  | 35 |
| 755i | 17901 | 1 1/2" | 25  | 100  | 20 |
| 756i | 17911 | 2"     | 10  | 40   | 13 |
| 757i | 17921 | 2 1/2" | 10  | 40   | 17 |
| 758i | 17931 | 3"     | 10  | 40   | 22 |
| 759i | 17941 | 3 1/2" | 10  | 40   | 27 |
| 760i | 17951 | 4"     | 5   | 20   | 14 |

### MALLEABLE IRON

|      |       |        |     |      |     |
|------|-------|--------|-----|------|-----|
| 751M | 17862 | 1/2"   | 100 | 1000 | 5   |
| 752M | 17872 | 3/4"   | 50  | 500  | 7   |
| 753M | 17882 | 1"     | 25  | 250  | 12  |
| 754M | 17892 | 1 1/4" | 25  | 250  | 15  |
| 755M | 17902 | 1 1/2" | 25  | 250  | 22  |
| 756M | 17912 | 2"     | 10  | 40   | 35  |
| 757M | 17922 | 2 1/2" | 10  | 40   | 76  |
| 758M | 17932 | 3"     | 10  | 40   | 101 |
| 759M | 17942 | 3 1/2" | 10  | 40   | 124 |
| 760M | 17943 | 4"     | 5   | 20   | 200 |
| 760A | 17952 | 5"     | —   | 1    | 75  |
| 760B | 17953 | 6"     | —   | 1    | 65  |

### INSULATED THROAT

|       |       |        |     |      |     |
|-------|-------|--------|-----|------|-----|
| 751Mi | 17863 | 1/2"   | 100 | 1000 | 7   |
| 752Mi | 17873 | 3/4"   | 50  | 500  | 7   |
| 753Mi | 17883 | 1"     | 25  | 250  | 12  |
| 754Mi | 17893 | 1 1/4" | 25  | 250  | 15  |
| 755Mi | 17903 | 1 1/2" | 25  | 250  | 22  |
| 756Mi | 17913 | 2"     | 10  | 40   | 35  |
| 757Mi | 17923 | 2 1/2" | 10  | 40   | 76  |
| 758Mi | 17933 | 3"     | 10  | 40   | 101 |
| 759Mi | 17943 | 3 1/2" | 10  | 40   | 124 |
| 760Mi | 17944 | 4"     | 5   | 20   | 200 |



E148716



E148716



E148716



E148716