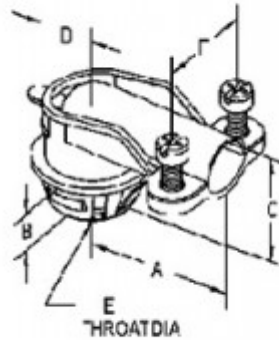


E-Z LOCK® 90° Connector Double Screw Design

90 Degree Connector for use with 3/8" Flexible Metal Conduit. Non-Insulated. Recommended cable types: Diameter for 12/2 (.550" Ø min) to 10/3 (.610" Ø max)

[Download Photo](#)[Download Drawing](#)[Download Drawing](#)

Product details

Catalog Number:	850SP
UPC Number:	78174771801
Primary Materials:	Zinc Die Cast
Finish:	Ball Burnished, Mirror Smooth
Trade Size:	3/8"
Unit Quantity:	25
Standard Package Quantity:	250

Dimensions

Trade Size:	3/8"
Dimensions A:	1-7/16
Dimensions B:	7/16
Dimensions C:	1-1/8
Dimensions D:	9/16
Dimensions E:	13/32

Certifications & Codes

Federal Specification Number: A-A-50552

UL File Number: E9391

UNSPSC: 39121438

Nema Standard: FB1

UL Standard: UL-514B

Country Of Manufacture: USA