


Eaton B2610ZN

Catalog Number: B2610ZN

Eaton B-Line series Twist Ear pipe clamp, 0.0677" H x 6.7030" L x 1.25" W, Steel, 500 Lbs load cap

General specifications

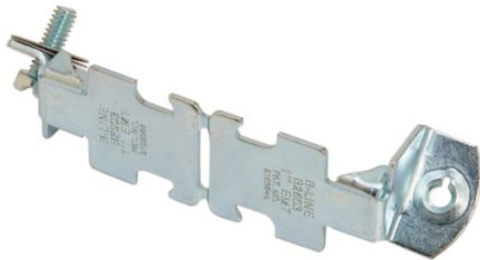

| | |
|--|----------------------|
| Product Name | Catalog Number |
| Eaton B-Line series Twist Ear pipe clamp B2610ZN | |
| UPC | Product Length/Depth |
| 781011026448 | 6.703 in |
| Product Height | Product Width |
| 0.0677 in | 1.25 in |
| Product Weight | Certifications |
| 0.156 lb | Not Applicable |

Model

Special features

Easier access bolt can be tightened directly

Type

Twist ear pipe clamp

Load rating/capacity

Load capacity

500 lbs

Material/finish

Material

Steel

Resources

Catalogs

[Pipe clamps and hangers catalog section](#)

Specifications and datasheets

[Eaton Specification Sheet - B2610ZN](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)