


B6IC-100

6" Universal 100W IC Housing Double Wall

LAMP WATTAGE: (1) MAX. 75W R/PAR40/PAR38, 75W R/PAR30, 60W A19, 65W BR30



DESIGNED FOR 2" X 8" JOIST CONSTRUCTION

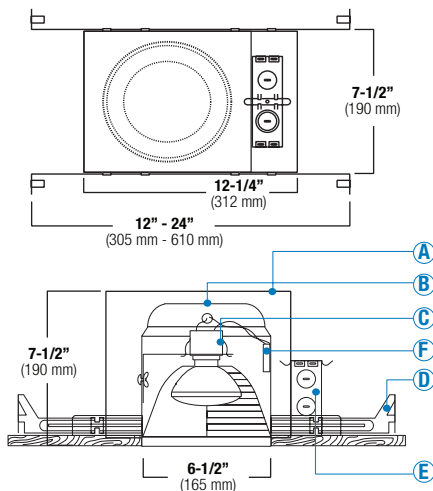

ITEM SELECTOR: (Please check the boxes below for the option desired)

TYPE	AIR-SHUT	OPTION	TRIM TYPE								BAFFLE	REFLECTOR	TRIM/RING	GLASS	
B6IC-100	<input type="checkbox"/> AT	<input type="checkbox"/> (W) With quick connects	<input type="checkbox"/> B630	<input type="checkbox"/> B608	<input type="checkbox"/> B601	<input type="checkbox"/> B637	<input type="checkbox"/> B615	<input type="checkbox"/> B622	<input type="checkbox"/> B689 <input type="checkbox"/> B680	<input type="checkbox"/> W	<input type="checkbox"/> CL	<input type="checkbox"/> WH	<input type="checkbox"/> Green		
			<input type="checkbox"/> B640	<input type="checkbox"/> B602	<input type="checkbox"/> B601L	<input type="checkbox"/> B643	<input type="checkbox"/> B633	<input type="checkbox"/> B623		<input type="checkbox"/> P	<input type="checkbox"/> RG	<input type="checkbox"/> BK	<input type="checkbox"/> Yellow		
			<input type="checkbox"/> B620	<input type="checkbox"/> B609	<input type="checkbox"/> B605	<input type="checkbox"/> B658	<input type="checkbox"/> B634	<input type="checkbox"/> B625		<input type="checkbox"/> SN	<input type="checkbox"/> W	<input type="checkbox"/> SN	<input type="checkbox"/> Pink		
			<input type="checkbox"/> B631	<input type="checkbox"/> B619	<input type="checkbox"/> B605L	<input type="checkbox"/> B659	<input type="checkbox"/> B649	<input type="checkbox"/> B624		<input type="checkbox"/> CP	<input type="checkbox"/> MB	<input type="checkbox"/> CP	<input type="checkbox"/> Brown		
			<input type="checkbox"/> B632	<input type="checkbox"/> B646	<input type="checkbox"/> B606	<input type="checkbox"/> B675	<input type="checkbox"/> AF633	<input type="checkbox"/> B681		<input type="checkbox"/> BZ	<input type="checkbox"/> BZ	<input type="checkbox"/> CH	<input type="checkbox"/> Navy Blue		
			<input type="checkbox"/> AF637	<input type="checkbox"/> B616	<input type="checkbox"/> B606L	<input type="checkbox"/> B676	<input type="checkbox"/> B225	<input type="checkbox"/> B687		<input type="checkbox"/> CP	<input type="checkbox"/> PB	<input type="checkbox"/> Orange			
			<input type="checkbox"/> AF631	<input type="checkbox"/> B663	<input type="checkbox"/> B635	<input type="checkbox"/> B612	<input type="checkbox"/> B653	<input type="checkbox"/> B682		<input type="checkbox"/> SN	<input type="checkbox"/> BZ	<input type="checkbox"/> Blue			
			<input type="checkbox"/> AF639	<input type="checkbox"/> B664	<input type="checkbox"/> B636	<input type="checkbox"/> B645	<input type="checkbox"/> B651	<input type="checkbox"/> B693		<input type="checkbox"/> SHZ	<input type="checkbox"/> White				
			<input type="checkbox"/> AF640	<input type="checkbox"/> B673	<input type="checkbox"/> B641	<input type="checkbox"/> B648	<input type="checkbox"/> B611	<input type="checkbox"/> B694			<input type="checkbox"/> Red				
			<input type="checkbox"/> B610	<input type="checkbox"/> B674	<input type="checkbox"/> B642	<input type="checkbox"/> B652	<input type="checkbox"/> B647	<input type="checkbox"/> B688							
			<input type="checkbox"/> B607	<input type="checkbox"/> B683	<input type="checkbox"/> B656	<input type="checkbox"/> B603	<input type="checkbox"/> B644	<input type="checkbox"/> B685							
			<input type="checkbox"/> B627	<input type="checkbox"/> B684	<input type="checkbox"/> B657	<input type="checkbox"/> B604	<input type="checkbox"/> B650	<input type="checkbox"/> B696							

Specifications:

B6IC-100

AIR-SHUT - OPTION - TRIM TYPE - BAFFLE - REFLECTOR - TRIM/RING - GLASS

Sample of Catalog Number: B6IC-100-AT-W-B630-W-WH

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.



Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011

Catalog Number:

Project Name:

Type:

Note:



DESCRIPTION

For new construction. Thermally protected, IC rated specification grade recessed housing. Accommodates up to 100W R40, par38, 75W PAR30, R30 lamps, 60W A19 lamps and 65W BR30 lamps. Furnished with pre-installed adjustable bar hangers. Junction box is provided with four 1/2" KOs, one 3/4" KO and four Romex knockouts with strain relief.

SPECIFICATION

A. OUTER HOUSING - Die formed aluminum construction for maximum heat dissipating air chamber on top of the housing. Junction box could be accessed from inside and outside housing.


B. INNER HOUSING - Die-formed all aluminum construction for maximum heat dissipation and rust protection. Adjusts vertically in plaster frame to accommodate 1/2" to 1-3/8" ceiling.

C. SOCKET - Medium base screw shell porcelain socket preinstalled on adjustable mounting bracket is designed to allow usage of different lamp types, as well as proper and consistent lamp positioning.

D. BAR HANGERS - Preinstalled bar hangers allow housing to be positioned and locked at any point within a 24" joist span. They can be positioned on either the long or short axis of the housing and can be shortened for 12" joists. They contain a double-headed real nail for 20° downward angle for better contact, and the 90° pivoting mounting plate makes installation fast and accurate. Bar hangers can fit onto T-Bar spline with additional slots and holes for special mounting methods if necessary.

E. JUNCTION BOX - through-branch circuit wiring and has four 1/2" KOs, one 3/4" KO and four Romex knockouts with true pry-out slots and strain clamps.

F. THERMAL PROTECTION - Standard thermal protection device guards against improper installation, overlamping and misuse of insulation material.

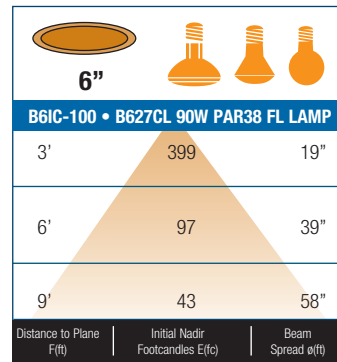

BEAM DIA. MEASURED AT 50% OF NADIR F.C.

FEATURES

- Thermally Protected IC housing.
- Adjustable socket bracket.
- Wire through junction box.
- Preinstalled adjustable bar hanger.
- Dependable, favorable design and effortless installation.
- 7-1/2" height allows use in 2" x 8" joist construction.
- Special screw on the frame locks bar hangers in place which prevents the housing from any movement once installed.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.

OPTIONS

AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.

6" Incandescent Trims

(LAMP WATTAGE: (1) MAX. 75W R/PAR40/PAR38, 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B630CP-CP
METAL STEPPED BAFFLE R30/PAR30



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

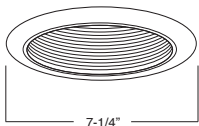


B640SN-SN
METAL STEPPED BAFFLE R40/PAR38




BAFFLE FINISH:
W, P, SN, CP, BZ


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

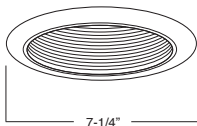


B620-ORANGE
GLASS TRIM

 

GLASS FINISH:
GREEN, YELLOW,
PINK, BROWN, NAVY
BLUE, ORANGE,
WHITE, RED

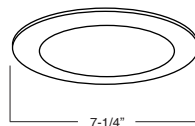


 B631P-WH
R30 PREMIUM PHENOLIC BAFFLE / METAL RING



BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

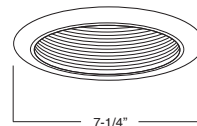


B632W-WH
R40 PREMIUM PHENOLIC BAFFLE / METAL RING



BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

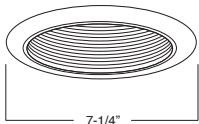

AF637W-WH
SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
SN-SN, CP-CP, BZ-BZ

AF631W-WH
SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
SN-SN, CP-CP, BZ-BZ

AF639W-WH
SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH


MATT WHITE FINISH

AF640W-WH
DEEP SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, SN-SN,
CP-CP, BZ-BZ

B610P-RG-WH
CONE REFLECTOR/BAFFLE TRIM

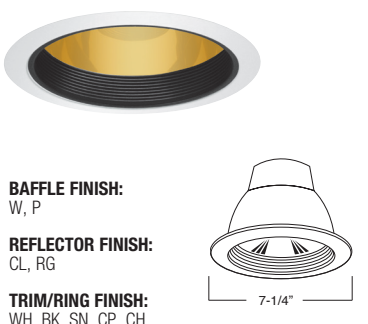


BAFFLE FINISH:
W, P

REFLECTOR FINISH:
CL, RG

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


B607CP-WH
REFLECTOR R/PAR30

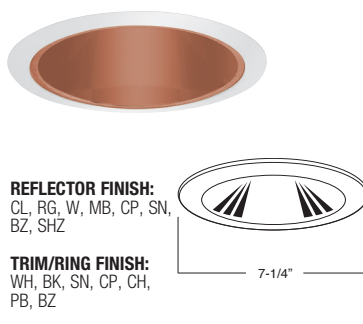

REFLECTOR FINISH:
CL, RG, W, MB, CP, SN,
BZ, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

B627RG-WH
REFLECTOR R40/PAR38

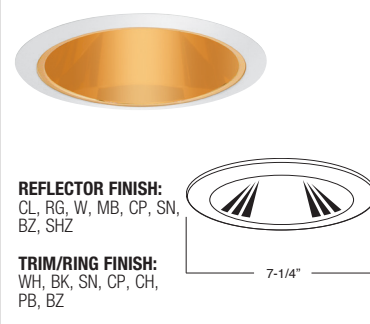

REFLECTOR FINISH:
CL, RG, W, MB, CP, SN,
BZ, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

B608CL-WH
CONE REFLECTOR A19



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN,
BZ, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

B602SN
EYEBALL



TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

B609W-WH
REGRESSED EYEBALL WITH BAFFLE




BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

B619RG-PB
REGRESSED EYEBALL WITH REFLECTOR

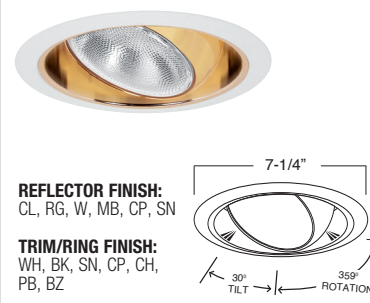

REFLECTOR FINISH:
CL, RG, W, MB, CP, SN

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAX. 75W R/PAR40/PAR38, 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:


Project Name:

Type:

Note:


elite LIGHTING

B646P-WH
EYEBALL WITH BAFFLE

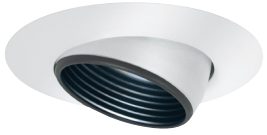

BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH

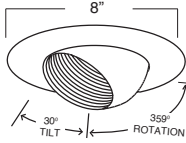


B616W-WH
PAR20 REGRESSED EYEBALL W/ BAFFLE




BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ


EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

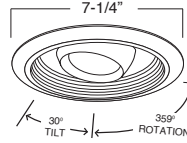


B663PB
PAR30 GIMBAL RING

 


TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

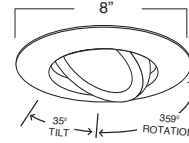

B664CP
PAR38 GIMBAL RING

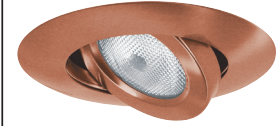

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

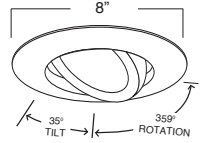


B673P-WH
PAR30 BAFFLE W/ GIMBAL RING



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

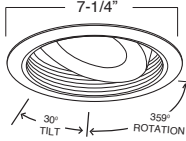


B674W-WH
PAR38 BAFFLE W/ GIMBAL RING




BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

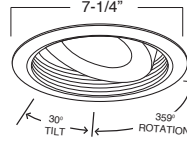


 B683CL-WH
PAR30 REFLECTOR W/ GIMBAL RING



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

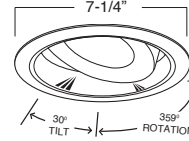


B684RG-WH
PAR38 REFLECTOR W/ GIMBAL RING



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

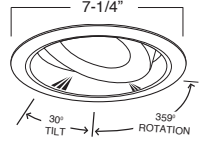


B601CP
METAL ALBALITE LENS



LENS:
ALBALITE

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

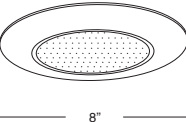


B601L
PLASTIC ALBALITE LENS



LENS:
ALBALITE

TRIM/RING FINISH:
WHITE PLASTIC

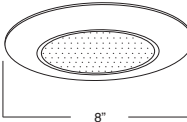


B605PB
METAL FRESNEL LENS



LENS:
FRESNEL

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

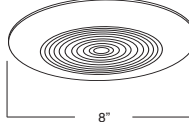


B605L
PLASTIC FRESNEL LENS



LENS:
FRESNEL

TRIM/RING FINISH:
WHITE PLASTIC

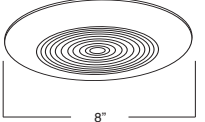


B606CP
METAL DROP OPAL LENS



LENS:
DROP OPAL

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

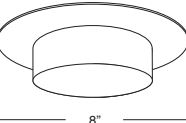


B606L
PLASTIC DROP OPAL LENS



LENS:
DROP OPAL

TRIM/RING FINISH:
WHITE PLASTIC

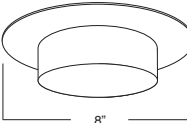


B635P-WH
BAFFLE W/ ALBALITE LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

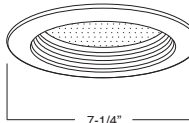


B636W-WH
BAFFLE W/ FRESNEL LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

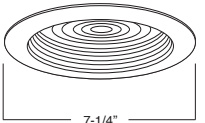

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAX. 75W R/ PAR40/ PAR38, 75W R/ PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B641RG-WH
REFLECTOR W/ ALBALITE LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

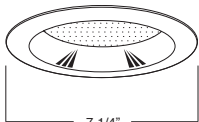

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B642CL-WH
REFLECTOR W/ FRESNEL LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

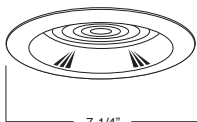

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B656W-WH
BAFFLE W/ FROSTED DOME SHOWER LENS



FOR
WET
LOCATION


BAFFLE FINISH:
W, P, SN, CP, BZ

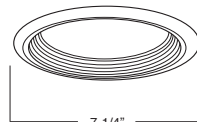

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

7-1/4"

 B657CL-WH
REFLECTOR W/ FROSTED DOME SHOWER LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ



TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B637W-WH
BAFFLE W/ DROP OPAL LENS



FOR
WET
LOCATION

BAFFLE FINISH:
W, P, SN, CP, BZ

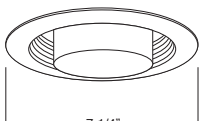

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B643RG-WH
REFLECTOR W/ DROP OPAL LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

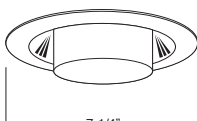

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B658CL-WH
REFLECTOR W/ PRISMATIC LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

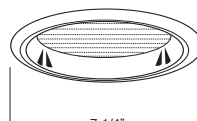

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B659CL-WH
REFLECTOR W/ FROSTED LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

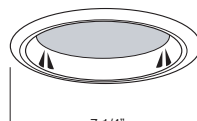

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B675W-WH
BAFFLE W/ PRISMATIC LENS



FOR
WET
LOCATION

BAFFLE FINISH:
W, P, SN, CP, BZ

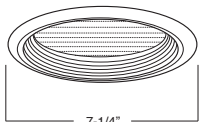

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B676W-WH
BAFFLE W/ FROSTED LENS



FOR
WET
LOCATION

BAFFLE FINISH:
W, P, SN, CP, BZ

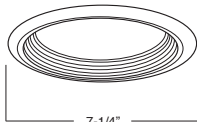

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B612WH
SMOOTH FROST DOME SHOWER LENS



FOR
WET
LOCATION

LENS:
FROSTED

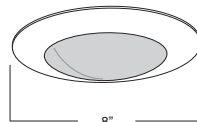

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


8"

B645WH
DESIGNER POINT SHOWER LENS



FOR
WET
LOCATION

LENS:
FROSTED/CLEAR

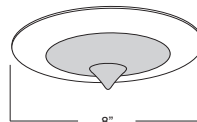

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


8"

B648WH
DESIGNER CONE SHOWER LENS



FOR
WET
LOCATION

LENS:
FROSTED

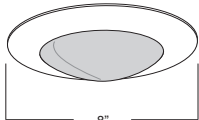

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


8"

B652WH
SMOOTH FROST SHOWER LENS



FOR
WET
LOCATION


LENS:
FROSTED

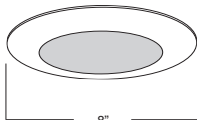


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

8"

 B603CP
R/ PAR30 OPEN TRIM




TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

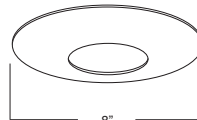


8"

 B604PB
R40/ PAR38 OPEN TRIM



TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

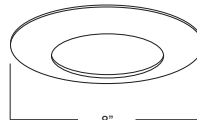

8"

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAX. 75W R/PAR40/PAR38, 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:


Note:

elite LIGHTING

B615WH
DESIGNER PINHOLE




TRIM/RING FINISH:
WH, BK

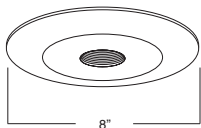

B633WH
R/PAR30 SPLAY TRIM




TRIM/RING FINISH:
WH, BK

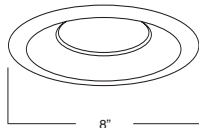

B634WH
R40/PAR38 SPLAY TRIM



TRIM/RING FINISH:
WH, BK

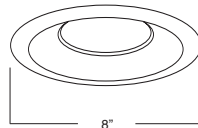


B649RG-WH
PAR20 REFLECTOR




REFLECTOR FINISH:
CL, RG, W, MB, CP, SN


TRIM/RING FINISH:
WH, BK

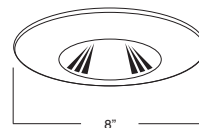

AF633CH
R/PAR30 OPEN TRIM

 

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

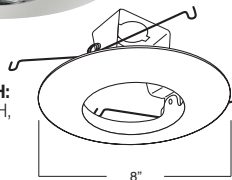


B225WH
OPEN TRIM STEPPED BAFFLE




BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH

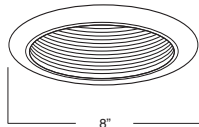


B653W-WH
BAFFLE WITH BAFFLE

 


BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB

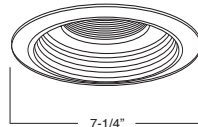


B651P-WH
PAR20 STEPPED BAFFLE

 

BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK

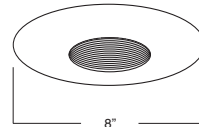


B611W-WH
PAR30 BAFFLE WALL WASH



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, SN-SN, CP-CP, BZ-BZ

COVER FINISH:
WH, BK

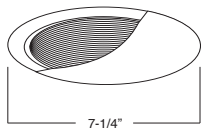


B647P-WH
DESIGNER BAFFLE WALL WASH PAR20



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH

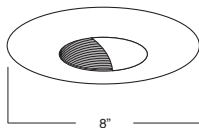


B644RG-WH
DESIGNER REFLECTOR WALL WASH PAR20



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN


TRIM/RING FINISH:
WH

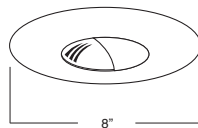

B650WH
DESIGNER WALL WASH



TRIM/RING FINISH:
WH

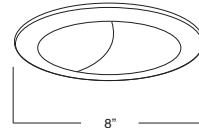


B622RG-WH
R/PAR30 WALL WASH REFLECTOR



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN, SHZ

COVER FINISH:
WH

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

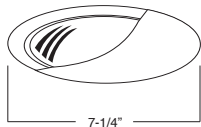


B623MB-WH
R40/PAR38 WALL WASH REFLECTOR



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN, SHZ

COVER FINISH:
WH

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

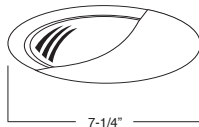


B625CL-WH
A-19 CONE REFLECTOR WALL WASH



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN, SHZ

COVER FINISH:
WH

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

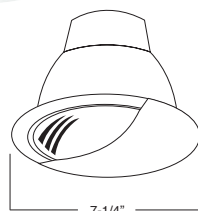

B624W-CL
CONE REFLECTOR BAFFLE WALL WASH




BAFFLE FINISH:
W, P

REFLECTOR FINISH:
CL, RG

COVER FINISH:
WH

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

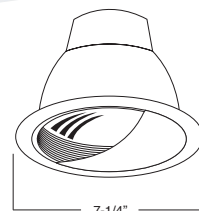

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAX. 75W R/ PAR40/ PAR38, 75W R/ PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

**B681CP-WH
SQUARE BAFFLE TRIM**



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP

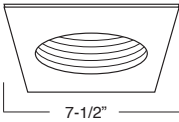


**B687CP-WH
SQUARE REFLECTOR TRIM**



REFLECTOR FINISH:
CL, RG, W, MB,
SN, CP


TRIM/RING FINISH:
WH, BK, SN, CP

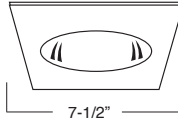

**B682WH
SQUARE EYEBALL TRIM**




TRIM/RING FINISH:
WH

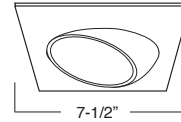

**B693WH
SQUARE PAR30 GIMBAL TRIM**




TRIM/RING FINISH:
WH

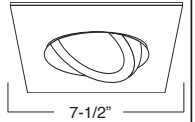

**B694WH
SQUARE PAR38 GIMBAL TRIM**



TRIM/RING FINISH:
WH

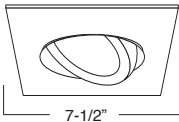


**B688WH
SQUARE ALBALITE SHOWER TRIM**



LENS:
WHITE

TRIM/RING FINISH:
WH

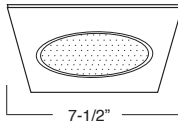


**B685WH
SQUARE FRESNEL SHOWER TRIM**



LENS:
CLEAR

TRIM/RING FINISH:
WH

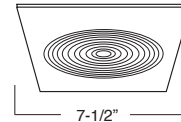


**B696WH
SQUARE DROP OIPAL SHOWER TRIM**



LENS:
WHITE

TRIM/RING FINISH:
WH

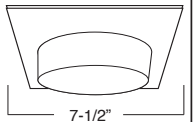


**B689WH
SQUARE DESIGNER CONE SHOWER LENS**



LENS:
FROSTED

TRIM/RING FINISH:
WH

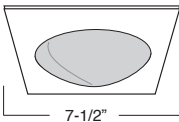


**B680WH
SQUARE DESIGNER POINT LENS**



LENS:
FROSTED/CLEAR

TRIM/RING FINISH:
WH

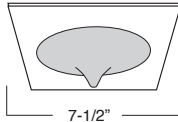

BAFFLE	REFLECTOR	TRIM RING
W White	CL Chrome	WH White
P Black	RG Gold	BK Black
SN Satin Nickel	W White	SN Satin Nickel
CP Copper	MB Black	CP Copper
BZ Bronze	CP Copper	CH Chrome
	SN Satin Nickel	PB Polish Brass
		BZ Bronze

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.


B6IC-100

6" Universal 100W IC Housing Double Wall

LAMP WATTAGE: (1) MAX. 75W R/PAR40/PAR38, 75W R/PAR30, 60W A19, 65W BR30



DESIGNED FOR 2" X 8" JOIST CONSTRUCTION

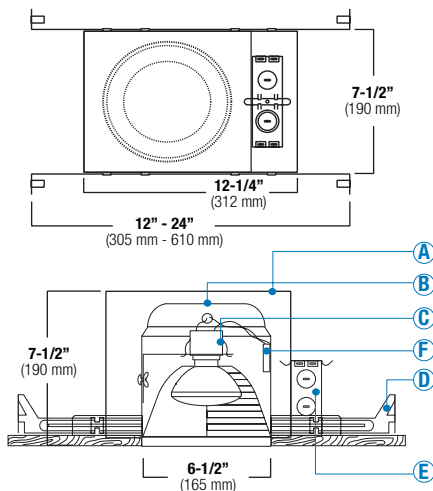

ITEM SELECTOR: (Please check the boxes below for the option desired)

TYPE	AIR-SHUT	OPTION	TRIM TYPE								BAFFLE	REFLECTOR	TRIM/RING	GLASS
B6IC-100	<input type="checkbox"/> AT	<input type="checkbox"/> (W) With quick connects	<input type="checkbox"/> B630	<input type="checkbox"/> B608	<input type="checkbox"/> B601	<input type="checkbox"/> B637	<input type="checkbox"/> B615	<input type="checkbox"/> B622	<input type="checkbox"/> B689 <input type="checkbox"/> B680	<input type="checkbox"/> W	<input type="checkbox"/> CL	<input type="checkbox"/> WH	<input type="checkbox"/> Green	
			<input type="checkbox"/> B640	<input type="checkbox"/> B602	<input type="checkbox"/> B601L	<input type="checkbox"/> B643	<input type="checkbox"/> B633	<input type="checkbox"/> B623		<input type="checkbox"/> P	<input type="checkbox"/> RG	<input type="checkbox"/> BK	<input type="checkbox"/> Yellow	
			<input type="checkbox"/> B620	<input type="checkbox"/> B609	<input type="checkbox"/> B605	<input type="checkbox"/> B658	<input type="checkbox"/> B634	<input type="checkbox"/> B625		<input type="checkbox"/> SN	<input type="checkbox"/> W	<input type="checkbox"/> SN	<input type="checkbox"/> Pink	
			<input type="checkbox"/> B631	<input type="checkbox"/> B619	<input type="checkbox"/> B605L	<input type="checkbox"/> B659	<input type="checkbox"/> B649	<input type="checkbox"/> B624		<input type="checkbox"/> CP	<input type="checkbox"/> MB	<input type="checkbox"/> CP	<input type="checkbox"/> Brown	
			<input type="checkbox"/> B632	<input type="checkbox"/> B646	<input type="checkbox"/> B606	<input type="checkbox"/> B675	<input type="checkbox"/> AF633	<input type="checkbox"/> B681		<input type="checkbox"/> BZ	<input type="checkbox"/> BZ	<input type="checkbox"/> CH	<input type="checkbox"/> Navy Blue	
			<input type="checkbox"/> AF637	<input type="checkbox"/> B616	<input type="checkbox"/> B606L	<input type="checkbox"/> B676	<input type="checkbox"/> B225	<input type="checkbox"/> B687		<input type="checkbox"/> CP	<input type="checkbox"/> CP	<input type="checkbox"/> PB	<input type="checkbox"/> Orange	
			<input type="checkbox"/> AF631	<input type="checkbox"/> B663	<input type="checkbox"/> B635	<input type="checkbox"/> B612	<input type="checkbox"/> B653	<input type="checkbox"/> B682		<input type="checkbox"/> SN	<input type="checkbox"/> BZ	<input type="checkbox"/> Blue		
			<input type="checkbox"/> AF639	<input type="checkbox"/> B664	<input type="checkbox"/> B636	<input type="checkbox"/> B645	<input type="checkbox"/> B651	<input type="checkbox"/> B693		<input type="checkbox"/> SHZ	<input type="checkbox"/> White			
			<input type="checkbox"/> AF640	<input type="checkbox"/> B673	<input type="checkbox"/> B641	<input type="checkbox"/> B648	<input type="checkbox"/> B611	<input type="checkbox"/> B694			<input type="checkbox"/> Red			
			<input type="checkbox"/> B610	<input type="checkbox"/> B674	<input type="checkbox"/> B642	<input type="checkbox"/> B652	<input type="checkbox"/> B647	<input type="checkbox"/> B688						
			<input type="checkbox"/> B607	<input type="checkbox"/> B683	<input type="checkbox"/> B656	<input type="checkbox"/> B603	<input type="checkbox"/> B644	<input type="checkbox"/> B685						
			<input type="checkbox"/> B627	<input type="checkbox"/> B684	<input type="checkbox"/> B657	<input type="checkbox"/> B604	<input type="checkbox"/> B650	<input type="checkbox"/> B696						

Specifications:

B6IC-100

AIR-SHUT - OPTION - TRIM TYPE - BAFFLE - REFLECTOR - TRIM/RING - GLASS

Sample of Catalog Number: B6IC-100-AT-W-B630-W-WH

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.



Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011

Catalog Number:

Project Name:

Type:

Note:



DESCRIPTION

For new construction. Thermally protected, IC rated specification grade recessed housing. Accommodates up to 100W R40, par38, 75W PAR30, R30 lamps, 60W A19 lamps and 65W BR30 lamps. Furnished with pre-installed adjustable bar hangers. Junction box is provided with four 1/2" KOs, one 3/4" KO and four Romex knockouts with strain relief.

SPECIFICATION

A. OUTER HOUSING - Die formed aluminum construction for maximum heat dissipating air chamber on top of the housing. Junction box could be accessed from inside and outside housing.


B. INNER HOUSING - Die-formed all aluminum construction for maximum heat dissipation and rust protection. Adjusts vertically in plaster frame to accommodate 1/2" to 1-3/8" ceiling.

C. SOCKET - Medium base screw shell porcelain socket preinstalled on adjustable mounting bracket is designed to allow usage of different lamp types, as well as proper and consistent lamp positioning.

D. BAR HANGERS - Preinstalled bar hangers allow housing to be positioned and locked at any point within a 24" joist span. They can be positioned on either the long or short axis of the housing and can be shortened for 12" joists. They contain a double-headed real nail for 20° downward angle for better contact, and the 90° pivoting mounting plate makes installation fast and accurate. Bar hangers can fit onto T-Bar spline with additional slots and holes for special mounting methods if necessary.

E. JUNCTION BOX - through-branch circuit wiring and has four 1/2" KOs, one 3/4" KO and four Romex knockouts with true pry-out slots and strain clamps.

F. THERMAL PROTECTION - Standard thermal protection device guards against improper installation, overlamping and misuse of insulation material.

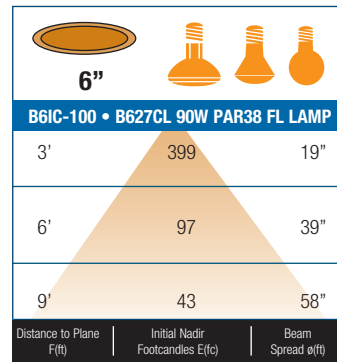

BEAM DIA. MEASURED AT 50% OF NADIR F.C.

FEATURES

- Thermally Protected IC housing.
- Adjustable socket bracket.
- Wire through junction box.
- Preinstalled adjustable bar hanger.
- Dependable, favorable design and effortless installation.
- 7-1/2" height allows use in 2" x 8" joist construction.
- Special screw on the frame locks bar hangers in place which prevents the housing from any movement once installed.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.

OPTIONS

AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.

6" Incandescent Trims

(LAMP WATTAGE: (1) MAX. 75W R/PAR40/PAR38, 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B630CP-CP
METAL STEPPED BAFFLE R30/PAR30



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

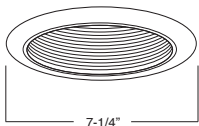


B640SN-SN
METAL STEPPED BAFFLE R40/PAR38




BAFFLE FINISH:
W, P, SN, CP, BZ


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

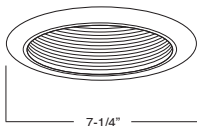


B620-ORANGE
GLASS TRIM

 

GLASS FINISH:
GREEN, YELLOW,
PINK, BROWN, NAVY
BLUE, ORANGE,
WHITE, RED

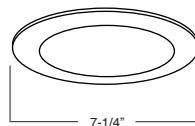


 B631P-WH
R30 PREMIUM PHENOLIC BAFFLE / METAL RING



BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

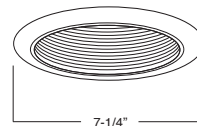


B632W-WH
R40 PREMIUM PHENOLIC BAFFLE / METAL RING



BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

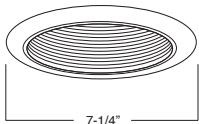

AF637W-WH
SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
SN-SN, CP-CP, BZ-BZ

AF631W-WH
SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
SN-SN, CP-CP, BZ-BZ

AF639W-WH
SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH


MATT WHITE FINISH

AF640W-WH
DEEP SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, SN-SN,
CP-CP, BZ-BZ

B610P-RG-WH
CONE REFLECTOR/BAFFLE TRIM

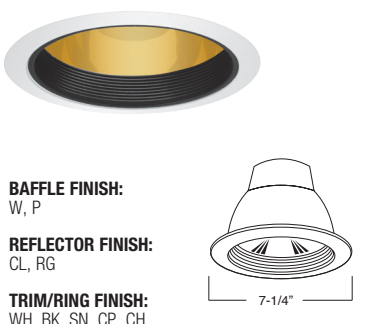


BAFFLE FINISH:
W, P

REFLECTOR FINISH:
CL, RG

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


B607CP-WH
REFLECTOR R/PAR30

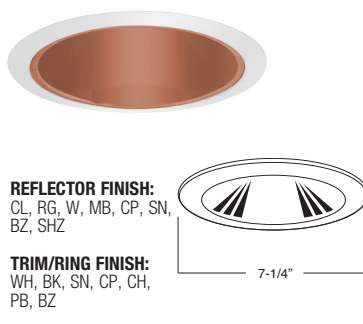

REFLECTOR FINISH:
CL, RG, W, MB, CP, SN,
BZ, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

B627RG-WH
REFLECTOR R40/PAR38

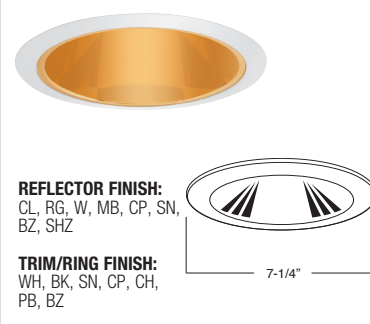

REFLECTOR FINISH:
CL, RG, W, MB, CP, SN,
BZ, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

B608CL-WH
CONE REFLECTOR A19



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN,
BZ, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

B602SN
EYEBALL



TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

B609W-WH
REGRESSED EYEBALL WITH BAFFLE




BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

B619RG-PB
REGRESSED EYEBALL WITH REFLECTOR

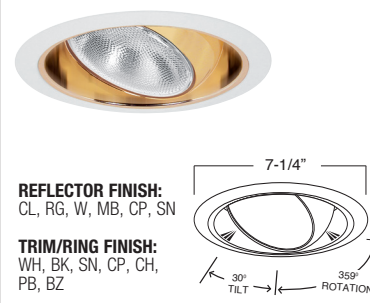

REFLECTOR FINISH:
CL, RG, W, MB, CP, SN

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAX. 75W R/PAR40/PAR38, 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B646P-WH
EYEBALL WITH BAFFLE



BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH

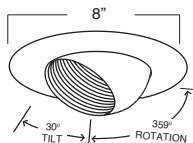


B616W-WH
PAR20 REGRESSED EYEBALL W/ BAFFLE




BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ


EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

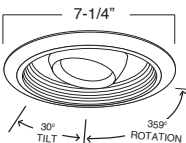


B663PB
PAR30 GIMBAL RING

 


TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

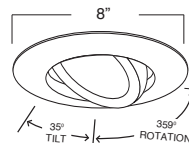


B664CP
PAR38 GIMBAL RING

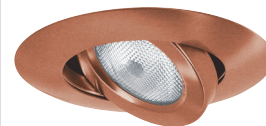

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

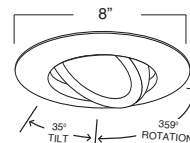


B673P-WH
PAR30 BAFFLE W/ GIMBAL RING

 

BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

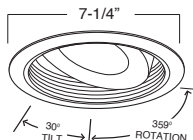


B674W-WH
PAR38 BAFFLE W/ GIMBAL RING




BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

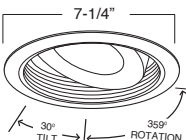


 B683CL-WH
PAR30 REFLECTOR W/ GIMBAL RING



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

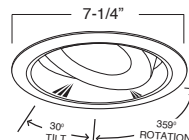


B684RG-WH
PAR38 REFLECTOR W/ GIMBAL RING



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

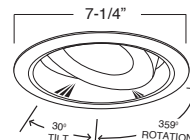


B601CP
METAL ALBALITE LENS



LENS:
ALBALITE

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

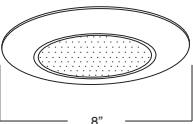


B601L
PLASTIC ALBALITE LENS



LENS:
ALBALITE

TRIM/RING FINISH:
WHITE PLASTIC

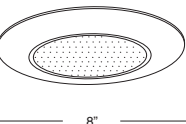


B605PB
METAL FRESNEL LENS



LENS:
FRESNEL

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

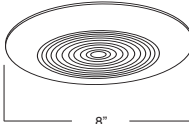


B605L
PLASTIC FRESNEL LENS



LENS:
FRESNEL

TRIM/RING FINISH:
WHITE PLASTIC

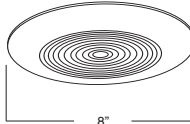


B606CP
METAL DROP OPAL LENS



LENS:
DROP OPAL

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

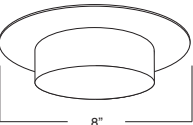


B606L
PLASTIC DROP OPAL LENS



LENS:
DROP OPAL

TRIM/RING FINISH:
WHITE PLASTIC

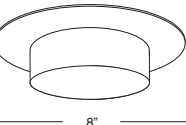


B635P-WH
BAFFLE W/ ALBALITE LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

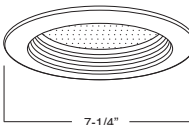


B636W-WH
BAFFLE W/ FRESNEL LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

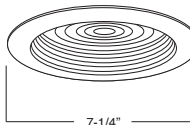

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAX. 75W R/ PAR40/ PAR38, 75W R/ PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B641RG-WH
REFLECTOR W/ ALBALITE LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

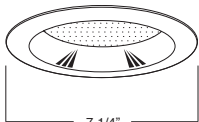

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B642CL-WH
REFLECTOR W/ FRESNEL LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

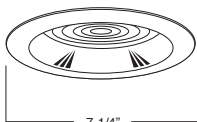

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B656W-WH
BAFFLE W/ FROSTED DOME SHOWER LENS



FOR
WET
LOCATION


BAFFLE FINISH:
W, P, SN, CP, BZ

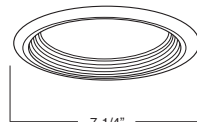

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

7-1/4"

 B657CL-WH
REFLECTOR W/ FROSTED DOME SHOWER LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ



TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B637W-WH
BAFFLE W/ DROP OPAL LENS



FOR
WET
LOCATION

BAFFLE FINISH:
W, P, SN, CP, BZ

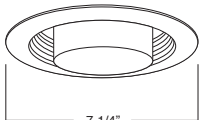

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B643RG-WH
REFLECTOR W/ DROP OPAL LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

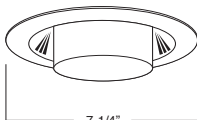

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B658CL-WH
REFLECTOR W/ PRISMATIC LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

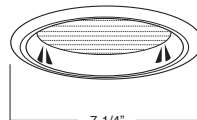

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B659CL-WH
REFLECTOR W/ FROSTED LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

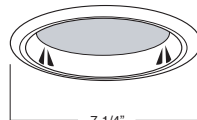

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B675W-WH
BAFFLE W/ PRISMATIC LENS



FOR
WET
LOCATION

BAFFLE FINISH:
W, P, SN, CP, BZ

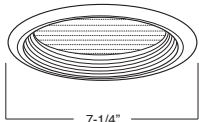

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B676W-WH
BAFFLE W/ FROSTED LENS



FOR
WET
LOCATION

BAFFLE FINISH:
W, P, SN, CP, BZ

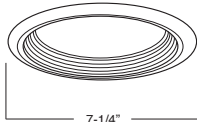

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


7-1/4"

B612WH
SMOOTH FROST DOME SHOWER LENS



FOR
WET
LOCATION

LENS:
FROSTED

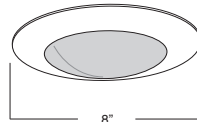

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


8"

B645WH
DESIGNER POINT SHOWER LENS



FOR
WET
LOCATION

LENS:
FROSTED/CLEAR

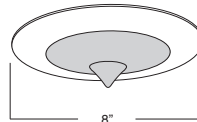

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


8"

B648WH
DESIGNER CONE SHOWER LENS



FOR
WET
LOCATION

LENS:
FROSTED

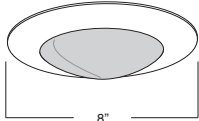

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ


8"

B652WH
SMOOTH FROST SHOWER LENS



FOR
WET
LOCATION


LENS:
FROSTED

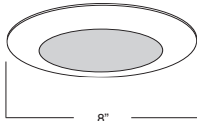


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

8"

 B603CP
R/ PAR30 OPEN TRIM




TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

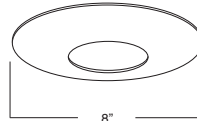


8"

 B604PB
R40/ PAR38 OPEN TRIM



TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

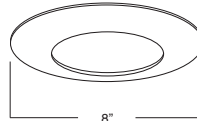

8"

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAX. 75W R/PAR40/PAR38, 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:


Note:

elite LIGHTING

B615WH
DESIGNER PINHOLE




TRIM/RING FINISH:
WH, BK

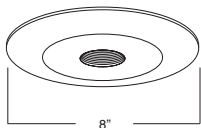

B633WH
R/PAR30 SPLAY TRIM




TRIM/RING FINISH:
WH, BK

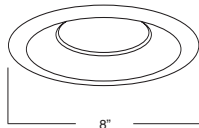

B634WH
R40/PAR38 SPLAY TRIM



TRIM/RING FINISH:
WH, BK

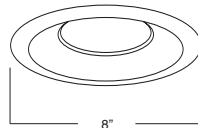


B649RG-WH
PAR20 REFLECTOR




REFLECTOR FINISH:
CL, RG, W, MB, CP, SN


TRIM/RING FINISH:
WH, BK

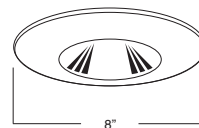

AF633CH
R/PAR30 OPEN TRIM

 

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

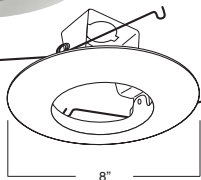


B225WH
OPEN TRIM STEPPED BAFFLE



BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH

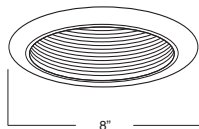


B653W-WH
BAFFLE WITH BAFFLE




BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB

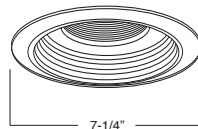


B651P-WH
PAR20 STEPPED BAFFLE

 

BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK

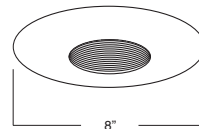


B611W-WH
PAR30 BAFFLE WALL WASH



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, SN-SN, CP-CP, BZ-BZ

COVER FINISH:
WH, BK

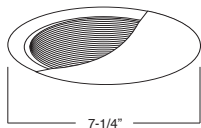


B647P-WH
DESIGNER BAFFLE WALL WASH PAR20



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH

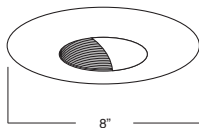


B644RG-WH
DESIGNER REFLECTOR WALL WASH PAR20



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN


TRIM/RING FINISH:
WH

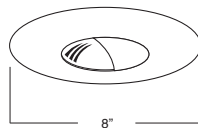

B650WH
DESIGNER WALL WASH



TRIM/RING FINISH:
WH

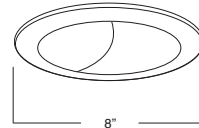


B622RG-WH
R/PAR30 WALL WASH REFLECTOR



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN, SHZ

COVER FINISH:
WH

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

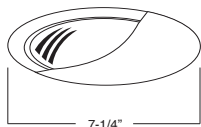


B623MB-WH
R40/PAR38 WALL WASH REFLECTOR



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN, SHZ

COVER FINISH:
WH

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

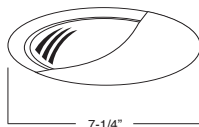


B625CL-WH
A-19 CONE REFLECTOR WALL WASH



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN, SHZ

COVER FINISH:
WH

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

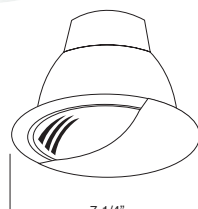

B624W-CL
CONE REFLECTOR BAFFLE WALL WASH




BAFFLE FINISH:
W, P

REFLECTOR FINISH:
CL, RG

COVER FINISH:
WH

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

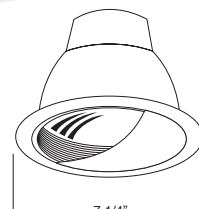

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAX. 75W R/ PAR40/ PAR38, 75W R/ PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

**B681CP-WH
SQUARE BAFFLE TRIM**



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP

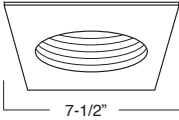


**B687CP-WH
SQUARE REFLECTOR TRIM**



REFLECTOR FINISH:
CL, RG, W, MB,
SN, CP


TRIM/RING FINISH:
WH, BK, SN, CP

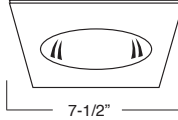

**B682WH
SQUARE EYEBALL TRIM**




TRIM/RING FINISH:
WH

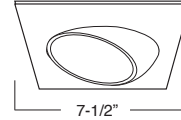

**B693WH
SQUARE PAR30 GIMBAL TRIM**




TRIM/RING FINISH:
WH

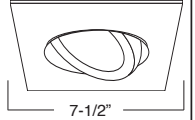

**B694WH
SQUARE PAR38 GIMBAL TRIM**



TRIM/RING FINISH:
WH

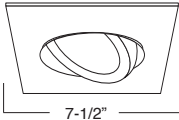


**B688WH
SQUARE ALBALITE SHOWER TRIM**



LENS:
WHITE

TRIM/RING FINISH:
WH

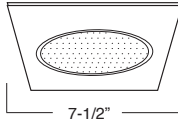


**B685WH
SQUARE FRESNEL SHOWER TRIM**



LENS:
CLEAR

TRIM/RING FINISH:
WH

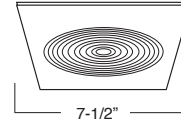


**B696WH
SQUARE DROP OIPAL SHOWER TRIM**



LENS:
WHITE

TRIM/RING FINISH:
WH

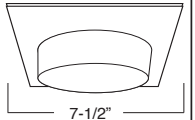


**B689WH
SQUARE DESIGNER CONE SHOWER LENS**



LENS:
FROSTED

TRIM/RING FINISH:
WH

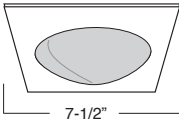


**B680WH
SQUARE DESIGNER POINT LENS**



LENS:
FROSTED/CLEAR

TRIM/RING FINISH:
WH

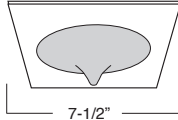

BAFFLE	REFLECTOR	TRIM RING
W White	CL Chrome	WH White
P Black	RG Gold	BK Black
SN Satin Nickel	W White	SN Satin Nickel
CP Copper	MB Black	CP Copper
BZ Bronze	CP Copper	CH Chrome
	SN Satin Nickel	PB Polish Brass
		BZ Bronze

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.