
 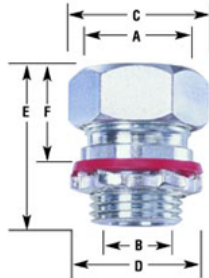


## US Steel

### Images



[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: .650-.750  
Dimension B in Inches: .845  
Dimension C in Inches: 1.440  
Dimension D in Inches: 1.220  
Dimension E in Inches: 1-9/16  
Dimension F in Inches: 1-1/32

### Application

These watertight fittings are designed for both indoor and outdoor applications. All fittings can be used in chemical and treatment plants as well as for offshore applications. Straight connector for use with portable cord provides liquid tight and water tight protection. Typical applications include wiring of motors, transformers, advanced machinery, refrigeration, and tools.

### Product Information

Material: Steel  
Finish: Zinc Electro-Plate

### Certifications & Codes:

NEMA Standard: FB-1  
UL File Number: E11259, cULus  
UL Standard: UL514B  
UNSPSC: 39121431

**Catalog ID:** CG771-750

**UPC Number:** 78174727716

**Description:** Connector, cord grip, straight, steel, k.o. size-3/4", cord range .650-.750

**Application:** These watertight fittings are designed for both indoor and outdoor applications. All fittings can be used in chemical and treatment plants as well as for offshore applications. Straight connector for use with portable cord provides liquid tight and water tight protection. Typical applications include wiring of motors, transformers, advanced machinery, refrigeration, and tools.

**Trade Size:** 3/4"

**Country of Manufacture:** USA

**Std Pkg Qty:** 100

**Unit Qty:** 10