
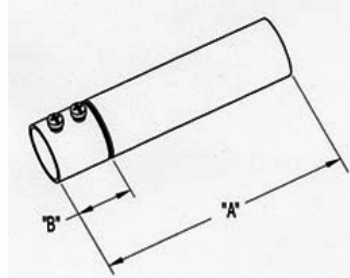


Steel

Images

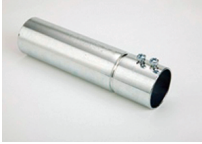

Application

Assembles like a regular EMT set screw coupling. To install, simply slide coupling end stop onto fixed end of EMT and tighten screw. Place movable EMT completely into coupling and mark engagement, remove EMT and mark half the distance of engagement, reinstall EMT to half distance.

Product Information

Material: Zinc Plated Steel

Certifications & Codes:

NEMA Standard:	FB-1
UL Standard:	UL514B
UNSPSC:	39121311
Patent Number:	6,715,803

Catalog ID: EC-150

UPC Number: 78174704304

Description: Mighty-Move® Expansion Coupling 1-1/2"
Steel expansion coupling for EMT & Rigid Conduit

Application: Assembles like a regular EMT set screw coupling. To install, simply slide coupling end stop onto fixed end of EMT and tighten screw. Place movable EMT completely into coupling and mark engagement, remove EMT and mark half the distance of engagement, reinstall EMT to half distance.

Trade Size: 1-1/2"

Country of Manufacture: Made in the USA with foreign components

Std Pkg Qty: 30

Unit Qty: 6

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 7 - 1/2

Dimension B in Inches: 1 - 9/16