


## Steel

### Images

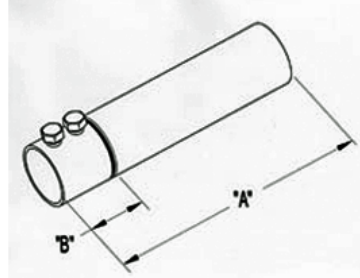

### Application

Assembles like a regular EMT/RIGID/IMC set screw coupling. To install, simply slide coupling end stop onto fixed end of EMT/RIGID/IMC and tighten screw. Place movable EMT/RIGID/IMC completely into coupling and mark engagement, remove EMT/RIGID/IMC and mark half the distance of engagement, reinstall EMT/RIGID/IMC to half distance.

### Product Information

Material: Zinc Plated Steel

### Certifications & Codes:

NEMA Standard:	FB-1
UL Standard:	UL514B
UNSPSC:	39121311
Patent Number:	6,715,803

**Catalog ID:** EC-250

**UPC Number:** 78174704306

**Description:** Mighty-Move® Expansion Coupling 2-1/2"  
Steel expansion coupling for EMT & Rigid Conduit

**Application:** Assembles like a regular EMT/RIGID/IMC set screw coupling. To install, simply slide coupling end stop onto fixed end of EMT/RIGID/IMC and tighten screw. Place movable EMT/RIGID/IMC completely into coupling and mark engagement, remove EMT/RIGID/IMC and mark half the distance of engagement, reinstall EMT/RIGID/IMC to half distance.

**Trade Size:** 2-1/2"

**Country of Manufacture:** Made in the USA with foreign components

**Std Pkg Qty:** 1

**Unit Qty:** Bulk

[Download Photo Image](#)   [Download Dimensional Image](#)  
Dimension A in Inches: 10  
Dimension B in Inches: 2 - 5/8