

NEW!
See reverse

Press-hold, Joist-mount Fan/Fixture Box

Ships ready to install for a fast, secure installation!



FB415 presses onto joist

Arlington's FB415 fan/fixture box saves time and money. And, it's the fastest way to a super-secure installation.


The box presses onto the joist where gripping tangs hold it firmly in place while you reach for your screwdriver. Tightening the shipped-in-place center screw (photo at left) attaches the box securely to the joist.

There are no pieces to lose! The installation screws for the box and bracket (shown at left) ship captive, along with an installed NM cable connector and mud cover.

- 10.3 cubic inch volume
- Two KOs
- 2-hour fire rating
- For 1/2 or 5/8 inch drywall
- UL rating:
70 lb fans, fixtures up to 200 lbs.
- CSA rating:
Fans, fixtures up to 50 lbs.

Catalog Number	UPC/DEI/NAED Mfg. #018997	Description	Std Pkg
FB415	72167	Non-metallic fan/fixture box	25
FB426	72179	10.3 cu. inch	25
		16.0 cu. inch	
		for 1/2 or 5/8 inch drywall	
FB423	72190	19.5 cu. inch	25
		for 1/2 or 5/8 inch drywall w/ furring strips or hat channel; or double drywall	

Patented
Other patents pending.

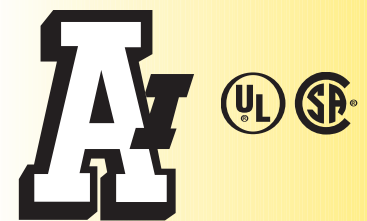


Arlington

1 Stauffer Industrial Park
Scranton, PA 18517
800/233.4717
Fax 570/562.0646
www.aifittings.com

Fan/Fixture Box

Press-hold • Fast and easy to install!

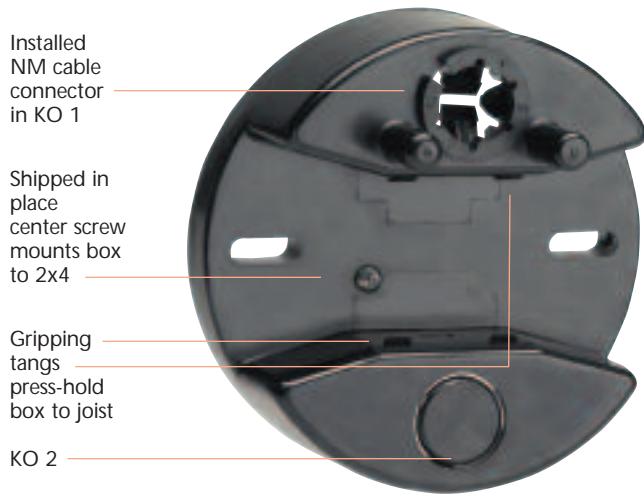

1 Press box onto joist.




Gripping tangs hold it in place, freeing hands to locate screwdriver.




2 Tighten center screw to secure box to joist.



3 Pull NM cable through connector.

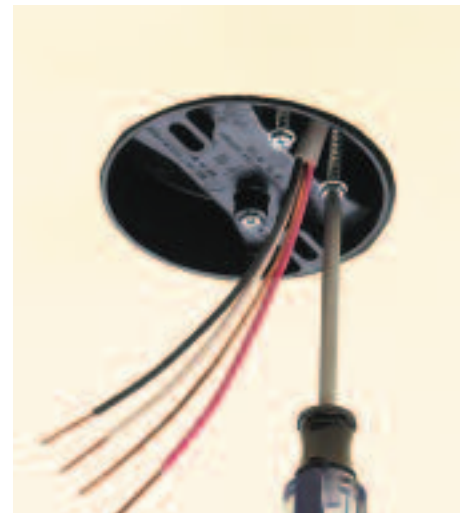

4 Remove two long, parked screws. Use to install bracket...

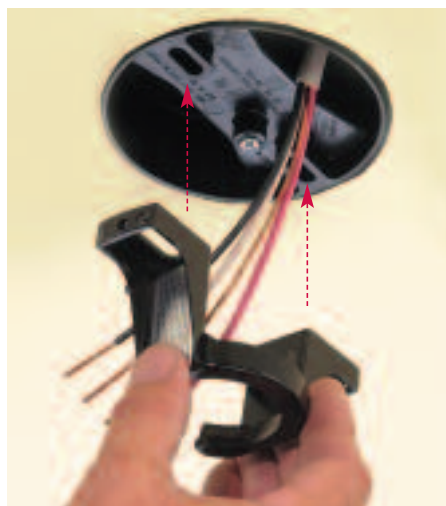

5 ...through the oval slots indicated in photo.



Distributed by

**2-hour
Fire Rating**



Arlington

1 Stauffer Industrial Park
Scranton, PA 18517
800/233.4717
Fax 570/562.0646
www.aifittings.com