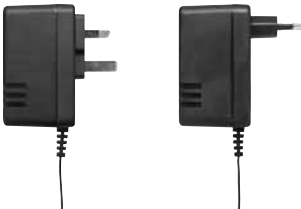
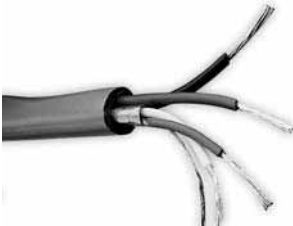
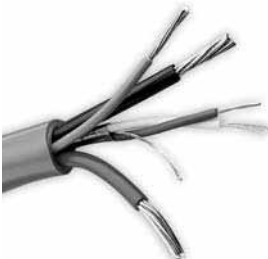


Accessories	Product	Model	
    	Lockable Covers	Single-gang Two-gang Three-gang Four-gang	GRX-1GLC GRX-2GLC GRX-3GLC GRX-4GLC
	• Prevents tampering with GRAFIK Eye control units or wallstations • Permits infrared operation • Translucent smoked grey • Cover slides left or right		
	Replacement Covers	Two-gang (AU models only) Three-gang (AU models only) Four-gang (Both AU and CE models)	GRX-2GRC- GRX-3GRC- GRX-4GRC-
	• See section 1.3 or section 1.4 for cover options and base colours. • For 230 V applications, all GRAFIK Eye 3000 Series control units are four-gang		
	External Power Supplies	UK plug style European plug style	TU240-15DC-9-BL TE240-15DC-9-BL
	GRAFIK Eye 3000 Low Voltage Cable^{1,2} 150 m (500') spool	GRX-CBL-346S-500 (non-plenum) GRX-PCBL-346S-500 (plenum)	
	• Four PELV (Class 2) conductors: (2) 1.0 mm² (#18 AWG) for power wires; plus (1) twisted, shielded 1.00 mm² (#22 AWG) pair for control wires		
	GRAFIK Eye 4000, Centralised Lighting Control System^{1,3} 75 m (250') spool	GRX-CBL-46L-250 (non-plenum) GRX-PCBL-46L-250 (plenum) GRX-CBL-46L-500 (non-plenum) GRX-PCBL-46L-500 (plenum)	
	150 m (500') spool		
	• Five PELV (Class 2) conductors: (2) 2.5 mm² (#12 AWG) for power wires; (1) twisted, shielded 1.00 mm² (#22 AWG) pair for control wires; plus (1) 1.00 mm² (#18 AWG) wire for the emergency sense line		
	Footnotes, pg. 2.13.1		
	¹ For information on cable size and distance, see "Application Note W14" on http://www.lutron.com/onespec/cutsheets/appnotes/grx/grxwire.pdf .		
	² See the application note on pg. 2.16.3 for more information.		
	³ See the application note on pg. 2.16.4 for more information.		