



Catalog Number: HC884JIC12
Item Description: N12 JIC HINGE CVR ENCL
UPC Code: 784572112728

Brand Name: Milbank

Type: Hinge Cover

Special Features: Continuous Hinge with Removable Pin, 1 Door, Clamps and Screws on One Side, Collar Studs for Panels, External Mounting Feet

Application: Enclosure for Mounting Electrical Equipment

Standard: UL Listed

Number Of Outlet: 0

Material: Steel with Powder Coat Finish



Color: ANSI 61 Gray

Mounting: Wall Mount


NEMA Rating: Type 12



Utility requirements may vary. Always consult the serving utility for their requirements prior to ordering or installing this equipment. This product must always be installed by a licensed electrician. Installation of this equipment may require local electrical inspector approval.

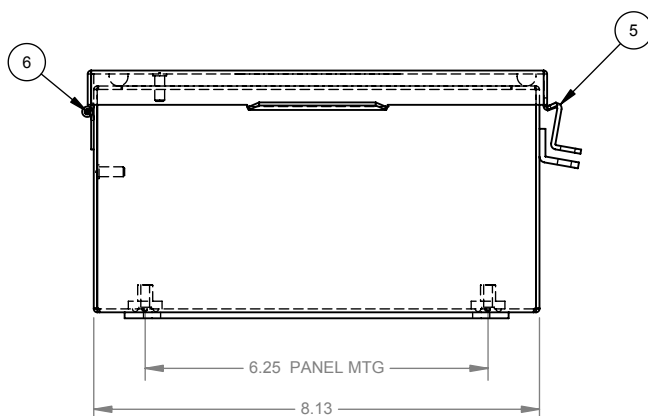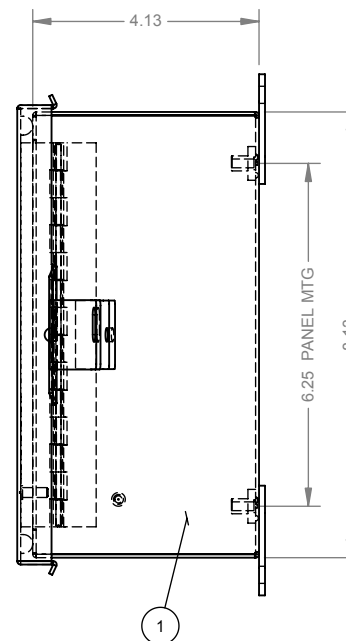

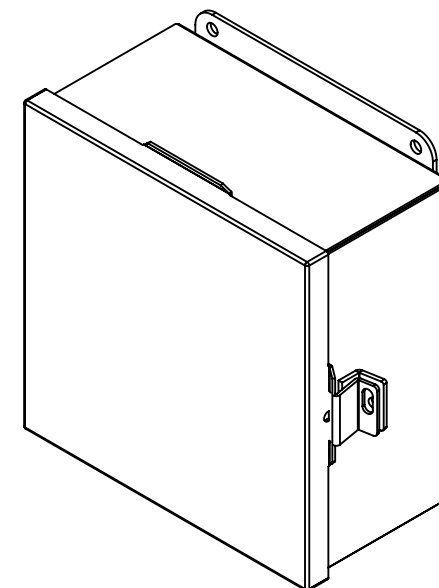

ITEM	QTY.	PART NUMBER	DESCRIPTION
1	1	504384	BACK WELDMENT
	1	202546	BACK
	4	1011649	WELD NUT (10-32)
	2	813729	MOUNTING EAR
	1	1011703	HINGE LEAF
	1	1092944	CLAMP BRACKET
	1	1002137	WELD STUD
2	1	917675	FRONT ASSY W/ FIP GASKET
	1	1000764	FRONT WELDMENT
	1	1011072	FRONT
	1	1011703	HINGE LEAF
	1	1002137	WELD STUD
	1	818221	GASKET, FOAM IN PLACE
3	1	1002646	BAG ASSY, (SCREWS)
4	1	1003115	LABEL (UL)
5	1	1000870	COVER CLAMP
6	1	1003394	HINGE PIN



CATALOG NUMBER	MATERIAL	FINISH
HC884JIC12	CRS	ANSI 61 GRAY
HC884JIC4XS	304 STAINLESS	GRAINED
HC884JIC4XZ	316 STAINLESS	GRAINED

2. USE CARTON 705069 (4 PER) FOR SHIPPING.
3. WHEN SOLD AS (RC)- PREFIX USE LABEL #1125021 INSTEAD OF #1003115.

E	5-20-02	ADDED GND STUD / NUT, CHGD FRONT - PMR 2819	DR					Scale:	NTS	Checked By:		Drawing No.:	638-11		
E1	8-22-06	mECO #15092, ADDED NOTE #3.	CMW					Drawn By:	DR	Approved By:		Date:	5-20-02	Sheet	1 of 1

Material:	SEE CHART			General Offices Kansas City, MO	
Finish:	SEE CHART			Title:	HINGE COVER JIC 8 x 8 x 4, TYPE 4, 12 ENCLOSURE
Tolerances: Unless Specified Otherwise X.X ±.1 X.XX ±.03 X.XXX ±.015 X* ±2°				Catalog No.:	SEE CHART
		Projection		Customer:	
Scale:	NTS	Checked By:		Drawing No.:	638-11
Drawn By:	DR	Approved By:		Date:	5-20-02
				Sheet	1 of 1



Catalog Number: HC884JIC12
Item Description: N12 JIC HINGE CVR ENCL
UPC Code: 784572112728

Brand Name: Milbank

Type: Hinge Cover

Special Features: Continuous Hinge with Removable Pin, 1 Door, Clamps and Screws on One Side, Collar Studs for Panels, External Mounting Feet

Application: Enclosure for Mounting Electrical Equipment

Standard: UL Listed

Number Of Outlet: 0

Material: Steel with Powder Coat Finish


Color: ANSI 61 Gray

Mounting: Wall Mount

NEMA Rating: Type 12



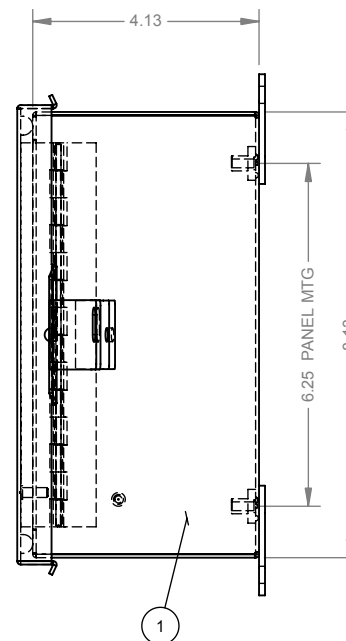

Utility requirements may vary. Always consult the serving utility for their requirements prior to ordering or installing this equipment. This product must always be installed by a licensed electrician. Installation of this equipment may require local electrical inspector approval.



2. USE CARTON 705069 (4 PER) FOR SHIPPING.
3. WHEN SOLD AS (RC)- PREFIX USE LABEL #1125021 INSTEAD OF #1003115.

CATALOG NUMBER	MATERIAL	FINISH
HC884JIC12	CRS	ANSI 61 GRAY
HC884JIC4XS	304 STAINLESS	GRAINED
HC884JIC4XZ	316 STAINLESS	GRAINED

Material:	SEE CHART			General Offices: Kansas City, MO	
Finish:	SEE CHART			Title:	HINGE COVER JIC 8 x 8 x 4, TYPE 4, 12 ENCLOSURE
Tolerances: Unless Specified Otherwise X.X ±.1 X.XX ±.03 X.XXX ±.015 X* ±.2		 Third Angle Projection	Catalog No.:	SEE CHART	
			Customer:		
Scale:	NTS	Checked By:	Drawing No.:	638-11	
Drawn By:	DR	Approved By:	Date:	5-20-02	Sheet 1 of 1