



PHYSICAL SPECIFICATIONS

BALLAST SPECIFICATIONS

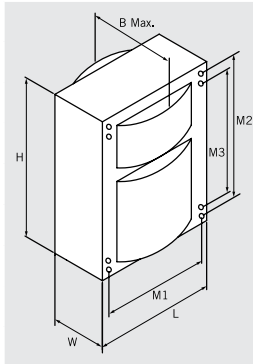


LENGTH	4.25"
WIDTH	4.10"
HEIGHT	6.00"
MOUNTING 1	3.875"
MOUNTING 2	5.375"
MOUNTING 3	4.375"
B MAX.	6.00"
NET WEIGHT	28 lbs
LEAD LENGTH	12-14"

CAPACITOR SPECIFICATIONS

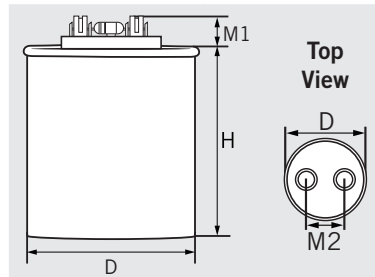

DIAMETER	2.00"
HEIGHT	4.75"
MOUNTING 1	0.58" Max.
MOUNTING 2	0.81"
TYPE	Oil Film

IGNITOR SPECIFICATIONS

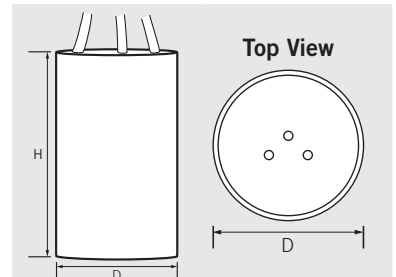

DIAMETER	1.40"
HEIGHT	2.60"
TYPE	CWA

ORDERING INFORMATION

ORDER CODE	PACKAGING STYLE	PACK QTY.	ITEM STATUS
HPS-1000A-Q-KIT 3/1	Individually Packaged	1	Quick Ship

Each kit includes the ballast pre-wired to a properly rated capacitor and ignitor (if required), mounting hardware, and pictorial installation guide.

NOTE: Version P1 (Manufacturing Revision). Prior versions of this ballast exist. Spec sheets for prior versions available upon request. Contact Keystone for details.

CATALOG NUMBER BREAKDOWN

HPS-1000A-Q-KIT

High Pressure Sodium

Input Power

CWA Circuit

Quad Tap

Ballast Kit