


Aluminum

Images

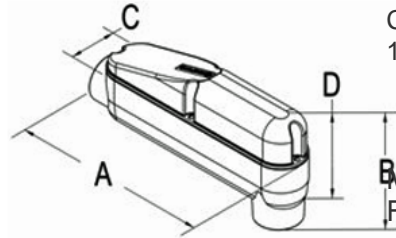

Application

Mogul style conduit body for use with threaded Rigid/IMC Conduit. Suitable for use in wet locations. Max wire fill 3-1000 MCM THHN, THWN, XHHW. Meets NEC 6X Rule.

Product Information

Material: Aluminum
Finish: Enamel paint

Certifications & Codes:

NEMA Standard: FB-1
UL File Number: E11077, cULus
UL Standard: UL-514A
UNSPSC: 39131708

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 29.12
Dimension B in Inches: 11.94
Dimension C in Inches: 5.63
Dimension D in Inches: 9.94

Catalog ID: MLB-50

UPC Number: 781747441508

Description: Conduit Body, Mogul, Aluminum, Size 4 Inch

Application: Mogul style conduit body for use with threaded Rigid/IMC Conduit. Suitable for use in wet locations. Max wire fill 3-1000 MCM THHN, THWN, XHHW. Meets NEC 6X Rule.

Trade Size: 4"

Std Pkg Qty: 1