


2

1

- NOTES:
- 1. MOISTURE RATING: SUITABLE FOR MOISTURE RICH ENVIRONMENTS
 - 2. EFFICIENCY: 91 db
 - 3. IMPEDANCE: 8 ohm
 - 4. FREQUENCY RESPONSE: 60-20KHz
 - 5. WOOFER TYPE: BLUE MICA FIBER
 - 6. TWEETER TYPE: SILVER MYLAR
 - 7. POWER RMS/PEAK: 50W/100W
 - 8. PAINTABLE SPEAKER GRILL INCLUDED

B

B

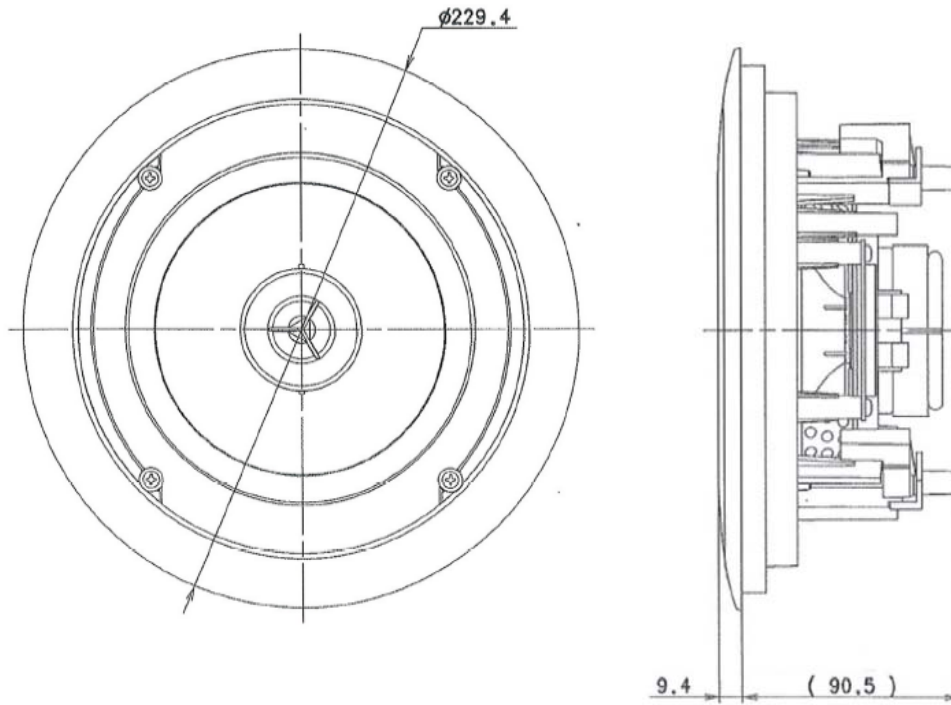

A

A

PROPRIETARY AND CONFIDENTIAL
THE INFORMATION CONTAINED
IN THIS DRAWING IS THE SOLE
PROPERTY OF On-Q/LEGRAND.
ANY REPRODUCTION IN PART OR
AS A WHOLE WITHOUT THE WRITTEN
PERMISSION OF On-Q/LEGRAND
IS PROHIBITED. DRAWING IS SUBJECT
TO CHANGE WITHOUT NOTICE.

on·Q

legrand

P.O. Box 60907
Middletown, PA 17106-0907
1-800-321-2343

TITLE:
**evoQ 3000 6.5" IN-CEILING SPEAKER
(PAIR)**

SIZE	DWG NO	FILE NAME	CUST REV
A	MS3650	CD-MS3650	1
REVISED DATE 7/18/08		SCALE NONE	SHEET 1 OF 1

2

1


2

1

- NOTES:
- 1. MOISTURE RATING: SUITABLE FOR MOISTURE RICH ENVIRONMENTS
 - 2. EFFICIENCY: 91 db
 - 3. IMPEDANCE: 8 ohm
 - 4. FREQUENCY RESPONSE: 60-20KHz
 - 5. WOOFER TYPE: BLUE MICA FIBER
 - 6. TWEETER TYPE: SILVER MYLAR
 - 7. POWER RMS/PEAK: 50W/100W
 - 8. PAINTABLE SPEAKER GRILL INCLUDED

B

B

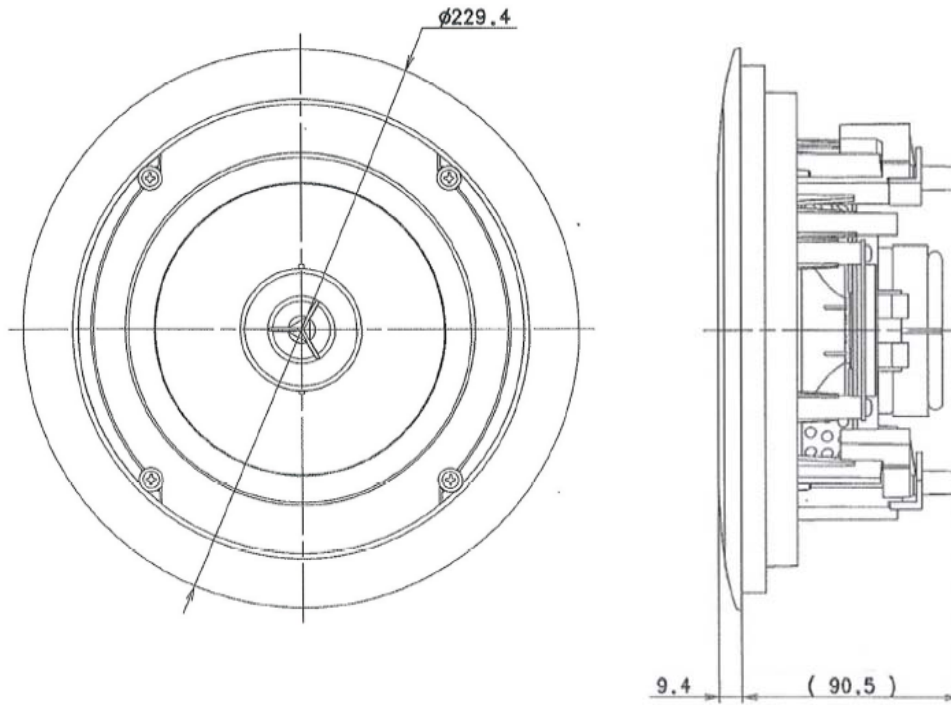

A

A

PROPRIETARY AND CONFIDENTIAL
THE INFORMATION CONTAINED
IN THIS DRAWING IS THE SOLE
PROPERTY OF On-Q/LEGRAND.
ANY REPRODUCTION IN PART OR
AS A WHOLE WITHOUT THE WRITTEN
PERMISSION OF On-Q/LEGRAND
IS PROHIBITED. DRAWING IS SUBJECT
TO CHANGE WITHOUT NOTICE.

on·Q

legrand

P.O. Box 60907
Middletown, PA 17106-0907
1-800-321-2343

TITLE:
**evoQ 3000 6.5" IN-CEILING SPEAKER
(PAIR)**

SIZE	DWG NO	FILE NAME	CUST REV
A	MS3650	CD-MS3650	1
REVISED DATE 7/18/08		SCALE NONE	SHEET 1 OF 1

2

1