




METALLIC LOW PROFILE WIU COVERS

**Single Gang Metal Low Profile WhileInUse Covers Extra Duty[®]
Vertical 8-in-1 Deep**

C11

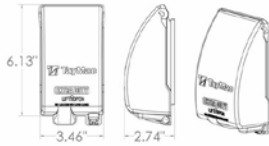

Catalog #: MX5280S

APPLICATIONS

Designed for use whenever weatherproof protection is required while an outlet is in use.

PRODUCT FEATURES

Revolutionary patented design expands from 2-1/2 in. to 4-1/2 in. for in-use needs
Heavy duty die-cast metal construction
Patented QuickFit™ keyhole mounting system allows installation in under a minute.
Pre-configured for GFCI with patented Knockout technology for alternate devices
Includes attached gasket and mounting hardware
Lockable tab
Premium Powder Coat

UL LISTED

File E212332

NEMA

3R Rated

NEC

2014 Compliant (article 406.9A & B) Extra Duty Rated

US PATENTS

8,314,334; 8,259,253 B1; 6,420,654; 8,106,295 B1

GENERAL PRODUCT INFORMATION

Color: Gray

CONFIGURATION

Gangs: 1

PRODUCT MEASUREMENTS

Depth: 2-1/2 in. to 4-1/2 in.
Wt. Ea. (Lbs.): 0.900

PACKAGING


Package Type: Shrink
Std. Pkg.: 2
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 90.00
Ship Carton Length (in.): 6.13
Ship Carton Width (in.): 4.13
Ship Carton Height (in.): 7.13
Ctn Weight (Lbs.): 1.80
Pallet Qty: 620
UPC Number: 092326101356
I2of5: 30092326101357



METALLIC LOW PROFILE WIU COVERS

**Single Gang Metal Low Profile WhileInUse Covers Extra Duty[®]
Vertical 8-in-1 Deep**

C11

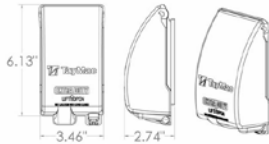

Catalog #: MX5280S

APPLICATIONS

Designed for use whenever weatherproof protection is required while an outlet is in use.

PRODUCT FEATURES

- Revolutionary patented design expands from 2-1/2 In. to 4-1/2 In. for in-use needs
- Heavy duty die-cast metal construction
- Patented QuickFit™ keyhole mounting system allows installation in under a minute.
- Pre-configured for GFCI with patented Knockout technology for alternate devices
- Includes attached gasket and mounting hardware
- Lockable tab
- Premium Powder Coat

UL LISTED

File E212332

NEMA

3R Rated

NEC

2014 Compliant (article 406.9A & B) Extra Duty Rated

US PATENTS

8,314,334; 8,259,253 B1; 6,420,654; 8,106,295 B1

GENERAL PRODUCT INFORMATION

Color: Gray

CONFIGURATION

Gangs: 1

PRODUCT MEASUREMENTS

Depth: 2-1/2 in. to 4-1/2 in.
Wt. Ea. (Lbs.): 0.900

PACKAGING

Package Type: Shrink
Std. Pkg.: 2
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 90.00
Ship Carton Length (in.): 6.13
Ship Carton Width (in.): 4.13
Ship Carton Height (in.): 7.13
Ctn Weight (Lbs.): 1.80
Pallet Qty: 620
UPC Number: 092326101356
I2of5: 30092326101357