


Type _____
-30
P3536 ☐
P3537 ☐
P3538 ☐

Catalog No.	Finish	Lamping	Dimensions (Inches)	
	White		A	B
P3536	-30	2 (m) 60w	11-3/4	6
P3537	-30	2 (m) 60w	13-1/4	6
P3538	-30	3 (m) 60w	15-1/4	6-1/4

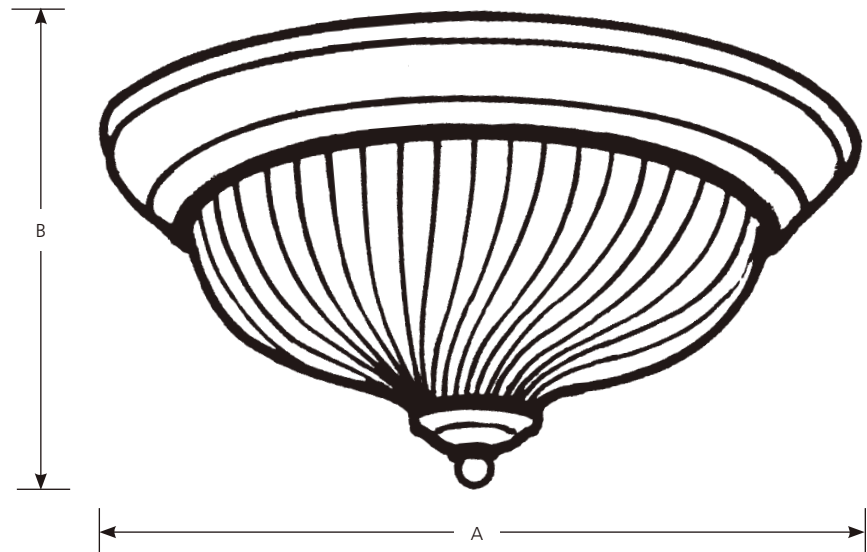

Specifications:

General

- Satin etched swirled glass
- White (-30) finish
- Steel construction
- Fiberglass insulated

Mounting

- Ceiling mount
- Covers outlet box
- Mounting strap for outlet box included
- Keyhole slots for easy mounting

Electrical


- Requires 90-degree supply wire connection
- Medium based ceramic sockets
- Pre-wired

Labeling

- UL-CUL listed

Type _____
-30
P3536 ☐
P3537 ☐
P3538 ☐

Catalog No.	Finish	Lamping	Dimensions (Inches)	
	White		A	B
P3536	-30	2 (m) 60w	11-3/4	6
P3537	-30	2 (m) 60w	13-1/4	6
P3538	-30	3 (m) 60w	15-1/4	6-1/4

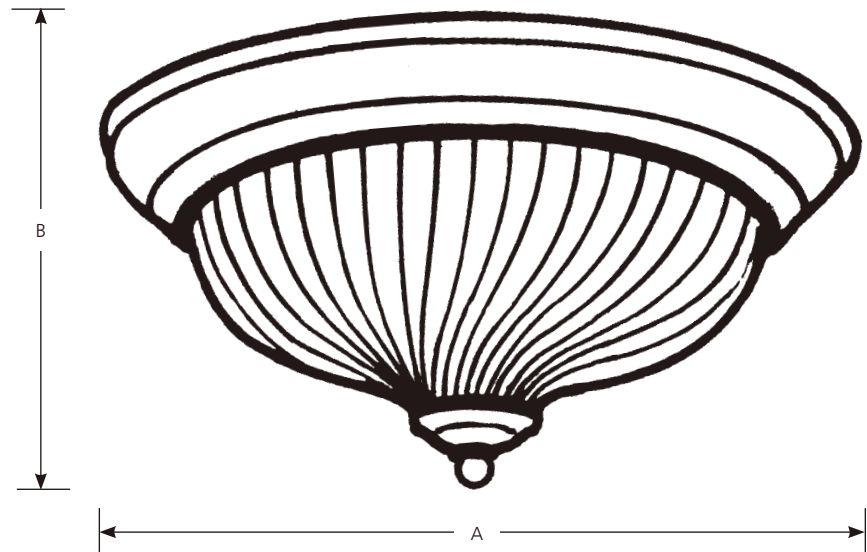

Specifications:

General

- Satin etched swirled glass
- White (-30) finish
- Steel construction
- Fiberglass insulated

Mounting

- Ceiling mount
- Covers outlet box
- Mounting strap for outlet box included
- Keyhole slots for easy mounting

Electrical

- Requires 90-degree supply wire connection
- Medium based ceramic sockets
- Pre-wired

Labeling

- UL-CUL listed