

# Kindorf®

**Right Angle Slotted Angles**  
**T&B Catalog Number:**

**UPC Number:**  
**Status:**  
**Description:**

RA 225 10  
 78599180005  
 Active

10 ft. right angle slotted metal framing. Designed for heavy duty applications.

**Features**

Packaged in five 10 foot or 12 foot lengths complete with 36 long hex head bolts and nuts-3/8 in. x 5/8 in.

**Application**

Wide range versatility for nearly every type of framing  
 Well suited for electrical applications  
 Slot-and-hole pattern provides ready-made anchoring points for panel-board framing and fixtures of all kinds.

**General**

Material Steel

**Dimension Information**

Length (feet) 10

**Specifications**


3dmodel Available on Website

**Packaging**

T&B Order Multiple	50
T&B Inner Pack	50
Package in Units	1000
T&B Sold in UOM	Feet
T&B Weight Per UOM	85 lbs. per 100

**Certifications**

RoHS Compliance Yes

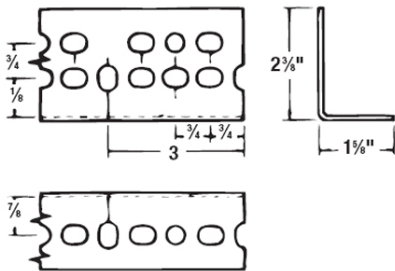

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
 8155 T&B Blvd.  
 Memphis, TN 38125  
 www.tnb.com

T&B Technical Support  
 MS 3B-50  
 8155 T&B Blvd.  
 Memphis, TN 38125

Hours: 7AM - 6PM CDT  
 Monday-Friday  
 Phone: (888) 862-3289  
 Fax: (901) 252-1321  
 Email:techsupport@tnb.com