


RIGID BODIES AND ASSEMBLIES

LB Assembly
N/A

C13

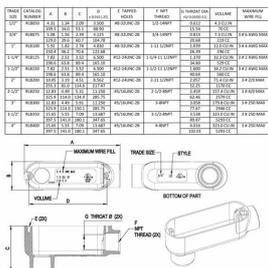

Catalog #: RLB075

APPLICATIONS

For use with threaded rigid/IMC conduit for pulling access or to split a run into multiple directions. Removable cover allows access for maintenance and making taps and splices to conductors.
N/A

PRODUCT FEATURES

- Durable die cast aluminum construction
- Premium powder coat finish
- Includes NBR synthetic rubber gasket
- Stamped aluminum cover
- Combination head screw

UL LISTED

File E331564

NEMA

NEMA 3R rated

NEC

2014 NEC® compliant

GENERAL PRODUCT INFORMATION

Trade Size: 3/4 in.

DRAWING DIMENSIONS

- Dimension A: 5.08 in.
- Dimension B: 1.56 in.
- Dimension C: 2.39 in.
- Dimension D: 4.125 in.
- Dimension E: Tapped holes #8-32UNC-2B
- Thread Spec. F: 3/4-14NPT
- Dimension G: .814 in.

PRODUCT MEASUREMENTS

Cubic Inches (cm3): 7.3 (119.6)

PACKAGING

- Package Type: Carton
- Ship Carton Qty.: 10
- Product UPC-A Labeled: Yes
- Weight (Lbs. Per/C): 37.00
- Ship Carton Length (in.): 1.88
- Ship Carton Width (in.): 3.75
- Ship Carton Height (in.): 6.88
- Ctn Weight (Lbs.): 3.70
- UPC Number: 092326211925
- I2of5: 30092326211926