


Eaton XC E4 B4

Catalog Number: XC E4 B4

Eaton Crouse-Hinds series XC electric heater, 25,950 BTU/hr, 7.6 kW, Steel, 20A max., With built-in room thermostat, 480 Vac

General specifications

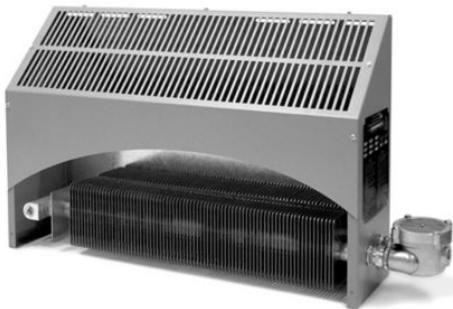

Product Name	Catalog Number
Eaton Crouse-Hinds series XC electric heater	XC E4 B4
	UPC
	662276105775
Product Length/Depth	Product Height
65.13 in	20.3 in
Product Width	Product Weight
8.11 in	104.3 lb

Certifications and compliances

Area classification

Hazardous/Classified Locations

Standards type

NEC/CEC

IEC

NEC hazardous rating

Class I, Division 1

Class I, Zone 1

Class I, Division 2

Class I, Zone 2

NEMA Rating

7

Product specifications

Type

With built-in room thermostat

Power output

7.6 kW

Heat output

25,950 BTU/hr

Voltage rating

480 Vac

Maximum total amperage

20 A

Material

Steel

Resources

Catalogs

[XC Series Explosionproof Electric Heaters catalog page](#)

Certification reports

[XC Explosionproof Electric Heaters UL certification](#)

Installation instructions

[IF 1729 - XC Series Explosionproof Electric Heaters](#)

Specifications and datasheets

[Eaton Specification Sheet - XC E4 B4](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)