



Weatherproof Boxes & Covers Thermoplastic Covers

Features


- Broad line of single gang covers for switches, receptacles, GFCIs and power outlets.
- Clear polycarbonate lid with reinforced thermoplastic base.
- Covers comply with 2005 NEC Section 406.8(A) and 406.8(B)(2).

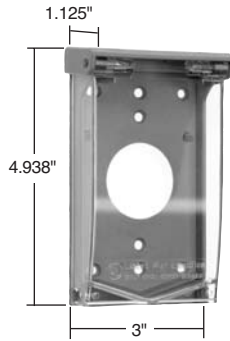


3720-FS

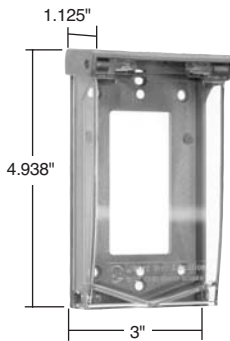


3723-FS

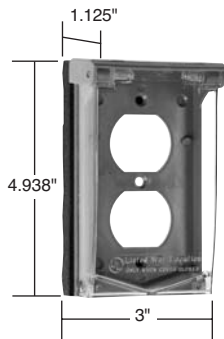

3710

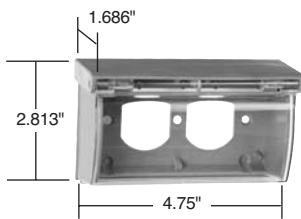

3700

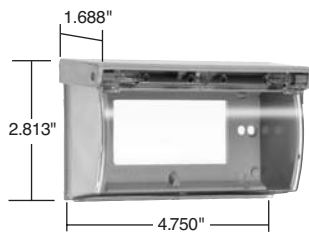

3703

Catalog Number	Description	Gasket Thickness	3rd Party Compliance	
			UL	SR
Self-Closing Covers – Clear Polycarbonate Lid Vertical Two Screw Mounting – Padlockable				
3710	Duplex RV use Gray Base	3/8"	•	•
3720	Single Receptacle 1.40" Diameter Gray Base	3/8"	•	•
3723	Decorator RV use Gray Base	3/8"	•	•
Self-Closing Covers – Clear Polycarbonate Lid Vertical Four Screw Mounting – Padlockable				
3710-FS	Duplex Receptacle Gray Base	3/32"	•	•
3720-FS	Single Receptacle 1.40" Diameter Gray Base	3/32"	•	•
3723-FS	Decorator or GFCI Gray Base	3/32"	•	•
3722-FS	Power Outlet, 1.60" Diameter Gray Base	3/32"	•	•
3724-FS	Power Outlet, 1.73" Diameter Gray Base	3/32"	•	•
3795	Power Outlet, 2.13" Diameter Gray Base	3/8"	•	•
Self-Closing Covers – Clear Polycarbonate Lid Horizontal Two Screw Mounting				
3700	Duplex Receptacle Gray Base	3/32"	•	•
3703	Decorator Gray Base	3/32"	•	•
3703-T	Decorator RV Use Gray Base	3/8"	•	•
3703-TCW	Decorator RV Use Colonial White Base	3/8"	•	•
Self-Closing Covers – Clear Polycarbonate Lid Horizontal Four Screw Mounting				
3700-FS	Duplex Receptacle Gray Base	3/32"	•	•
3703-FS	Decorator Receptacle Gray Base	3/32"	•	•


Weatherproof Boxes & Covers Thermoplastic Covers

Pass & Seymour



Features	
<ul style="list-style-type: none"> ■ Broadest line in the industry. ■ All covers are self-closing with two flip lids. 	<ul style="list-style-type: none"> ■ Covers comply with 2005 NEC Section 406.8(A) and 406.8(B)(2).

Catalog Number	Description	Gasket Thickness	3rd Party Compliance	
			UL	SF
Outdoor Assemblies and Special Covers For Mobile Homes, Manufactured and Modular Housing, and RV Use – Horizontal Installation with Two Self-Closing Flip Lids				
3780-SCFBX	3232 Duplex Receptacle, Gasket and Flanged Box, Gray with Black Gasket	1/8"		•
3780-SCFBXCW	3232 Duplex Receptacle, Gasket and Flanged Box, Colonial White with Black Gasket	1/8"		•
3780-SCFBXWH	3232 Duplex Receptacle, Gasket and Flanged Box, White with White Gasket	1/8"		•
3780-SCMH	3232 Duplex Receptacle & Gasket, Gray with Black Gasket	3/8"		•
3780-SCMHCW	3232 Duplex Receptacle & Gasket, Colonial White with Black Gasket	3/8"		•
3780-SCMHBG	3232 Duplex Receptacle & Gasket, Beige with Black Gasket	3/8"		•
3780-SCMHW	3232 Duplex Receptacle & Gasket, White with White Gasket	3/8"		•
3780-SCLV	3/8" Round Openings for 2 Coaxial Connections, Gray with Black Gasket	1/8"	•	•
3780-SCLVBG	3/8" Round Openings for 2 Coaxial Connections, Beige with Black Gasket	1/8"	•	•
3780-SCLVCW	3/8" Round Openings for 2 Coaxial Connections, Colonial White with Black Gasket	1/8"	•	•
3780-SCLVWH	3/8" Round Openings for 2 Coaxial Connections, White with White Gasket	1/8"	•	•

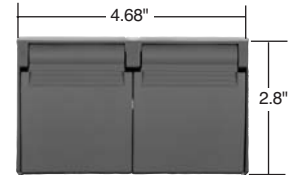

3780 Series



FBOX1


Catalog Number	Description	Color	3rd Party Compliance	
			UL	SF
Flanged Boxes for Horizontal or Vertical Installation				
FBOX1	Flanged Box – 18.5 Cubic Inch Minimum Opening Size 2.5" x 4.1" Depth 3.0"	Gray		•
FBOX1WH	Flanged Box – 18.5 Cubic Inch Minimum Opening Size 2.5" x 4.1" Depth 3.0"	White		•

Weatherproof Boxes & Covers


Thermoplastic Covers

Features


- Broadest line in the industry.
- Covers comply with 2005 NEC Section 406.8(A) and 406.8(B)(2).
- 3780 series have two flip lids.
- 3726 series have a single flip lid.

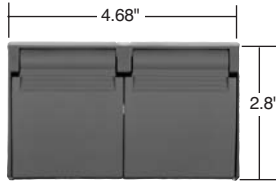



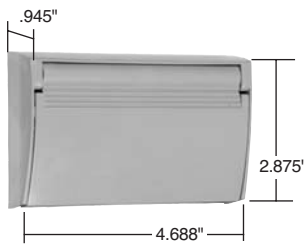



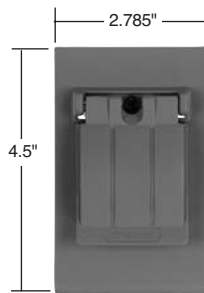






3780 Series



3726 Series



3760

Catalog Number	Description	Gasket Thickness	3rd Party Compliance	
			UL	CSA
Horizontal Self-Closing Flip Lids				
 3780-SC	Duplex, Gray with Black Gasket	1/8"	•	•
 3780-SCCW	Duplex, Colonial White with White Gasket	1/8"	•	•
 3780-SCWH	Duplex, White with White Gasket	1/8"	•	•
 3780-SCBG	Duplex, Beige with Black Gasket	1/8"	•	•
 3780-SCCWT	Duplex, Colonial White with Black Gasket	3/8"	•	•
 3726-SC	Decorator or GFCI, Gray with Black Gasket	3/32"	•	•
 3726-SCBG	Decorator or GFCI, Beige with Black Gasket	3/32"	•	•
 3726-SCCW	Decorator or GFCI, Colonial White with Black Gasket	3/32"	•	•
 3726-SCWH	Decorator or GFCI, White with White Gasket	3/32"	•	•
Horizontal Single Cover Self-Closing Flip-Lid				
 3770-SC	Single Receptacle 1.405" Diameter, Gray	3/32"	•	•
Vertical Single Cover Three Position Flip-Lid (Closed, Opened 90° or Opened 180°)				
 3760	Single Receptacle 1.563" Diameter, Gray	3/32"	•	•
 3763	Cover with 5251-I Single Receptacle, 15A-125V, Gray	3/32"	•	
Horizontal Reinforced Thermoplastic Two Position Flip-Lids, (Closed or Opened 90°)				
 3780	Duplex, Gray with Black Gasket, 2 Flip Lids	1/8"	•	•

Weatherproof Boxes & Covers Thermoplastic/ Heavy Cast Aluminum Covers

Specification Grade

Pass & Seymour




Weatherproof Boxes & Covers


Thermoplastic/Heavy Cast Aluminum Covers

Industrial Grade Weatherproof Covers

Features	
<ul style="list-style-type: none"> Unbreakable glass-filled polycarbonate construction to withstand years of job site abuse and harsh environmental exposure. Stainless steel mounting screws also resist corrosion. Covers comply with 2005 NEC Section 406.8(A) and 406.8(B)(2). Molded-in label area (2.8 sq. in.) for pre-printed or handwritten labels for identification of circuits, ratings, and other application data. 	<ul style="list-style-type: none"> WPG-1 and WPG-2 have lockable "bullnose" for OSHA locktag/tagout compliance. Covers fit all competitive inlets and outlets. Pre-attached gaskets for easy installation and tight seal to panel or weatherproof box – with no misaligned or collapsed gaskets. Tamper-proof hinge features permanent, locked-in pins for added security.

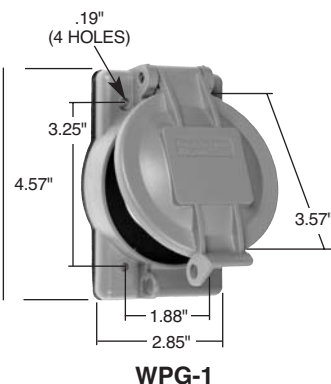

WPG-1

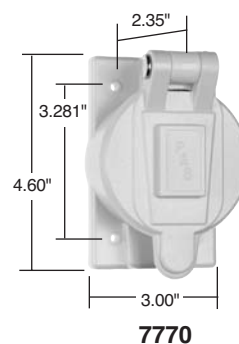


7770

Catalog Number	Description	Color	3rd Party Compliance	
			UL	SF
Thermoplastic Weatherproof Covers for Flanged Inlet/Outlet				
WPG-1	1.96" Diameter Opening to Accommodate 15/20A Straight Blade, 15A Turnlok, 20403 Power Interrupter	Gray	•	•
WPG-2	2.32" Diameter Opening to Accommodate 20A Turnlok, 30A Turnlok	Gray	•	•
Thermoplastic Weatherproof Cover for Single Receptacles				
7770	2.38" Diameter Opening to Accommodate 50A Turnlok (non-lockout)	Yellow	•	

Heavy Cast Aluminum Covers – Flush Enclosures

Features	
<ul style="list-style-type: none"> Adapter, frame, and cover are heavy cast aluminum. No. 8-32 screws hold assembly firmly in place. Covers comply with 2005 NEC Section 406.8(A) and 406.8(B)(2). Mortar keys provide positive holding means within wall. 	<ul style="list-style-type: none"> Neoprene gasket seals cover to frame. Moisture and dust cannot enter enclosure. Two keys provided for cam lock. Purchase enclosure and mounting plate separately Mounts on 4" or 4-11/16" box.

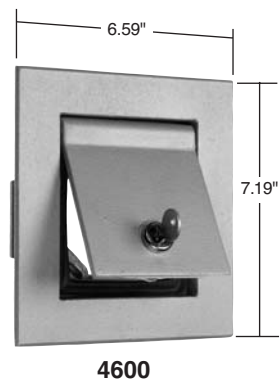

4600

Note: All locks keyed the same.

Catalog Number	Description	Color	3rd Party Compliance	
			UL	SF
Mortared-in Applications				
	4600 Enclosure Only, without Mounting Plate	Gray	•	•
	4600-1P Mounting Plate for Toggle Switch	Gray	•	•
	4600-7P Mounting Plate for Single Receptacle Diameter: 1.406"	Gray	•	•
	4600-8P Mounting Plate for Duplex Receptacle	Gray	•	•
	4600-26P Mounting Plate for Decorator/GFCI	Gray	•	•
	4609 Replacement Key for Enclosure		•	•