

Features

- Stainless steel mesh is corrosion resistant
- Multiweave grip gives cable arc-of-bend control
- Endless weave provides easy cable/flexible conduit installation

Ordering Information

Description	Form Size	Cable	UPC	Catalog Number
Straight Male Thread, F3 Stainless Steel Mesh, Liquidtight		.625"-.750 (1.59-1.90)	783585330303	074011247

Listings


UL Listed
CSA Certified

Specifications

Strand	Stainless Steel
Body	Aluminum

Performance

Environmental	
Flammability	UL 94HB (Strand grip), UL 94V-2(Fitting)
Hazardous Locations	Suitable for use in hazardous locations per Class I Div. 2, Class II Div. 1 & 2, Class III Div. 1 & 2 N.E.C
Operating Temperatures	-30°F to +240°F (-34°C to +115°C)
Wet Locations	Suitable for use in wet locations when used with a listed sealing ring between box and fitting

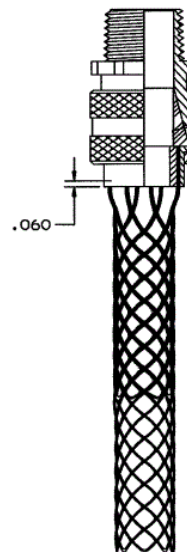

Related Products

Locknut	00322001LPK50
Metal Clad Sealing O-Ring	20509001

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions