





GE
Lighting

41459 - 100/300 6PK

GE soft white 3-way 100/200/300 watt PS25 1-pack

- Use original GE's Soft White when you need a light without glare and harsh shadows.
- Specifically designed for 3-way lamps in your home or office, GE 3-way bulbs offer a range of light levels. Choose the low light setting for energy savings, higher settings for general and activity lighting.
- Choose the low light setting for energy savings, higher settings for general and activity lighting.
- 2800K soft white light appearance
- GE soft white 3-way bulbs provide three levels of light for maximum flexibility--low for mood lighting and energy savings, high for task lighting. Use GE soft white 3-way bulbs warm, pleasing light without harsh shadows in table lamps and floor lamps with 3-way sockets
- Lasts 1.1 years based on 3 hours per day usage
- 1250/2650/3900 lumens providing strong, vibrant™ light
- Estimated yearly energy costs \$12.05/\$24.09/\$36.14 based on 3 hours per day \$0.11 per kWh
- PS25 shape with mogul base for use in table lamps and enclosed fixtures

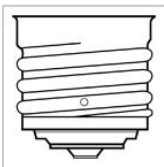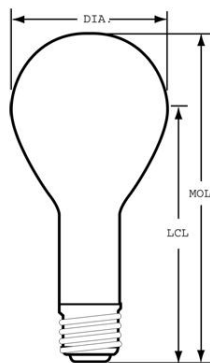

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	PS25D
Base	3 Contact Mogul Screw (E39D)
Filament	CC-6
Bulb Finish	Soft white
Rated Life	1200.0 hrs
Bulb Material	Soft glass
Life in Years	1.1
Primary Application	3-Way

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	1250.0 /2650.0 /3900.0
Color Temperature	2800.0 K
Nominal Initial Lumens per Watt	13 /13 /12

ELECTRICAL CHARACTERISTICS

Wattage	100.0
Voltage	120.0
Burn Position	Universal burning position
Estimated Energy Cost per Year	12.05

DIMENSIONS

Maximum Overall Length (MOL)	6.6800 in(169.7 mm)
Bulb Diameter (DIA)	3.125 in(79.4 mm)
Light Center Length (LCL)	4.430 in(112.5 mm)

PRODUCT INFORMATION

Product Code	41459
Description	100/300 6PK
Standard Package	BUNDLE
Standard Package GTIN	00043168414593
Standard Package Quantity	30
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	30
UPC	043168905053

CAUTIONS & WARNINGS

Warning

- Risk of Fire
 - Use in fixture rated for this product.




GE
Lighting

41459 - 100/300 6PK

GE soft white 3-way 100/200/300 watt PS25 1-pack

- Use original GE's Soft White when you need a light without glare and harsh shadows.
- Specifically designed for 3-way lamps in your home or office, GE 3-way bulbs offer a range of light levels. Choose the low light setting for energy savings, higher settings for general and activity lighting.
- Choose the low light setting for energy savings, higher settings for general and activity lighting.
- 2800K soft white light appearance
- GE soft white 3-way bulbs provide three levels of light for maximum flexibility--low for mood lighting and energy savings, high for task lighting. Use GE soft white 3-way bulbs warm, pleasing light without harsh shadows in table lamps and floor lamps with 3-way sockets
- Lasts 1.1 years based on 3 hours per day usage
- 1250/2650/3900 lumens providing strong, vibrant™ light
- Estimated yearly energy costs \$12.05/\$24.09/\$36.14 based on 3 hours per day \$0.11 per kWh
- PS25 shape with mogul base for use in table lamps and enclosed fixtures

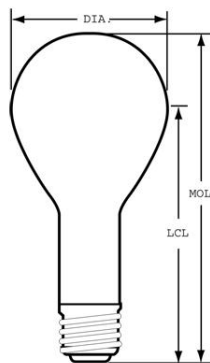

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	PS25D
Base	3 Contact Mogul Screw (E39D)
Filament	CC-6
Bulb Finish	Soft white
Rated Life	1200.0 hrs
Bulb Material	Soft glass
Life in Years	1.1
Primary Application	3-Way

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	1250.0 /2650.0 /3900.0
Color Temperature	2800.0 K
Nominal Initial Lumens per Watt	13 /13 /12

ELECTRICAL CHARACTERISTICS

Wattage	100.0
Voltage	120.0
Burn Position	Universal burning position
Estimated Energy Cost per Year	12.05

DIMENSIONS

Maximum Overall Length (MOL)	6.6800 in(169.7 mm)
Bulb Diameter (DIA)	3.125 in(79.4 mm)
Light Center Length (LCL)	4.430 in(112.5 mm)

PRODUCT INFORMATION

Product Code	41459
Description	100/300 6PK
Standard Package	BUNDLE
Standard Package GTIN	00043168414593
Standard Package Quantity	30
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	30
UPC	043168905053

CAUTIONS & WARNINGS

Warning

- Risk of Fire
 - Use in fixture rated for this product.