



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

3804 South Street
75964-7263, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685



1103DC 3/4" Diecast Chased Nipple

Bridgeport Fittings

Catalog Number	1103DC
Manufacturer	Bridgeport Fittings
Description	Conduit Chased Nipple, 3/4 In Trade Size, Hex Shape, Threaded Connection, 1/2 In Thread Length, 1-3/8 In Width, 0.0539 LB
Weight per unit	0.0539 (lbs/each)
Product Category	Rigid Conduit Fittings - Steel

Features

Material	ZINC DIE CAST
media	Yes

Material, Color, and Finish

Finish	Ball burnished, mirror smooth
--------	-------------------------------

Dimensions and Weight

Size	3/4 in
------	--------

Descriptions

Description	3/4" DIECAST CHASED NIPPLE
-------------	----------------------------

Manufacturer Information

Brand	Bridgeport
GTIN	00781747911032
UPC	781747911032

Taxonomies, Classifications, and Categories

Category Description	DIECAST OFFSET & CHASE NIPPLES
Type	Conduit Nipples

Packaging


Carton	1
Package	50
Weight Per each	0.0539

Uses, Certifications, and Standards

standard	cULus
----------	-------

Zinc

Images

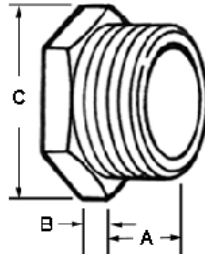

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1/2

Dimension B in Inches: 1/4

Dimension C in Inches: 1-3/8

Application

When used with a locknut, conduit nipples serve as a short raceway between enclosures.

Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50553

NEMA Standard: FB-1

UL File Number: E9391

UL Standard: UL-514B

UNSPSC: 39131718

Catalog ID: 1103-DC

UPC Number: 781747911032

Description: Nipple, Conduit, Zinc Die Cast, Size 3/4 Inch

Application: When used with a locknut, conduit nipples serve as a short raceway between enclosures.

Trade Size: 3/4"

Country of Manufacture: USA

Std Pkg Qty: 500

Unit Qty: 50