


Industrial Grade Heavy Duty String Lights

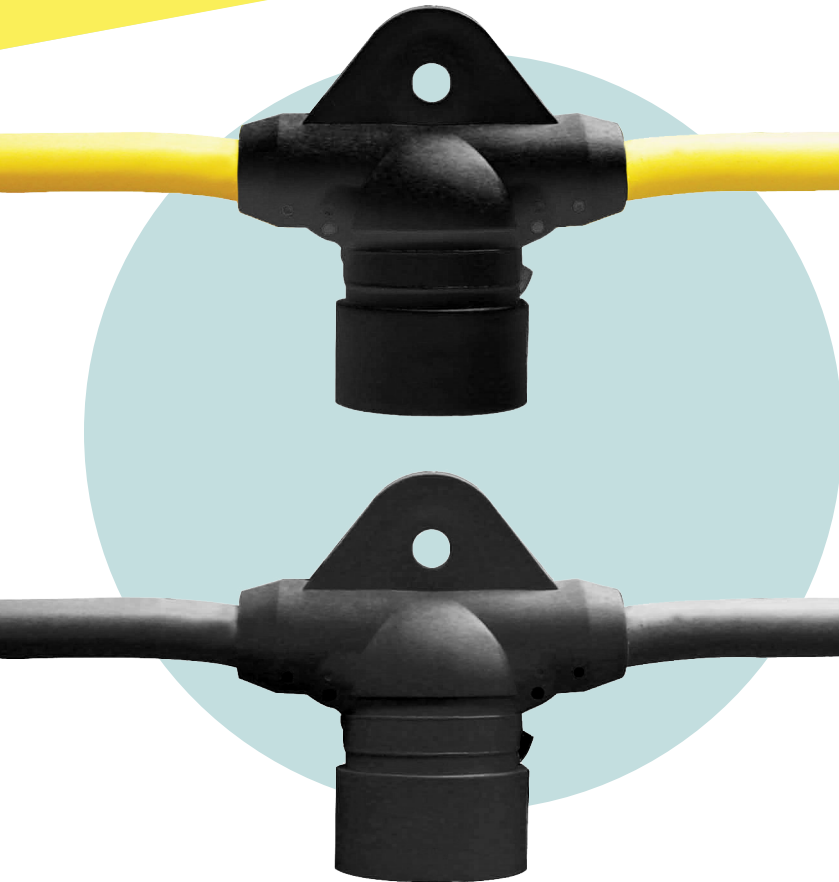

Standard Features:

- UL listed and CSA certified
- Meets OSHA, NEC, and CEC requirements.
- Full threaded screwshell to ensure proper contact
- Designed for applications that require rapid set-up and teardown
- String lights available in 50ft. and 100ft.
- String lights, standard with watertight NEMA Plug and connector
- Power drops available
- Guards sold separately
- Product customizations are available upon request

Applications:

- Petrochemical
- Military
- Power Generation
- Maintenance
- Mining
- Ship Building



Unique Features:



Durable elastomeric overmold protects sockets.



Full threaded screwshell to ensure proper contact.



Assembled with watertight plug and connector.




Available with custom spaced power drops.

Selection Guide:

Part Number	Length	Cable Type & Voltage	# of Sockets	Socket Spacing, Black Sockets	Max Watts per Socket	Primary	Secondary	Listing
Single Phase 3 wire, 14 gauge - Standard Duty String Lights Sockets*								
14350Y-1	50 ft.	Yellow 14/3 SEOW/SOW 600V	5	10 ft.	200 Watts	NEMA 5-15	NEMA 5-15	UL
143100Y-1	100 ft.	Yellow 14/3 SEOW/SOW 600V	10	10 ft.	150 Watts	NEMA 5-15	NEMA 5-15	UL
Single Phase 3 wire, 12 gauge - Standard Duty String Lights Sockets*								
12350Y-1	50 ft.	Yellow 12/3 SEOW/SOW 600V	5	10 ft.	200 Watts	NEMA 5-15	NEMA 5-15	UL / CSA
12350Y-3	50 ft.	Yellow 12/3 SEOW/SOW 600V	5	10 ft.	200 Watts	NEMA L5-20	NEMA L5-20	UL / CSA
123100Y-1	100 ft.	Yellow 12/3 SEOW/SOW 600V	10	10 ft.	150 Watts	NEMA 5-15	NEMA 5-15	UL / CSA
123100Y-3	100 ft.	Yellow 12/3 SEOW/SOW 600V	10	10 ft.	150 Watts	NEMA L5-20	NEMA L5-20	UL / CSA
Single Phase 4 wire, 12 gauge - Standard Duty String Lights Sockets*								
12460Y-4	60 ft.	Yellow 12/4 SEOW/SOW 600V	6	10 ft.	200 Watts	NEMA L14-20	NEMA L14-20	N/A
124100Y-4	100 ft.	Yellow 12/4 SEOW/SOW 600V	10	10 ft.	150 Watts	NEMA L14-20	NEMA L14-20	N/A
3 Phase 5 wire, 12 gauge - Standard Duty String Lights Sockets*								
12560Y-5	60 ft.	Yellow 12/5 SEOW/SOW 600V	6	10 ft.	200 Watts	NEMA L21-20	NEMA L21-20	N/A
12590Y-5	90 ft.	Yellow 12/5 SEOW/SOW 600V	9	10 ft.	200 Watts	NEMA L21-20	NEMA L21-20	N/A

 * Contact factory for military standard MIL-16377/39 crush resistant metal socket versions, or other customization



Guards:



211 Wire Guard



211-P Vinyl Guard




215 Rain Guard

Sold Separately.

Accessories:

Part Number	Description	Image Reference
SLBLED-60	11W 1150 lumen LED damp location light bulb	A
SS-HD	Rubber socket sleeve, weather tight seal	B
SLHK-01	String light hang kit	C

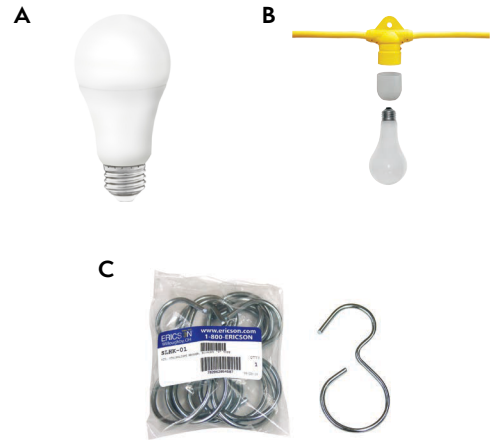

Customization Available:

Please complete form below.

Overall Length:		Socket Color:		Configuration for Plug/Conn:		Power Drop Spacing:	
Number of Sockets:		Primary Length:		Cable Color:		Power Drop Length:	
Socket Spacing:		Secondary Length:		Cable Size/# of Cond/ Jacket Type:		Drop Connector Configuration:	


Related Products



Commercial Grade
String Light



1004
Temporary Highbay
Lighting

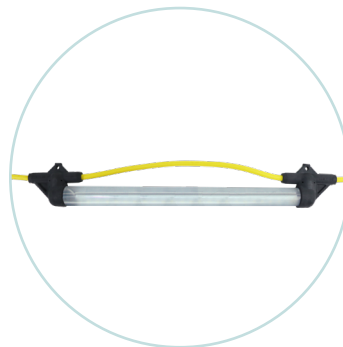

SL Series
Linear LED Lighting for
wet environments



SL Haz
Class 1, Div 2 String
Lights for Hazardous
Areas



Ericson Manufacturing Company
4323 Hamann Parkway
Willoughby, OH 44094, USA



1-800-374-2766
info@ericson.com
L1000839B