


Clamp-On Type

Images

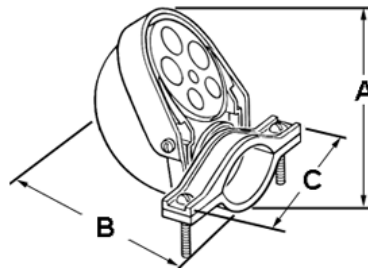

Application

Clamp type entrance cap for rigid conduit and IMC. 1 hole 7/16" dia.; 2 holes 5/8" dia.; 3 holes 3/4" dia.

Product Information

Material: Aluminum
 Finish: Plain

Certifications & Codes:

NEMA Standard: FB-1
 UL File Number: E11259
 UL Standard: UL-514B
 UNSPSC: 39121311

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 5-1/4
 Dimension B in Inches: 4-1/2
 Dimension C in Inches: 3-5/16

Catalog ID: 1255

UPC Number: 781747012555

Description: Entrance Cap, Clamp-On, Aluminum, Size 1 1/2 Inch

Application: Clamp type entrance cap for rigid conduit and IMC. 1 hole 7/16" dia.; 2 holes 5/8" dia.; 3 holes 3/4" dia.


Trade Size: 1-1/2"

Std Pkg Qty: 5

Unit Qty: Bulk

Clamp-On Type

Images

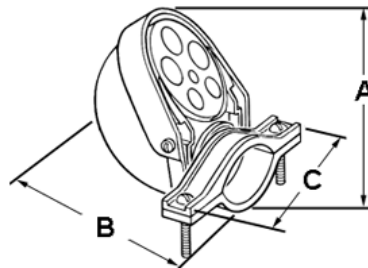

Application

Clamp type entrance cap for rigid conduit and IMC. 1 hole 7/16" dia.; 2 holes 5/8" dia.; 3 holes 3/4" dia.

Product Information

Material: Aluminum
 Finish: Plain

Certifications & Codes:

NEMA Standard: FB-1
 UL File Number: E11259
 UL Standard: UL-514B
 UNSPSC: 39121311

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 5-1/4
 Dimension B in Inches: 4-1/2
 Dimension C in Inches: 3-5/16

Catalog ID: 1255

UPC Number: 781747012555

Description: Entrance Cap, Clamp-On, Aluminum, Size 1 1/2 Inch

Application: Clamp type entrance cap for rigid conduit and IMC. 1 hole 7/16" dia.; 2 holes 5/8" dia.; 3 holes 3/4" dia.

Trade Size: 1-1/2"

Std Pkg Qty: 5

Unit Qty: Bulk