


Heavy Duty Grade Power Receptacles

2-Pole, 3-Wire Grounding
30A, 125V/AC
30A, 250V/AC

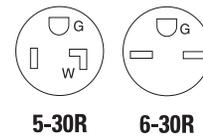

5-30R

6-30R

Features

- Heavy gauge galvanized steel mounting strap for corrosion resistance
- For use with copper or aluminum wire
- Flush receptacles fit one-gang or two-gang enclosures
- Surface receptacles have patented lay-in terminals that accept up to #4 AWG wire
- Surface receptacle backs feature concentric knockouts and an adjustable cord clamp to allow wiring from back or bottom



1263



1232



U1263

Flush Power NEMA TT



Rating		Description	Color	Catalog No.	
A	V/AC				
30	125	NEMA TT-30R Flush Mount Power Receptacle Matching Plug 83	BK	1263	

Listed to UL498, file no. E15058; CSA certified to CSA C22.2, no. 42

Flush Power NEMA 5-30R & NEMA 6-30R



Rating		Description	Color	Catalog No.	
A	V/AC				
30	125	NEMA 5-30R Flush Mount Power Receptacle Matching Plug S41	BK	1233	
30	250	NEMA 6-30R Flush Mount Power Receptacle Matching Plug S42	BK	1234	

Listed to UL498, file no. E15058; CSA certified to C22.2, no. 42; NOM certified

Surface Power Receptacle



Rating		Description	Color	Catalog No.	
A	V/AC				
30	250	NEMA 6-30R Surface Mount Power Receptacle Matching Plug S42	BK	1232	

Listed to UL498, file no. E15058; CSA certified to C22.2, no. 42; NOM certified

Panel Power Receptacles



Rating		Description	Color	Catalog No.
A	V/AC			
30	125	NEMA TT-30R Panel Mount Power Receptacle Matching Plug 83	BK	U1263

Listed to UL498, file no. E15058; CSA certified to C22.2, no. 42; NOM certified

Color Information:

BK (Black)



(Black)

Dimensional Information: B-70 **Specification Information:** Please visit www.cooperwiringdevices.com.

Specifications and availability are subject to change without notice.

NAFTA Compliant - see page F-21