





GE
Lighting

72532 - 150A21/RS-PK6

GE rough service work light 150/133 watt A21 1-pack

- 130/120 volts
- A21 shape with medium base for use in rough service applications
- GE rough services worklight bulbs are specially designed with rugged filaments and mounts to withstand rough handling and shock better than regular household bulbs
- Lasts 0.9/2.4 years based on 3 hours per day usage
- Estimated yearly energy costs \$18.07/\$16.02 based on 3 hours per day \$0.11 per kWh
- Provides 2065/1580 lumens

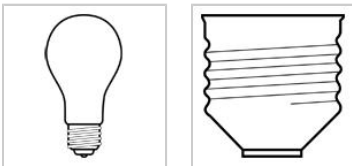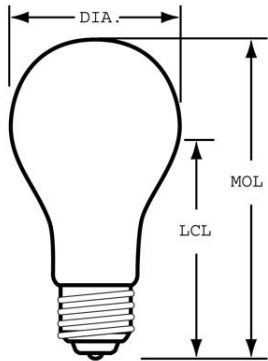

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A21
Base	Medium Screw (E26)
Filament	C-17
Bulb Finish	Inside frost
Rated Life	1000.0 hrs
Primary Application	Rough Service

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	2065.0 /1580.0
Nominal Initial Lumens per Watt	13 /11

ELECTRICAL CHARACTERISTICS

Wattage	150.0
Voltage	130.0

DIMENSIONS

Maximum Overall Length (MOL)	5.3700 in(136.4 mm)
Bulb Diameter (DIA)	3.750 in(95.2 mm)
Light Center Length (LCL)	4.060 in(103.1 mm)

PRODUCT INFORMATION

Product Code	72532
Description	150A21/RS-PK6
Standard Package	BUNDLE
Standard Package GTIN	00043168725323
Standard Package Quantity	30
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	30
UPC	043168725316