


Zinc - Threaded

Images

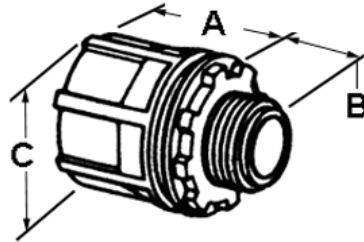

Application

To secure threaded rigid service entrance conduit to box or enclosure. Insulated throat rated 105 degree c. Suitable for Aluminum and Steel Rigid Conduit. UL Listed

Product Information

Material: Zinc Die Cast
Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50553
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121311

[Download Photo Image](#) [Download Dimensional Image](#)

Dimension A in Inches: 15/16

Dimension B in Inches: 5/8

Dimension C in Inches: 1-1/4

Catalog ID: 152-DC

UPC Number: 781747091529

Description: Threaded Hub, Zinc Die Cast, Size 3/4 Inch

Application: To secure threaded rigid service entrance conduit to box or enclosure. Insulated throat rated 105 degree c. Suitable for Aluminum and Steel Rigid Conduit. UL Listed

Trade Size: 3/4"

Std Pkg Qty: 100

Unit Qty: 25