
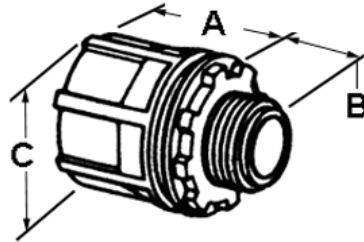


## Zinc - Threaded

### Images

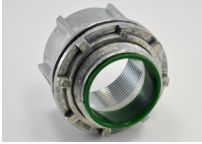

### Application

To secure threaded rigid service entrance conduit to box or enclosure. Insulated throat rated 105 degree c. UL listed Type 4 - Watertight. Suitable for Aluminum and Steel Rigid Conduit.

### Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

### Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50553
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121311

[Download Photo Image](#)    [Download Dimensional Image](#)

Dimension A in Inches: 1-1/4

Dimension B in Inches: 13/16

Dimension C in Inches: 2-3/16

**Catalog ID:** 155-DC

**UPC Number:** 781747091550

**Description:** Threaded Hub, Zinc Die Cast, Size 1 1/2 Inch

**Application:** To secure threaded rigid service entrance conduit to box or enclosure. Insulated throat rated 105 degree c. UL listed Type 4 - Watertight. Suitable for Aluminum and Steel Rigid Conduit.

**Trade Size:** 1-1/2"

**Std Pkg Qty:** 20

**Unit Qty:** 2