
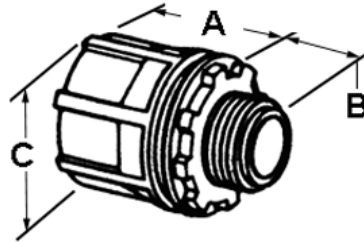


Zinc - Threaded

Images

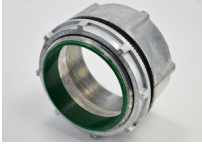

Application

To secure threaded rigid service entrance conduit to box or enclosure. Insulated throat rated 105 degree c. UL listed Type 4 - Watertight. Suitable for Aluminum and Steel Rigid Conduit.

Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50553

NEMA Standard: FB-1

UL File Number: E9391

UL Standard: UL-514B

UNSPSC: 39121311

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-5/8

Dimension B in Inches: 15/16

Dimension C in Inches: 3-13/16

Catalog ID: 158-DC

UPC Number: 781747091581

Description: Threaded Hub, Zinc Die Cast, Size 3 Inch

Application: To secure threaded rigid service entrance conduit to box or enclosure. Insulated throat rated 105 degree c. UL listed Type 4 - Watertight. Suitable for Aluminum and Steel Rigid Conduit.

Trade Size: 3"

Country of Manufacture: USA

Std Pkg Qty: 5

Unit Qty: Bulk