



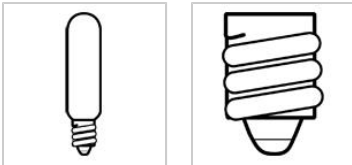

GE
Lighting

13402 - 15T6

GE T6

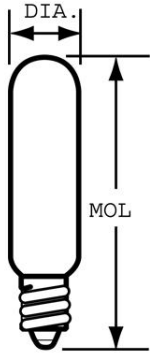

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Tubular
Bulb	T6
Base	Candelabra Screw (E12)
Filament	C-7A
Bulb Finish	Clear
Rated Life	1500.0 hrs
Primary Application	Standard;Standard

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	102.0
Nominal Initial Lumens per Watt	6

ELECTRICAL CHARACTERISTICS

Wattage	15.0
Voltage	145.0

DIMENSIONS

Maximum Overall Length (MOL)	3.0600 in(77.7 mm)
Bulb Diameter (DIA)	0.750 in(19.0 mm)
Light Center Length (LCL)	1.560 in(39.6 mm)

PRODUCT INFORMATION

Product Code	13402
Description	15T6
Standard Package	Case
Standard Package GTIN	10043168134023
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168134026