


Bolt and Nut Type - Steel

Images

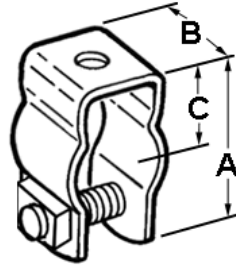

Application

To secure EMT or rigid conduit to threaded rod, insulator supports, or directly to mounting surface. With Carriage Bolt and Nut.

Product Information

Material: Steel

Finish: Zinc electro-plate

Certifications & Codes:

CSA File Number: LR39354

UL File Number: E161206

UNSPSC: 39121701

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 2.75

Dimension B in Inches: 0.88

Dimension C in Inches: 1.31

Catalog ID: 2125-BN

UPC Number: 781747202253

Description: Hanger, Conduit, Steel, Bolt & Nut, Trade Size 2-1/2

Application: To secure EMT or rigid conduit to threaded rod, insulator supports, or directly to mounting surface. With Carriage Bolt and Nut.

Trade Size: 2-1/2

Country of Manufacture: USA

Std Pkg Qty: 50