
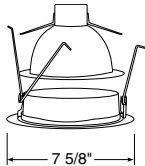


 


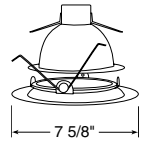


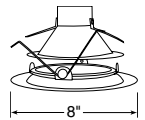


 





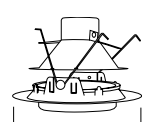



Project: _____

Fixture Type: _____


 


 


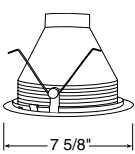


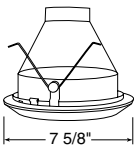


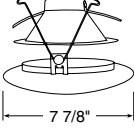


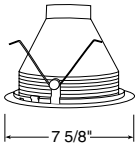

Location: _____

Contact/Phone: _____

Trim Series	Dimensions	Aperture	Catalog No.	Housing/ Lamp Compatibility
 <p>Frosted Lens with Reflector</p>			<p>239 WH 6" Lensed Frosted Lens Trim - White</p>	<p>IC2: 40W A19, 35W PAR30L TC2: 100W A19, TC2R: 75W A19 IC22LED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM TC22LED*: G4 09LM/ G4 14LM/ G4 20LM ICPL6: 18W, 26W, 32W PL6: 18W, 42W (32W rating) IC23: 35W PAR30L</p>
* Do not use reflector shipped with trim for LED Housing				
 <p>Albalite</p>			<p>20 PW 6" Lensed Albalite Trim - Plastic White 20 WH 6" Lensed Albalite Trim - White</p>	<p>IC2: 40W A19, TC2/TC2R: 70W A19 IC22LED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED: G4 09LM/ G4 14LM/ G4 20LM APT2: 75W A19</p>
 <p>Albalite Lends with Reflector</p>			<p>220 PW 6" Albalite Lens With Reflector Trim - Plastic White 220 WH 6" Albalite Lens With Reflector Trim - White</p>	<p>ICPL6: 26W, 32W (26W rating) PL6: 42W (26W rating)</p>
 <p>Albalite with Reflector</p>			<p>240 PW 6" Lensed Albalite with Reflector Trim - Plastic White 240 WH 6" Lensed Albalite with Reflector Trim - White</p>	<p>IC2: 60W A19, TC2/TC2R: 100W A19 ICPL6: 18W PL6: 18W APT2: 75W A19</p>
 <p>Drop Oval</p>			<p>21 PW 6" Lensed Drop Opal Trim - Plastic White 21 WH 6" Lensed Drop Opal Trim - White</p>	<p>IC2: 40W A19, TC2/TC2R: 75W A19 IC22LED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED: G4 09LM/ G4 14LM/ G4 20LM APT2: 75W A19</p>
 <p>Drop Oval with Reflector</p>			<p>241 PW 6" Lensed Drop Opal with Reflector Trim - Plastic White 241 WH 6" Lensed Drop Opal with Reflector Trim - White</p>	<p>IC2: 60W A19, TC2/TC2R: 100W A19 IC21/IC21R: 40W A19 IC22LED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED*: G4 09LM/ G4 14LM/ G4 20LM ICPL6: 18W, 26W, 32W (26W rating) PL6: 18W, 42W (26W rating) APT2: 100W A19</p>
* Do not use reflector shipped with trim for LED Housing				
 <p>Drop Oval with Reflector</p>			<p>271 PW 6" Lensed Drop Opal with Reflector Trim - Plastic White</p>	<p>ICPL6: 18W, 26W, 32W PL6: 18W, 42W (32W rating)</p>

Housing and trim can be ordered together or separate, but will always ship separately.

6" TRIM SERIES LENSED

Trim Series	Dimensions	Aperture	Catalog No.	Housing/ Lamp Compatibility
 <p>Frosted Lens with Clear Center</p>	 <p>7 3/8"</p>		<p>242 ABZ 6" Lensed Frosted Lens with Clear Center Trim - Classic Aged Bronze 242 SC 6" Lensed Frosted Lens with Clear Center Trim - Satin Chrome 242 WH 6" Lensed Frosted Lens with Clear Center Trim - White</p>	<p>IC2: 75W PAR38, TC2/ TC2R: 120W PAR38 IC22/ IC22 W/ IC22 S/ IC22R: 45W PAR38 IC22LED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED: G4 09LM/ G4 14LM/ G4 20LM ICPL6: 26W, 32W PL6: 42W (32W rating) APT2: 120W PAR38</p>
 <p>Fresnel</p>	 <p>8"</p>		<p>22 WH 6" Lensed Fresnel Trim - White</p>	<p>IC2: 40W A19, TC2/ TC2R: 75W A19 IC22LED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED: G4 09LM/ G4 14LM/ G4 20LM ICPL6: 26W PL6: 42W (32W rating) APT2: 75W A19</p>
 <p>Baffle, Regressed Frosted Dome Lens</p>	 <p>7 5/8"</p>		<p>2330 BWH 6" Lensed Baffle with Regressed Frosted Dome Lens Trim - Black Baffle, White Trim Ring 2330 WWH 6" Lensed Baffle with Regressed Frosted Dome Lens Trim - White Baffle, White Trim Ring</p>	<p>ICPL6: 18W, 26W, 32W PL6: 18W, 42W (32W rating) IC22LED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED*: G4 09LM/ G4 14LM/ G4 20LM</p>
* Do not use reflector shipped with trim for LED Housing				
 <p>Beveled Frame Frosted Dome Lens</p>	 <p>7 5/8"</p>		<p>6101 ABZ 6" Lensed Beveled Frame with Frosted Dome Lens Trim - Classic Aged Bronze 6101 SC 6" Lensed Beveled Frame with Frosted Dome Lens Trim - Satin Chrome 6101 WH 6" Lensed Beveled Frame with Frosted Dome Lens Trim - White</p>	<p>ICPL6: 18W, 26W, 32W PL6: 18W, 42W IC22LED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED*: G4 09LM/ G4 14LM/ G4 20LM</p>
* Do not use reflector shipped with trim for LED Housing				
 <p>Decorative Swirled Etched Opal Glass Trim - White</p>	 <p>7 7/8"</p>		<p>243 WH</p>	<p>IC2: 60W A19 TC2/ TC2R: 100W A19 IC22LED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM TC22LED*: G4 09LM/ G4 14LM/ G4 20LM ICPL6: 26W PL6: 42W (32W rating)</p>
* Do not use reflector shipped with trim for LED Housing				
 <p>Wall Wash Fluted Drop Opal Trim - White</p>	 <p>7 5/8"</p>		<p>9900 WH</p>	<p>IC2: 60W A19, TC2/ TC2R: 75W A19 ICPL6: 13W, 18W, 26W, 32W PL6: 13W, 18W, 26W APT2: 75W A19</p>


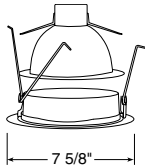


 


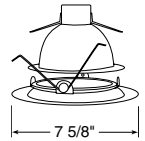


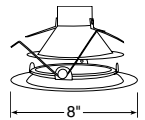


 





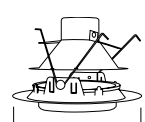

Housing and trim can be ordered together or separate, but will always ship separately.

Project: _____

Fixture Type: _____


 


 


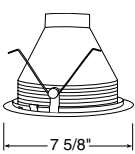


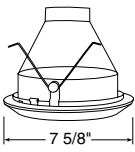


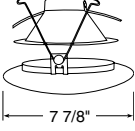


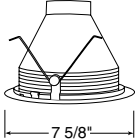

Location: _____

Contact/Phone: _____

Trim Series	Dimensions	Aperture	Catalog No.	Housing/ Lamp Compatibility
 <p>Frosted Lens with Reflector</p>	 <p>7 5/8"</p>		<p>239 WH 6" Lensed Frosted Lens Trim - White</p>	<p>IC2: 40W A19, 35W PAR30L TC2: 100W A19, TC2R: 75W A19 IC22LED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM TC22LED*: G4 09LM/ G4 14LM/ G4 20LM ICPL6: 18W, 26W, 32W PL6: 18W, 42W (32W rating) IC23: 35W PAR30L</p>
* Do not use reflector shipped with trim for LED Housing				
 <p>Albalite</p>	 <p>8"</p>		<p>20 PW 6" Lensed Albalite Trim - Plastic White 20 WH 6" Lensed Albalite Trim - White</p>	<p>IC2: 40W A19, TC2/TC2R: 70W A19 IC22LED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED: G4 09LM/ G4 14LM/ G4 20LM APT2: 75W A19</p>
 <p>Albalite Lends with Reflector</p>	 <p>7 5/8"</p>		<p>220 PW 6" Albalite Lens With Reflector Trim - Plastic White 220 WH 6" Albalite Lens With Reflector Trim - White</p>	<p>ICPL6: 26W, 32W (26W rating) PL6: 42W (26W rating)</p>
 <p>Albalite with Reflector</p>	 <p>8"</p>		<p>240 PW 6" Lensed Albalite with Reflector Trim - Plastic White 240 WH 6" Lensed Albalite with Reflector Trim - White</p>	<p>IC2: 60W A19, TC2/TC2R: 100W A19 ICPL6: 18W PL6: 18W APT2: 75W A19</p>
 <p>Drop Oval</p>	 <p>8"</p>		<p>21 PW 6" Lensed Drop Opal Trim - Plastic White 21 WH 6" Lensed Drop Opal Trim - White</p>	<p>IC2: 40W A19, TC2/TC2R: 75W A19 IC22LED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED: G4 09LM/ G4 14LM/ G4 20LM APT2: 75W A19</p>
 <p>Drop Oval with Reflector</p>	 <p>8"</p>		<p>241 PW 6" Lensed Drop Opal with Reflector Trim - Plastic White 241 WH 6" Lensed Drop Opal with Reflector Trim - White</p>	<p>IC2: 60W A19, TC2/TC2R: 100W A19 IC21/IC21R: 40W A19 IC22LED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED*: G4 09LM/ G4 14LM/ G4 20LM ICPL6: 18W, 26W, 32W (26W rating) PL6: 18W, 42W (26W rating) APT2: 100W A19</p>
* Do not use reflector shipped with trim for LED Housing				
 <p>Drop Oval with Reflector</p>	 <p>8"</p>		<p>271 PW 6" Lensed Drop Opal with Reflector Trim - Plastic White</p>	<p>ICPL6: 18W, 26W, 32W PL6: 18W, 42W (32W rating)</p>

Housing and trim can be ordered together or separate, but will always ship separately.

6" TRIM SERIES LENSED

Trim Series	Dimensions	Aperture	Catalog No.	Housing/ Lamp Compatibility
 <p>Frosted Lens with Clear Center</p>	 <p>7 3/8"</p>		<p>242 ABZ 6" Lensed Frosted Lens with Clear Center Trim - Classic Aged Bronze 242 SC 6" Lensed Frosted Lens with Clear Center Trim - Satin Chrome 242 WH 6" Lensed Frosted Lens with Clear Center Trim - White</p>	<p>IC2: 75W PAR38, TC2/ TC2R: 120W PAR38 IC22/ IC22 W/ IC22 S/ IC22R: 45W PAR38 IC22LED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED: G4 09LM/ G4 14LM/ G4 20LM ICPL6: 26W, 32W PL6: 42W (32W rating) APT2: 120W PAR38</p>
 <p>Fresnel</p>	 <p>8"</p>		<p>22 WH 6" Lensed Fresnel Trim - White</p>	<p>IC2: 40W A19, TC2/ TC2R: 75W A19 IC22LED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED: G4 09LM/ G4 14LM/ G4 20LM ICPL6: 26W PL6: 42W (32W rating) APT2: 75W A19</p>
 <p>Baffle, Regressed Frosted Dome Lens</p>	 <p>7 5/8"</p>		<p>2330 BWH 6" Lensed Baffle with Regressed Frosted Dome Lens Trim - Black Baffle, White Trim Ring 2330 WWH 6" Lensed Baffle with Regressed Frosted Dome Lens Trim - White Baffle, White Trim Ring</p>	<p>ICPL6: 18W, 26W, 32W PL6: 18W, 42W (32W rating) IC22LED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED*: G4 09LM/ G4 14LM/ G4 20LM</p>
* Do not use reflector shipped with trim for LED Housing				
 <p>Beveled Frame Frosted Dome Lens</p>	 <p>7 5/8"</p>		<p>6101 ABZ 6" Lensed Beveled Frame with Frosted Dome Lens Trim - Classic Aged Bronze 6101 SC 6" Lensed Beveled Frame with Frosted Dome Lens Trim - Satin Chrome 6101 WH 6" Lensed Beveled Frame with Frosted Dome Lens Trim - White</p>	<p>ICPL6: 18W, 26W, 32W PL6: 18W, 42W IC22LED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM TC22LED*: G4 09LM/ G4 14LM/ G4 20LM</p>
* Do not use reflector shipped with trim for LED Housing				
 <p>Decorative Swirled Etched Opal Glass Trim</p>	 <p>7 7/8"</p>		<p>243 WH 6" Decorative Swirled Etched Opal Glass Trim - White</p>	<p>IC2: 60W A19 TC2/ TC2R: 100W A19 IC22LED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM IC22RLED*: G4 06LM, WD G4N 06LM/ G4 09LM, WD G4 09LM/ G4 14LM TC22LED*: G4 09LM/ G4 14LM/ G4 20LM ICPL6: 26W PL6: 42W (32W rating)</p>
* Do not use reflector shipped with trim for LED Housing				
 <p>Wall Wash Fluted Drop Opal Trim</p>	 <p>7 5/8"</p>		<p>9900 WH 6" Wall Wash Fluted Drop Opal Trim - White</p>	<p>IC2: 60W A19, TC2/ TC2R: 75W A19 ICPL6: 13W, 18W, 26W, 32W PL6: 13W, 18W, 26W APT2: 75W A19</p>

Housing and trim can be ordered together or separate, but will always ship separately.