




4 in. Square Box, Welded, 2-1/8 in. Deep, One 1/2 in. and Eleven 3/4 in. KO's

By Raco
Catalog # [231](#)

4 in. Square Box, Welded, 2-1/8 in. Deep, One 1/2 in. and Eleven 3/4 in. KO's

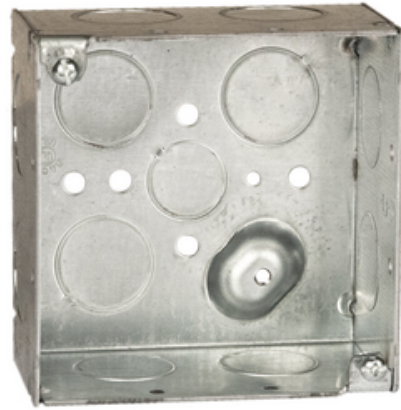

*Representative Image

Features

- Combination screw heads allow quick installation
- Welded construction
- One 1/2 in. and Eleven 3/4 in. Knockouts
- Raised ground
- 30.3 cu. in. capacity
- Acceptable in 2-hour fire rated walls
- UL Listed

General

Bracket Type	No Bracket
Drawn or Welded	Welded
EU RoHS Indicator	Contact Manufacturer
Fire Resistance	Yes
Knockouts	1/2 in.;3/4 in
Material	Steel
Type	Box
UPC	050169902318
Wiring System	Conduit

Dimensions

Actual Depth	2.425 in
Cubic Capacity	30.3 cu.in
Depth	2.125 in
Height	4 in
Raised Ground	No
Weight	0.894 lb
Width	4 in

Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

Logistics

Carton Quantity	25
Packaging Type	No Packaging
Pallet Quantity	1750

Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)
[Certifications - LEED Statement](#)
[Certifications - NEMA OS1](#)
[Certifications - UL COC - E195978-5](#)
[Sales Drawings - 231](#)
[Sales Drawings - RACO-welded-steel-box-infographic](#)
[SDS - HCC_SDS](#)
[Terms and Conditions - HCC Terms & Conditions](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
RACO-231-SPEC-EN | REV 5/2024