




## 4 in. Square Box, Welded, 2-1/8 in. Deep, Two 3/4 in., Two 1/2 in., & Eight 1 in. KO's

By Raco  
Catalog # [233](#)

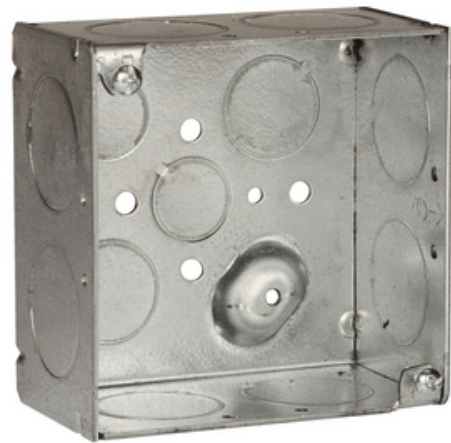

4 in. Square Box, Welded, 2-1/8 in. Deep, Two 3/4 in., Two 1/2 in., & Eight 1 in. KO's

### Features

- Combination screw heads allow quick installation
- Welded construction
- Eight 1 in., Two 3/4 in. and Two 1/2 in. KO's
- UL Listed
- 30.3 cu. in. capacity
- Acceptable in 2-hour fire rated walls

### General

Bracket Type	No Bracket
Drawn or Welded	Welded
EU RoHS Indicator	Yes
Fire Resistance	Yes
Knockouts	1/2 in.;3/4 in.;1 in
Material	Steel
Type	Box
UPC	050169902332
Wiring System	Conduit

### Dimensions

Actual Depth	2.5 in
Cubic Capacity	30.3 cu.in
Depth	2.125 in
Height	4 in
Raised Ground	No
Weight	0.89 lb
Width	4 in

### Certifications And Compliance

Certified Listed	UL Listed
------------------	-----------

### Logistics

Carton Quantity	25
Packaging Type	No Packaging
Pallet Quantity	1750

### Product Assets

[Catalogs - RACO / TayMac / Bell Full Catalog](#)  
[Certifications - LEED Statement](#)  
[Certifications - NEMA OS1](#)  
[Certifications - UL COC - E195978-5](#)  
[Sales Drawings - 233](#)  
[Sales Drawings - RACO-welded-steel-box-infographic](#)  
[SDS - HCC\\_SDS](#)  
[Terms and Conditions - HCC Terms & Conditions](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
RACO-233-SPEC-EN | REV 5/2024