


Connectors - Zinc

Images

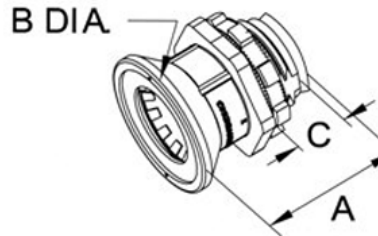

Application

The 250-MBI is used to connect a properly deburred length of EMT raceway to a box, device, panelboard, or similar electrical enclosure. Simply push the fitting on to raceway with a slight twist. Remove the fitting by unthreading it from conduit end. No tools are required. Concrete Tight. Patented

Product Information

[Download Photo Image](#) [Download Dimensional Image](#)
Dimension A in Inches: 1.29
Dimension B in Inches: 1.25
Dimension C in Inches: .43 thread length

Material: Zinc Alloy body and locknut with steel internal components
Finish: Mirror Finish/Ball Burnished

Certifications & Codes:

CSA File Number: 22.2 18.3-04
Federal Specification Number: A-A-50553
NEMA Standard: FB-1
UL File Number: E24001,cULus
UL Standard: UL-514B
UNSPSC: 39121434

Catalog ID: 250-MBI

UPC Number: 78174724250

Description: The Bridgeport Fittings 250-MBI Mighty-Bite™ are Insulated Throat, PUSH-EMT® Connectors.

Application: The 250-MBI is used to connect a properly deburred length of EMT raceway to a box, device, panelboard, or similar electrical enclosure. Simply push the fitting on to raceway with a slight twist. Remove the fitting by unthreading it from conduit end. No tools are required. Concrete Tight. Patented

Trade Size: 1/2"

Std Pkg Qty: 250

Unit Qty: 25