





GE
Lighting

37771 - 250R40/10 6PK

GE heat lamp 250 watt R40 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- Use it at home to heat small areas of the bathroom and workbench, or to prevent freezing of water pipes, car radiators and pumps.
- 120 volts
- Red light bulb
- GE heat lamps have many uses around the home, garage, and workshop. Use GE heat lamps at home to heat small areas of the bathroom and workbench, or to prevent freezing of water pipes, car radiators and pumps
- Lasts 5000 hours
- R40 shape with medium base

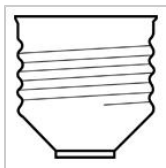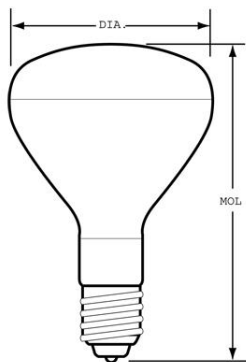

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Reflector
Bulb	R40
Base	Medium Screw (E26)
Filament	C-9
Rated Life	5000.0 hrs
Bulb Material	Hard glass
Primary Application	Heat Lamp10

ELECTRICAL CHARACTERISTICS

Wattage	250.0
Voltage	120.0

DIMENSIONS

Maximum Overall Length (MOL)	6.5600 in(166.6 mm)
Bulb Diameter (DIA)	5.000 in(127.0 mm)

PRODUCT INFORMATION

Product Code	37771
Description	250R40/10 6PK
Standard Package	Case
Standard Package GTIN	00043168377713
Standard Package Quantity	6
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168906586

CAUTIONS & WARNINGS

Warning

- Unexpected lamp rupture may cause injury, fire, or property damage
 - Avoid direct water, liquid or metal contact.
- Risk of Burn
 - Do not touch operating lamp.
- Lamp emits IR radiation which may cause eye injury
 - Do not use on infant, disabled, sleeping, or unconscious person or any person/animal unable to avoid potential injury.
- Risk of Fire
 - Keep combustible materials away from lamp.
 - Use in fixture rated for this product.





GE
Lighting

37771 - 250R40/10 6PK

GE heat lamp 250 watt R40 1-pack

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- Use it at home to heat small areas of the bathroom and workbench, or to prevent freezing of water pipes, car radiators and pumps.
- 120 volts
- Red light bulb
- GE heat lamps have many uses around the home, garage, and workshop. Use GE heat lamps at home to heat small areas of the bathroom and workbench, or to prevent freezing of water pipes, car radiators and pumps
- Lasts 5000 hours
- R40 shape with medium base

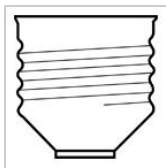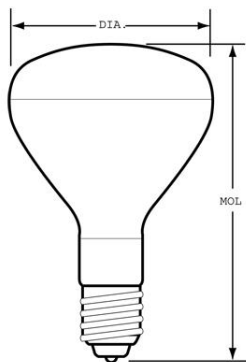

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Reflector
Bulb	R40
Base	Medium Screw (E26)
Filament	C-9
Rated Life	5000.0 hrs
Bulb Material	Hard glass
Primary Application	Heat Lamp10

ELECTRICAL CHARACTERISTICS

Wattage	250.0
Voltage	120.0

DIMENSIONS

Maximum Overall Length (MOL)	6.5600 in(166.6 mm)
Bulb Diameter (DIA)	5.000 in(127.0 mm)

PRODUCT INFORMATION

Product Code	37771
Description	250R40/10 6PK
Standard Package	Case
Standard Package GTIN	00043168377713
Standard Package Quantity	6
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168906586

CAUTIONS & WARNINGS

Warning

- Unexpected lamp rupture may cause injury, fire, or property damage
 - Avoid direct water, liquid or metal contact.
- Risk of Burn
 - Do not touch operating lamp.
- Lamp emits IR radiation which may cause eye injury
 - Do not use on infant, disabled, sleeping, or unconscious person or any person/animal unable to avoid potential injury.
- Risk of Fire
 - Keep combustible materials away from lamp.
 - Use in fixture rated for this product.