


## Connectors - Zinc

### Images

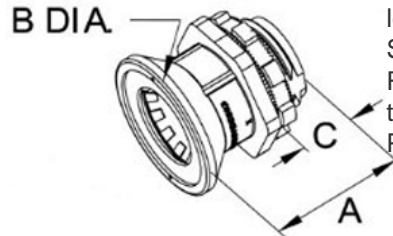

### Application

The 251-MB is used to connect a properly deburred length of EMT raceway to a box or electrical enclosure. Simply push the fitting onto raceway with a slight twist. Remove the fitting by unthreading it from conduit end. No tools are required. Concrete Tight. Dry locations only. Patented

### Product Information

[Download Photo Image](#)   [Download Dimensional Image](#)  
Dimension A in Inches: 1.47  
Dimension B in Inches: 1.50  
Dimension C in Inches: .46

Material: Zinc Alloy body and locknut with steel internal components  
Finish: Mirror finish/Ball Burnish

### Certifications & Codes:

Federal Specification Number: A-A-50553  
NEMA Standard: FB-1  
UL File Number: E24001,cULus  
UL Standard: 514B  
UNSPSC: 39121434  
Patent Number: 8,274,000; 8,487,197; 6,765,143

**Catalog ID:** 251-MB

**UPC Number:** 78174723251

**Description:** 3/4" DRY The Mighty-Bite™ 251-MB is a PUSH-EMT® Connector.

**Application:** The 251-MB is used to connect a properly deburred length of EMT raceway to a box or electrical enclosure. Simply push the fitting onto raceway with a slight twist. Remove the fitting by unthreading it from conduit end. No tools are required. Concrete Tight. Dry locations only. Patented

**Trade Size:** 3/4"

**Country of Manufacture:** USA

**Std Pkg Qty:** 250

**Unit Qty:** 25