


Connectors - Zinc

Images

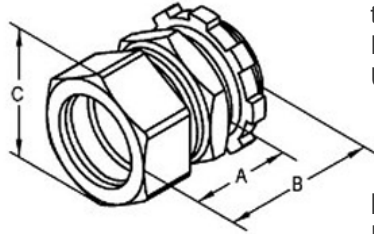

Application

Used to join steel EMT to box or enclosure. Concrete-tight. 1/2" thru 2" suitable for use with Steel or Aluminum EMT. Insulator rated 105°C. CSA Listed Raintight/For Use in Wet Locations in Canada Only

Product Information

Material: Zinc Die Cast
Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50553
NEMA Standard:	FB-1
UL File Number:	E24001
UL Standard:	UL-514B
UNSPSC:	39121434

[Download Photo Image](#) [Download Dimensional Image](#)
Dimension A in Inches: 3/4
Dimension B in Inches: 1-3/8
Dimension C in Inches: 2-15/16

Catalog ID: 255-DC12

UPC Number: 781747162557

Description: Connector, Compression, Zinc Die Cast, 105°C Insulated Throat, Size 2 Inch

Application: Used to join steel EMT to box or enclosure. Concrete-tight. 1/2" thru 2" suitable for use with Steel or Aluminum EMT. Insulator rated 105°C. CSA Listed Raintight/For Use in Wet Locations in Canada Only

Trade Size: 2"

Country of Manufacture: USA

Std Pkg Qty: 10

Unit Qty: Bulk